


RoHS Compliant

[BOMcheck.net](https://www.bomcheck.net)

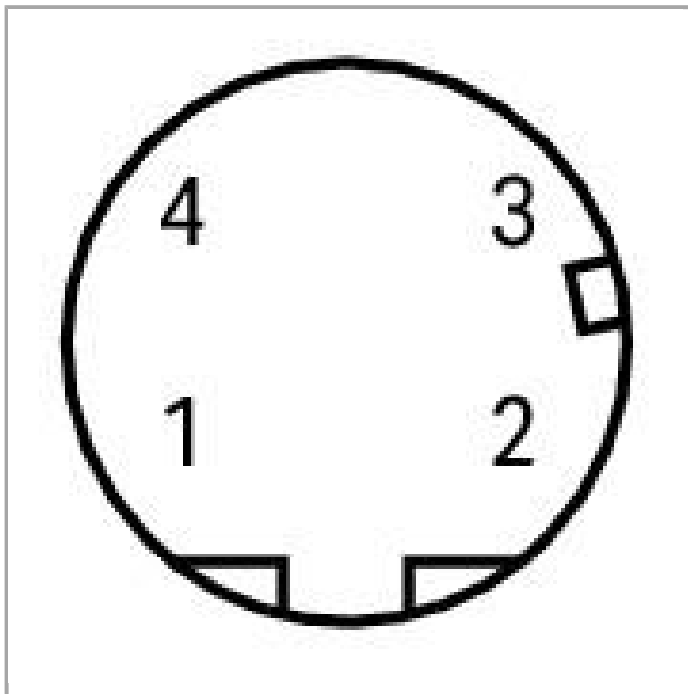

Anschließbare Leitung
Ø 6 ... 8 mm / 0,14 - 0,5 mm²

Data
Technical Data



Connection type	M12 plug
No. of poles	4
Anschlusspunkt geschirmt	yes
Leitungsanschlussrichtung zur Steckrichtung	0°
Steckgesichtskodierung Leitung/Adapter 1 1	D coded

Connection data

Connection type (1)	Federtechnik
Solid conductor	0.14 ... 0.5 mm ² / ...

Mechanical data

Connectable sheathed cable diameter	6 ... 8 mm
Weight	4.3 g

Environmental Requirements

Surrounding air (operating) temperature	-25 ... 85 °C
Degree of protection	IP67

Commercial data

Country of origin	DE
GTIN	4045454639921
Customs Tariff No.	85369010000

Downloads**Documentation****Bid Text**

756-9501/060-000 Zubehör	Oct 6, 2014	DOC 24.1 kB	Download
-----------------------------	-------------	----------------	----------

System Description

767 Series, SPEEDWAY accessories, data sheet	May 16, 2018	1.0 MB	Download
--	--------------	--------	----------

Subject to changes.

WAGO Kontakttechnik GmbH & Co. KG
Hansastr. 27
32423 Minden
Phone: +49571 887-0 | Fax: +49571 887-169
Email: info.de@wago.com | Web: www.wago.com

Do you have any questions about our products?
We are always happy to take your call at +49 (571) 887-44222.