


RoHS Compliant [BOMcheck.net](https://www.bomcheck.net)

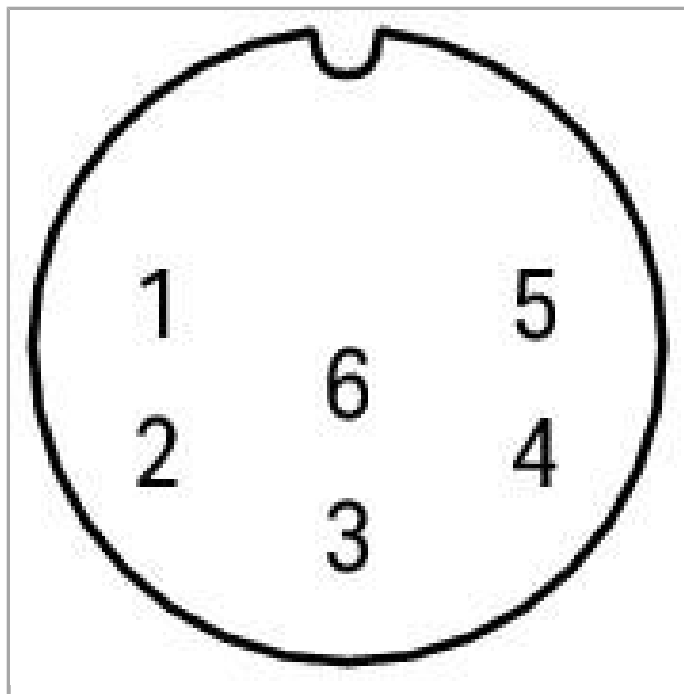

Anschließbare Leitung
Ø 2,0 ... 10,5 mm / max. 2,5 mm²

Data

Technical Data

Connection type	M23 plug
No. of poles	6
Leistungsanschlussrichtung zur Steckrichtung	90°

Connection data

Connection type (1)	Löttechnik
---------------------	------------



Solid conductor	2.5 mm ²
-----------------	---------------------

Mechanical data

Connectable sheathed cable diameter	2 ... 10.5 mm
-------------------------------------	---------------

Weight	142.48 g
--------	----------

Environmental Requirements

Degree of protection	IP67
----------------------	------

Commercial data

Packaging type	bag
----------------	-----

Country of origin	DE
-------------------	----

GTIN	4045454434793
------	---------------

Customs Tariff No.	85444290900
--------------------	-------------

Product Group	23 (I/O passive and accessories)
---------------	----------------------------------

Downloads

Documentation

System Description

767 Series, SPEEDWAY accessories, data sheet	May 16, 2018	1.0 MB	Download
--	--------------	--------	--------------------------

Subject to changes.

WAGO Kontakttechnik GmbH & Co. KG

Hansastr. 27

32423 Minden

Phone: +49571 887-0 | Fax: +49571 887-169

Email: info.de@wago.com | Web: www.wago.com

Do you have any questions about our products?

We are always happy to take your call at +49 (571) 887-44222.