


SYMBOL	DATE	CONTENTS		

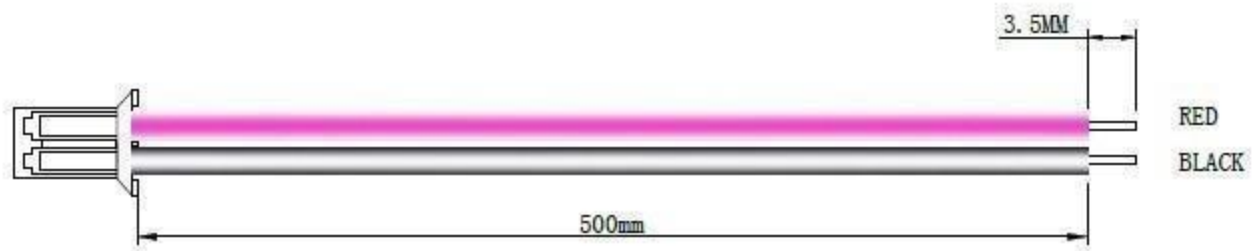

Rated voltage: < 45Vac
Maximum conductor resistance: 45.20Ω
Operating temperature: 80°
Insulation material type: PVC
Flammability type: VW-1

3	WIRE	UL1007 26#SOLDERED 3.5MM DUPORT2.0-2P	PCS	2		
2	HG	PH2.0MM/2P	PCS			
1	TE	PH2.0MM	PCS	1		
			PCS	2		
ITEM	NAME	TYPE/COLOR	UNIT	Q'TY	NADER	DRAWING
PART NAME		CABLE+PULG	MODEL NO: ZTF-2*500-200			
PAET NO		PH2.0MM/2P	PH2.0MM/2P 500MM			

HOLE NO	TERNING	HOUSING	WYRE/COLOR	HOLE NO	TERNING	HOUSING						
A END				B END								