



Polyethylene Spiral Binding with UL94V0 classification

• SBPAV0

Features and Benefits

Due to its flame-retardant additives SBPAV0 spiral binding is self-extinguishing according to UL94 V0. Halogen free, PA6 SBPAV0 spiral binding is easy to install and offers optimal mechanical protection. Multiple cables can be easily bundled. SBPAV0 spiral binding is easy to remove and to re-use.

Application


The use of SBPAV0 spiral binding is particularly suitable for challenging applications, for instance public buildings, the rail and aviation industry and wherever the requirements of UL94 V0 are demanded.



Spiral binding SBPAV0.

Material Data

Material	Polyamide 6 V0 (PA6V0)
Colour	Black (BK)
Operating Temperature	-60 °C to +95 °C, intermittent +130 °C
Flammability	UL94 V0
Specification	UL

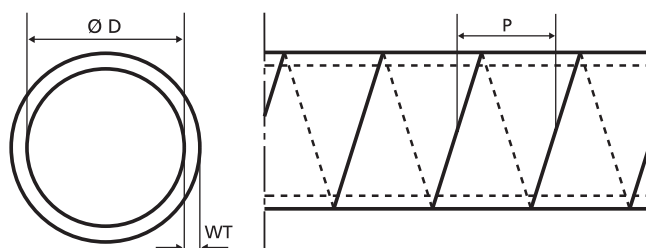

Technical Table

Article-No.	Type	Ø D	Wall (WT)	Pitch (P)	Bundle Ø min.	Bundle Ø max.
SBPAV0 30m lengths						
161-44000	SBPAV01.5	1.5	0.4	6.0	1.6	8.0
161-44100	SBPAV04	4.0	0.6	7.8	5.0	20.0
161-44200	SBPAV09	9.0	1.0	12.5	10.0	100.0
161-44300	SBPAV016	16.0	1.2	16.0	20.0	150.0

All dimensions in mm. Subject to technical changes.



Please note! Not all products listed on this page may have this approval. For product specific approvals please refer to the Appendix.