



Self Adhesive Clips

- RA-Series with round design
- RB-Series with flat design

Features and Benefits


Wires, cables or hoses can be quickly and easily installed using these one piece fixing clips.

Application


These clips are ideal for use in applications which are difficult to access, or for areas where a self adhesive is the only possible fixing method (for example where fixing 'holes' would be unacceptable).



One piece fixing clips Type RA - quick and easy installation.

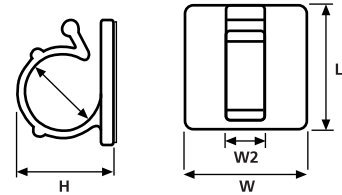

RA3-18 Self Adhesive Clip

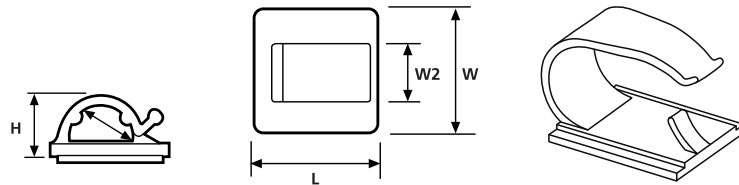

RB5-14 Self Adhesive Clip

For more information on the types of adhesive please turn to page 162.

Material Data	
Material	Polyamide 6.6 (PA66)
Operating Temperature	-40 °C to +85 °C Continuous, (+105 °C for 500 h)
Flammability	UL94 V2 (excluding adhesive)



Material Data	
Material	Polyamide 6.6 High Imp. Mod., Heat Stab. (PA66HIRHS)
Operating Temperature	-40 °C to +105 °C
Flammability	UL94 HB



Technical Table

Article-No.	Type	Length (L)	Width (W)	Width (W2)	Height (H)	Bundle Ø max.	Material	Colour	Adhesive
151-13018	RA3	13.0	13.0	5.0	5.0	3.0	PA66	Natural (NA)	Synthetic rubber
151-13019	RA6	19.0	19.0	5.0	9.0	6.0	PA66	Natural (NA)	Synthetic rubber
151-13020	RA9	19.0	19.0	7.5	12.5	9.0	PA66	Natural (NA)	Synthetic rubber
151-13021	RA13	25.0	25.0	10.0	16.5	13.0	PA66	Natural (NA)	Synthetic rubber
151-13119	RA18	28.5	28.5	10.0	23.0	18.0	PA66	Natural (NA)	Synthetic rubber
151-14059	RB5	19.0	19.0	9.7	6.0	5.0	PA66	Natural (NA)	Synthetic rubber
151-14000	RB5	19.0	19.0	9.7	6.0	5.0	PA66	Black (BK)	Synthetic rubber
151-13606	RB8	25.0	25.0	12.7	11.5	8.0	PA66	Natural (NA)	Synthetic rubber
151-13601	RB8	25.0	25.0	12.7	11.5	8.0	PA66	Black (BK)	Synthetic rubber
151-00505	RB14	33.2	27.4	23.0	16.0	14.0	PA66	Natural (NA)	Synthetic rubber
151-00502	RB14	33.2	27.4	23.0	16.0	14.0	PA66	Black (BK)	Synthetic rubber
151-00831	RB20	33.0	27.0	18.0	25.0	20.0	PA66HIRHS	Black (BK)	Synthetic rubber

All dimensions in mm. Subject to technical changes.