


A B C D E F G H

Contents:

Section	Connector	Stud	d2	W	L	D	d1	Color	Pcs.	
1	Ring Connector	1/4	6.3	12	36.7	5	2.3	Blue	10	
2		1/4	6.4	11.6	34.7	5	1.7	Red	10	
3		1/4	6.3	12	42.8	6	3.5	Yellow	8	
4		#8	4.2	8	29	4.5	1.7	Red	8	
5	Spade Connector	#8	4.2	8.4	38.7	7	3.5	Yellow	8	
6		#10	5.2	8.2	32	5.2	2.3	Blue	10	
7		#8	4.2	6.4	32	5.2	2.3	Blue	10	
8		#8	4.2	6.5	29.5	4.5	1.7	Red	8	
9		1/4	6.3	12	36	4.5	1.7	Red	8	
10	Butt Connector				33.3	4	1.7	Red	8	
11					40.9	6.5	2.3	Yellow	8	
12					34.3	5.6	3.4	Blue	8	

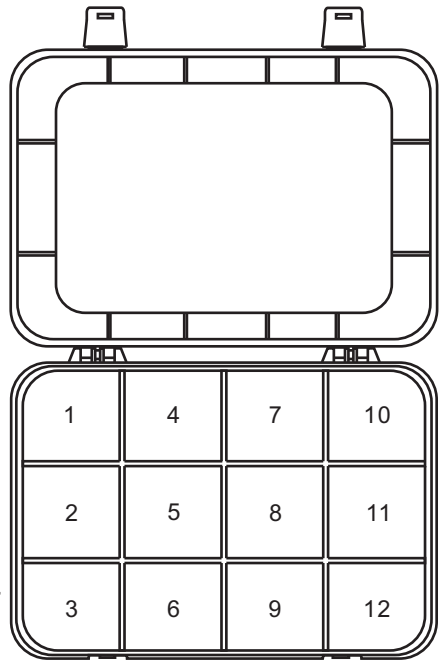

Box ID: BN181934

Specification

Maximum Electric Rating:	600V
Maximum Electric Current	
22-16AWG/0.5-1.5mm <sup>2</sup> :	19A
16-14AWG/1.5-2.5mm <sup>2</sup> :	27A
12-10AWG/4-6mm <sup>2</sup> :	48A
Shrinking Temperature:	≥ 150°C
Operating Temperature:	-40°C ~ 120°C
Shrinking Ratio:	3:1
Terminal Body:	Copper
Insulation:	PE
Plating:	Tin

Hest Shrink Connector kit Set