


Specification / Spezifikation

Model-No / Modell Nr.	RAH1238S1
Dimension / Abmessungen	12 x 120 x 38 mm
Rated Voltage / Nennspannung	230VAC
Operating Voltage / Arbeitsspannung	161 ~ 242 VAC
Frequency / Frequenz	50/60 Hz
Rated Current / Nennstrom	0,20 A
Power / Leistung	23/20 W
Rotating Speed / Umdrehungen	2600/3000 rpm +/- 10%
Airflow / Luftdurchsatz	139,32/163,11 m ³ /h
Static Pressure / Statischer Druck	6,8/8,5 mm H ₂ O
Noise Level / Geräusch	40/43 dBA
Weight / Gewicht	540 g
Material	Frame/Gehäuse: Aluminium Impeller/Lüfterrad: Thermo Plastic
Bearing / Lager	Sleeve Bearing / Gleitlager
Connection / Anschluss	Terminals

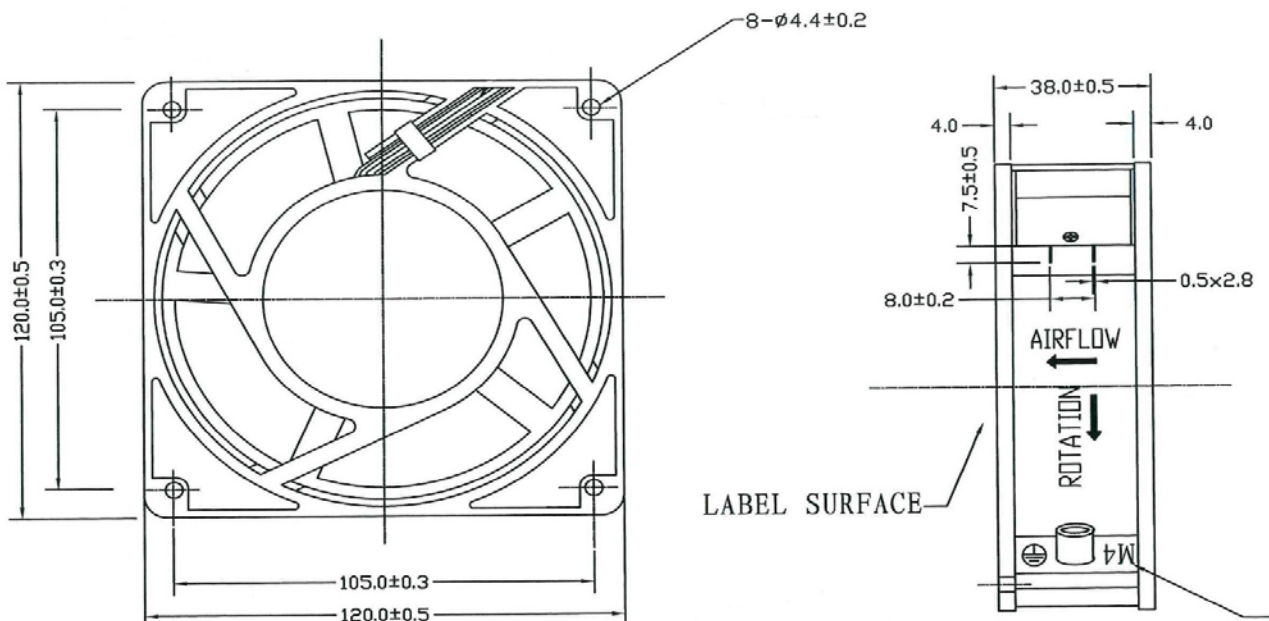

Safety Approvals / Prüfzeichen



Irrtum und Druckfehler vorbehalten / Errors and Omissions excepted