

# ECO LINE A



## WALL / WINDOW AUTOMATIC AXIAL FANS

- Automatic axial fans provided with **electrical internal shutters**, operating via a thermal actuator.
- Delayed and **silent** shutter moving.
- Supplied with warning light, to indicate that the fan is running.
- Window kit available for glazed installation.

### Versions

- ⏱ Timer - Comfortimer **NEW**
- 💧 MHT humidity control
- 🔌 Pull cord switch


### Options

- Ball bearing motor
- Kit for window installation

### SPECIFICATION


| model     | m <sup>3</sup> /h | l/s | Pa | W  | dB(A)<br>@ 3m | protection | marked |
|-----------|-------------------|-----|----|----|---------------|------------|--------|
| ECO 100 A | 90                | 25  | 27 | 13 | 39            | IPX4       | CE Ⓜ   |
| ECO 120 A | 170               | 47  | 40 | 15 | 42            | IPX4       | CE Ⓜ   |
| ECO 150 A | 320               | 89  | 70 | 25 | 49            | IPX4       | CE Ⓜ   |

### DIMENSIONS (mm)

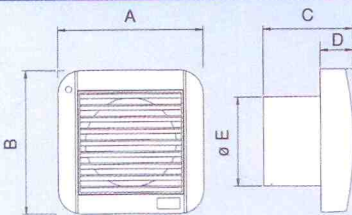


| model     | A   | B   | C   | D  | ø E | Kg. |
|-----------|-----|-----|-----|----|-----|-----|
| ECO 100 A | 155 | 155 | 101 | 44 | 97  | 0,6 |
| ECO 120 A | 180 | 180 | 121 | 51 | 119 | 0,8 |
| ECO 150 A | 209 | 209 | 137 | 52 | 149 | 1,2 |

### CURVES

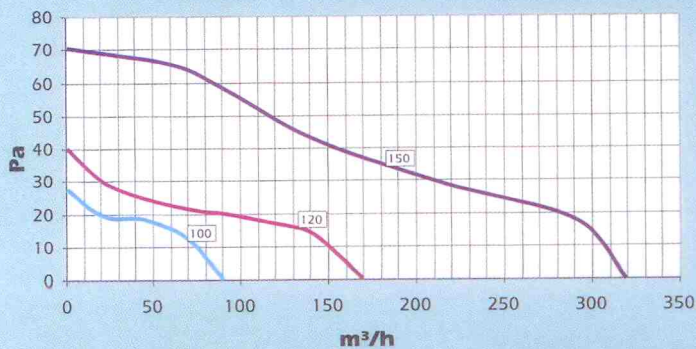


Accessories and controllers: see pages 63/69


### APPLICATIONS

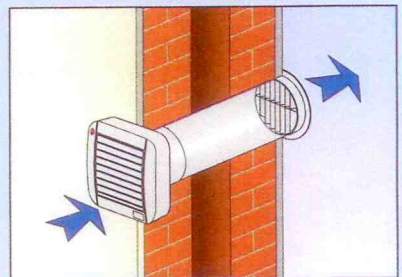

WALL

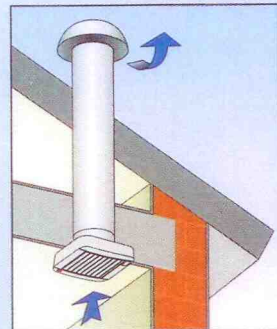

CEILING

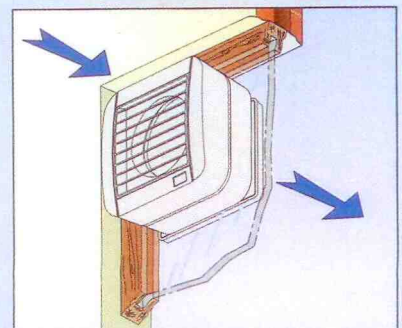


WINDOW

Max glass thickness 22 mm.

Wiring can be surfaced or recessed


## DIMENSIONS (mm)

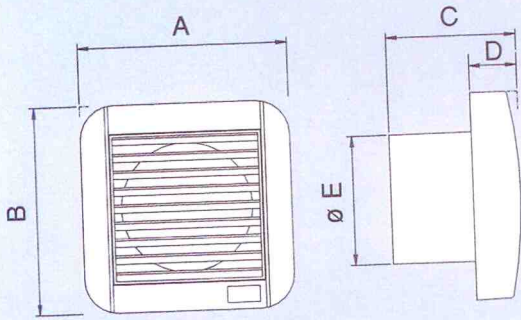


| model   | A   | B   | C   | D  | Ø E | Kg. |
|---------|-----|-----|-----|----|-----|-----|
| ECO 100 | 155 | 155 | 92  | 35 | 97  | 0,5 |
| ECO 120 | 180 | 180 | 121 | 51 | 119 | 0,8 |
| ECO 150 | 209 | 209 | 137 | 52 | 149 | 1,2 |

## CURVES

ECO 100/120/150 GF

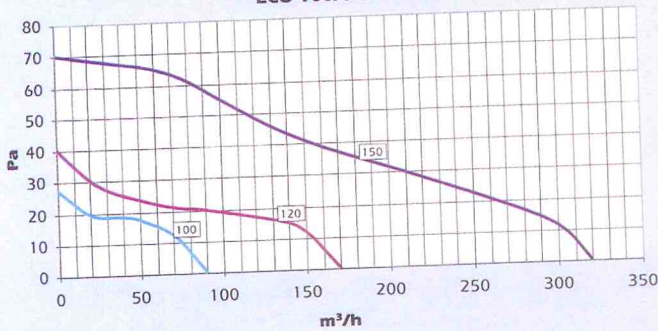


ECO 100/120/150 GG

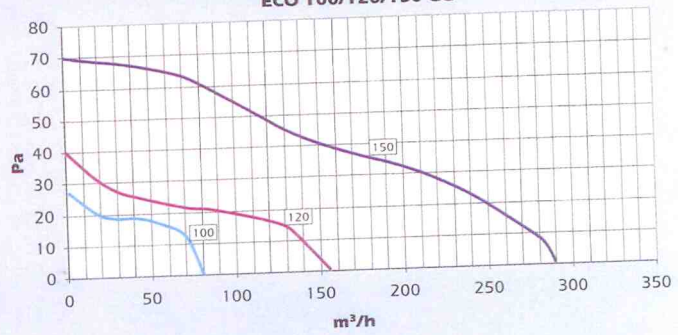


## APPLICATIONS


WALL

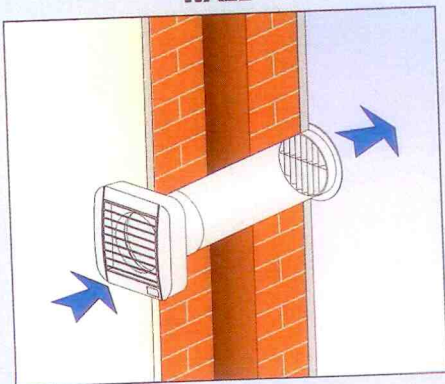

CEILING

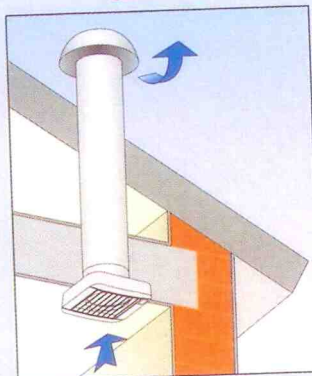

WINDOW

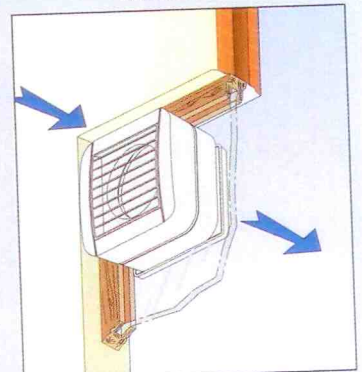

Max glass thickness 22 mm.

Wiring can be surfaced or recessed.