


Available on request:  
220-240 V/~60 Hz  
110-120

**CABO FRIO NB #24235**  
housing new bronze, coffee beech  
composite blades

- weatherproof composite blades
  - humidity resistant, stainless housing
  - silent running
  - for use in covered applications
- Suitable for damp ambient air!**

**15 YEARS LIMITED MOTOR WARRANTY**

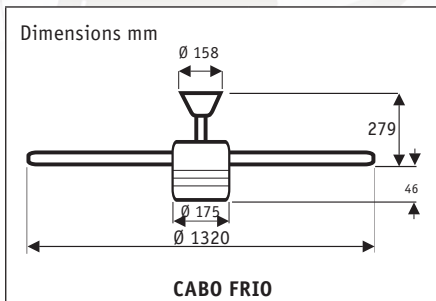

No. of blades	3
Power motor (W)	15 - 72
Voltage (V/Hz)	220-240/~50
Size Ø (cm/")	132/52
No. of speeds (w. W/C)	3
Rotation max. (RPM)	190
Weight (kg)	9.2

**Installation:** 2 screws Ø min. 4.5 mm separation 64 - 95 mm

### Perfect for humid environments

- Humidity resistant and stainless.
- Forward/reverse slide switch.
- Balanced motor and blades.
- Installation on sloped ceilings (up to 22°).

### Options:

- Optional controls (pages 116-119).
- Longer downrods for high ceilings available (page 124).

**3-speed wall control** included.



Product	Code No.	Housing Finish	Blades
CABO FRIO NB	24235	New bronze	Composite coffee beech
CABO FRIO WE	24234	White coated	Composite whit
CABO FRIO ZA	24238	Antique pewter	Composite antique black