

Data Sheet


Dynamo Light LED

17680



Designation:	17680 101 401
Battery Requirement:	3.6V 120mAh Li-ion rechargeable battery
Bulb required:	3pcs Kee Tat 5MM WHITE LED
Luminous intensity:	28 lumens or 170 cd
Range:	26 m (calculated distance at maximum luminous intensity with an illuminance of 0.25 lux).
Weight:	145g (with batteries).

Material: ABS (Acrylonitrile-Butadiene-Styrene)
PC (Polycarbonate)
TPR(Thermoplastic Rubber)
All contact parts made of bronze or nickel plated steel.

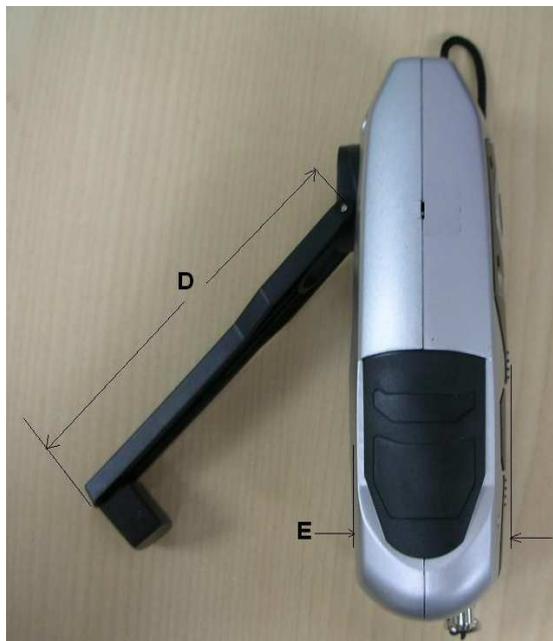

Dimensions (mm):	A	142.5
	B	51.5
	C	185
	D	101.5
	E	42.3

Features (Technical)

Crank for charging with LED indicator
CE approval
Push switch (on/off)
Lanyard