

Ground modular terminal block - ST 2,5-QUATTRO/2P-PE - 3040041

Please be informed that the data shown in this PDF Document is generated from our Online Catalog. Please find the complete data in the user's documentation. Our General Terms of Use for Downloads are valid (<http://download.phoenixcontact.com>)



Ground modular terminal block, Connection method: Spring-cage/plug-in connection, Cross section: 0.08 mm² - 4 mm², AWG: 28 - 12, Width: 5.2 mm, Color: green-yellow, Mounting type: NS 35/7,5, NS 35/15

Product Features

- ✓ Same shape and pitch as the basic terminal blocks
- ✓ Tested for railway applications

Key commercial data

package_quantity	50
GTIN	4017918832643

Technical data

General

Number of levels	1
Number of connections	4
Color	green-yellow
Insulating material	PA
Inflammability class according to UL 94	V0
Area of application	Railway industry
Area of application	Mechanical engineering
Area of application	Plant engineering

General

Rated surge voltage	6 kV
Pollution degree	3
Surge voltage category	III
Insulating material group	I
Connection in acc. with standard	IEC 61984
Open side panel	ja

Dimensions

Width	5.2 mm
Length	81 mm
Height NS 35/7,5	36.5 mm

Ground modular terminal block - ST 2,5-QUATTRO/2P-PE - 3040041

Technical data

Dimensions

Height NS 35/15	44 mm
-----------------	-------

Connection data

Conductor cross section solid min.	0.08 mm ²
Conductor cross section solid max.	4 mm ²
Conductor cross section AWG/kcmil min.	28
Conductor cross section AWG/kcmil max	12
Conductor cross section stranded min.	0.08 mm ²
Conductor cross section stranded max.	2.5 mm ²
Min. AWG conductor cross section, stranded	28
Max. AWG conductor cross section, stranded	14
Conductor cross section stranded, with ferrule without plastic sleeve min.	0.14 mm ²
Conductor cross section stranded, with ferrule without plastic sleeve max.	2.5 mm ²
Conductor cross section stranded, with ferrule with plastic sleeve min.	0.14 mm ²
Conductor cross section stranded, with ferrule with plastic sleeve max.	2.5 mm ²
2 conductors with same cross section, stranded, TWIN ferrules with plastic sleeve, max.	0.5 mm ²
Connection method	Spring-cage/plug-in connection
Minimum stripping length	8 mm
Maximum stripping length	10 mm
Internal cylindrical gage	A3

classifications

eCl@ss

eCl@ss 4.0	27141118
eCl@ss 4.1	27141118
eCl@ss 5.0	27141118
eCl@ss 5.1	27141118
eCl@ss 6.0	27141141
eCl@ss 7.0	27141141
eCl@ss 8.0	27141141

ETIM

ETIM 2.0	EC000901
ETIM 3.0	EC000901
ETIM 4.0	EC000901
ETIM 5.0	EC000901

UNSPSC

Ground modular terminal block - ST 2,5-QUATTRO/2P-PE - 3040041

classifications

UNSPSC

UNSPSC 6.01	30211811
UNSPSC 7.0901	39121410
UNSPSC 11	39121410
UNSPSC 12.01	39121410
UNSPSC 13.2	39121410

approvals

CSA / UL Recognized / cUL Recognized / GOST / LR / GL / BV / DNV / RS / IECEx CB Scheme / GOST / cULus Recognized /

Approval details

CSA 	
Nominal voltage UN	
Nominal current IN	
mm²/AWG/kcmil	28-12

UL Recognized 	
Nominal voltage UN	
Nominal current IN	
mm²/AWG/kcmil	28-12

cUL Recognized 	
Nominal voltage UN	
Nominal current IN	
mm²/AWG/kcmil	28-12

GOST 	
---	--

Ground modular terminal block - ST 2,5-QUATTRO/2P-
PE - 3040041

approvals

LR

GL

BV

DNV

RS

IECEE CB Scheme 	
Nominal voltage UN	500 V
Nominal current IN	
mm²/AWG/kcmil	0.2-4



accessories

End cover

D-ST 2,5-QUATTRO/ 2P - 3040083



Ground modular terminal block - ST 2,5-QUATTRO/2P- PE - 3040041

accessories

DS-ST 4/P - 3043750



DP PS-5 - 3036725



Partition plate

ATP-ST QUATTRO - 3030815



Coding element

PC - 3040588



Screwdriver tools

SZF 1-0,6X3,5 - 1204517



Ground modular terminal block - ST 2,5-QUATTRO/2P- PE - 3040041

accessories

Labeled terminal marker

WST 2,5 - 3030941



ZB 5 CUS - 0824962



UC-TM 5 CUS - 0824581



UCT-TM 5 CUS - 0829595



ZBF 5 CUS - 0825025



Ground modular terminal block - ST 2,5-QUATTRO/2P- PE - 3040041

accessories

UC-TMF 5 CUS - 0824638



UCT-TMF 5 CUS - 0829658



Flange

ST 2,5-QUATTRO/2P-F - 3209853



ST 2,5-QUATTRO/2P-FS - 3061392



Documentation

ST-IL - 3039900



Ground modular terminal block - ST 2,5-QUATTRO/2P- PE - 3040041

accessories

Mounting rail

NS 35/ 7,5 PERF 2000MM - 0801733



NS 35/ 7,5 UNPERF 2000MM - 0801681



NS 35/ 7,5 WH PERF 2000MM - 1204119



NS 35/ 7,5 WH UNPERF 2000MM - 1204122



NS 35/ 7,5 AL UNPERF 2000MM - 0801704



Ground modular terminal block - ST 2,5-QUATTRO/2P-PE - 3040041

accessories

NS 35/ 7,5 ZN PERF 2000MM - 1206421



NS 35/ 7,5 ZN UNPERF 2000MM - 1206434



NS 35/ 7,5 CU UNPERF 2000MM - 0801762



NS 35/ 7,5 CAP - 1206560



Terminal marking

ZB 5 :UNBEDRUCKT - 1050004



Ground modular terminal block - ST 2,5-QUATTRO/2P- PE - 3040041

accessories

UC-TM 5 - 0818108



UCT-TM 5 - 0828734



ZBF 5:UNBEDRUCKT - 0808642



UC-TMF 5 - 0818153



UCT-TMF 5 - 0828744



Test plug terminal block

Ground modular terminal block - ST 2,5-QUATTRO/2P- PE - 3040041

accessories

MPS-MT - 0201744



PAI-4-FIX-5/6 BU - 3035975



PAI-4-FIX-5/6 OG - 3035974



PAI-4-FIX-5/6 YE - 3035977



PAI-4-FIX-5/6 RD - 3035976



Ground modular terminal block - ST 2,5-QUATTRO/2P- PE - 3040041

accessories

PAI-4-FIX-5/6 GN - 3035978



PAI-4-FIX-5/6 BK - 3035980



PAI-4-FIX-5/6 GY - 3035982



PAI-4-FIX-5/6 VT - 3035979



PAI-4-FIX-5/6 BN - 3035981



Ground modular terminal block - ST 2,5-QUATTRO/2P-PE - 3040041

accessories

PS-5 - 3030983



PS-5/2,3MM RD - 3038723



Insulating sleeve

MPS-IH WH - 0201663



MPS-IH RD - 0201676



MPS-IH BU - 0201689



Ground modular terminal block - ST 2,5-QUATTRO/2P-PE - 3040041

accessories

MPS-IH YE - 0201692



MPS-IH GN - 0201702



MPS-IH GY - 0201728



MPS-IH BK - 0201731



ISH 2,5/0,2 - 3002843



Ground modular terminal block - ST 2,5-QUATTRO/2P-PE - 3040041

accessories

ISH 2,5/0,5 - 3002856




ISH 2,5/1,0 - 3002869



Drawings


Diagram

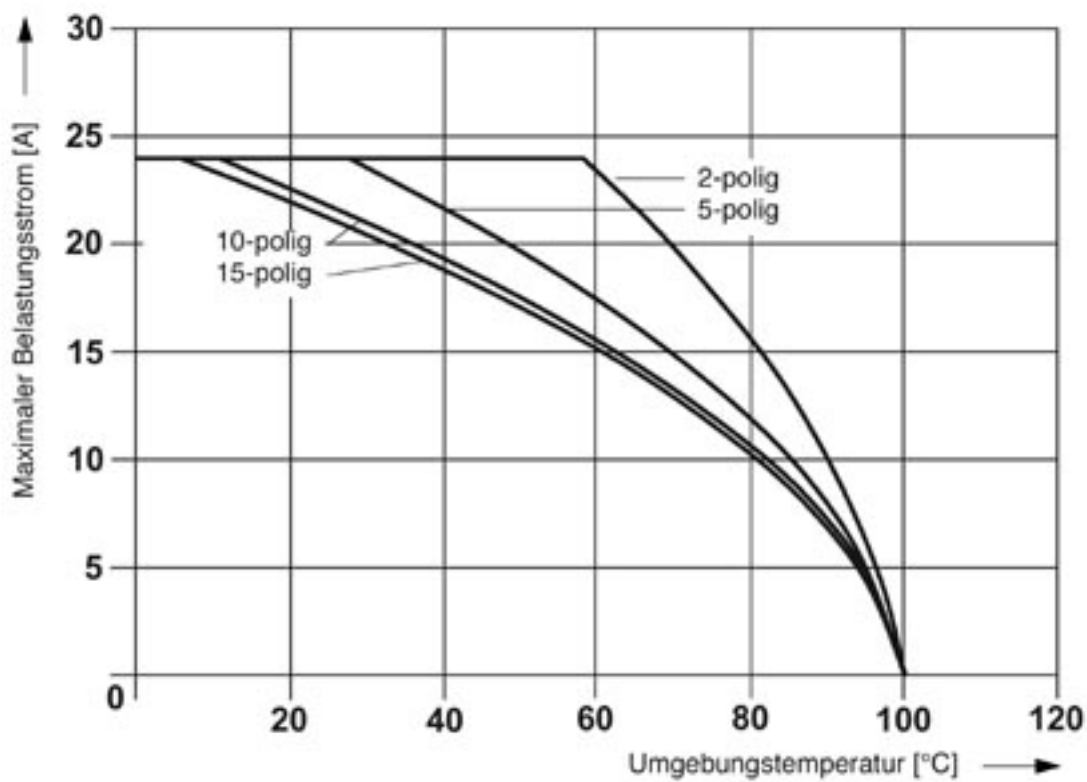

Applies to all male connector variants SP...

Ground modular terminal block - ST 2,5-QUATTRO/2P- PE - 3040041

Circuit diagram

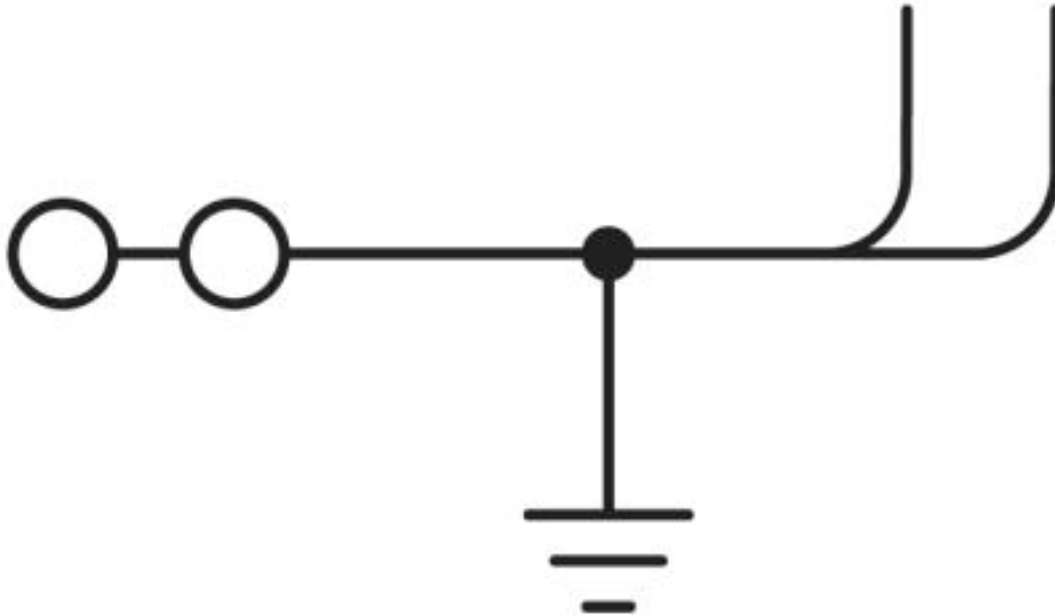

© Phoenix Contact 2013 - all rights reserved
<http://www.phoenixcontact.com>