

Accessories - MCC-MT 0,2-0,35 - 1859988

Please be informed that the data shown in this PDF Document is generated from our Online Catalog. Please find the complete data in the user's documentation. Our General Terms of Use for Downloads are valid (<http://download.phoenixcontact.com>)



Female contact, is inserted into the plug after crimping the conductor, for the module plug housing MCC 1...-STZ-3,81 and MCC 1...-STZF-3,81, for cross sections of 0.2 mm² to 0.34 mm²

Key commercial data

package_quantity	100
GTIN	4017918109721

Technical data

General

Nominal current	4 A
Conductor cross section stranded min.	0.2 mm²
Max. conductor cross section, stranded	0.35 mm²

Connection data

Core diameter including insulation	1.1 mm ... 1.3 mm
Stripping length of individual wires	4 mm

classifications

eCl@ss

eCl@ss 4.0	272607xx
eCl@ss 4.1	27260701
eCl@ss 5.0	27260701
eCl@ss 5.1	27260701
eCl@ss 6.0	27260704
eCl@ss 7.0	27440402
eCl@ss 8.0	27440402

ETIM

ETIM 3.0	EC001121
ETIM 4.0	EC001121
ETIM 5.0	EC002641

UNSPSC

UNSPSC 6.01	30211810
UNSPSC 7.0901	39121410

Accessories - MCC-MT 0,2-0,35 - 1859988

classifications

UNSPSC

UNSPSC 11	39121409
UNSPSC 12.01	39121409
UNSPSC 13.2	39121409

approvals

GOST /


Approval details



Drawings

Accessories - MCC-MT 0,2-0,35 - 1859988

Dimensioned drawing

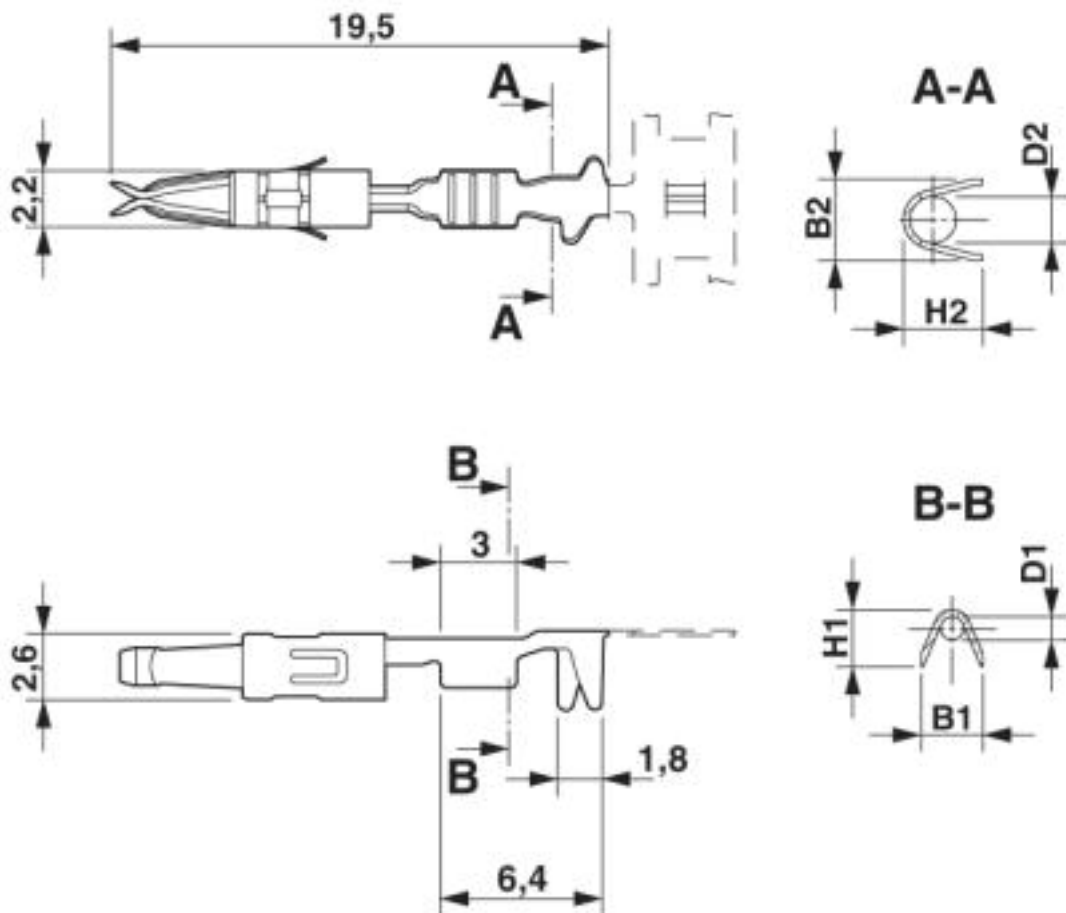

© Phoenix Contact 2013 - all rights reserved
<http://www.phoenixcontact.com>