

Accessories - MSTBC-MT 0,5-1,0 - 3190564

Please be informed that the data shown in this PDF Document is generated from our Online Catalog. Please find the complete data in the user's documentation. Our General Terms of Use for Downloads are valid (<http://download.phoenixcontact.com>)



Module female contact, is inserted into the plug housing MSTBC after crimping the conductor, for conductors from 0.5 to 1.0 mm²

Key commercial data

package_quantity	100
GTIN	4017918093396

Technical data

General

Nominal current	12 A (with 1 mm ² conductor cross section)
Conductor cross section stranded min.	0.5 mm ²
Max. conductor cross section, stranded	1 mm ²

Connection data

Core diameter including insulation	1.4 mm ... 2.31 mm
Stripping length of individual wires	3.5 mm

Material data

Contact material	CuFe
Contact surface material	Tin-plated

classifications

eCl@ss

eCl@ss 4.0	272607xx
eCl@ss 4.1	27260701
eCl@ss 5.0	27260701
eCl@ss 5.1	27260701
eCl@ss 6.0	27260704
eCl@ss 7.0	27440402
eCl@ss 8.0	27440402

ETIM

ETIM 3.0	EC001121
ETIM 4.0	EC001121
ETIM 5.0	EC002641

Accessories - MSTBC-MT 0,5-1,0 - 3190564

classifications

UNSPSC

UNSPSC 6.01	30211810
UNSPSC 7.0901	39121410
UNSPSC 11	39121409
UNSPSC 12.01	39121409
UNSPSC 13.2	39121409

approvals

GOST /

Approval details



accessories

Crimping tool


CRIMPFOX MT 2,5 - 1204038



Drawings

Accessories - MSTBC-MT 0,5-1,0 - 3190564

Dimensioned drawing

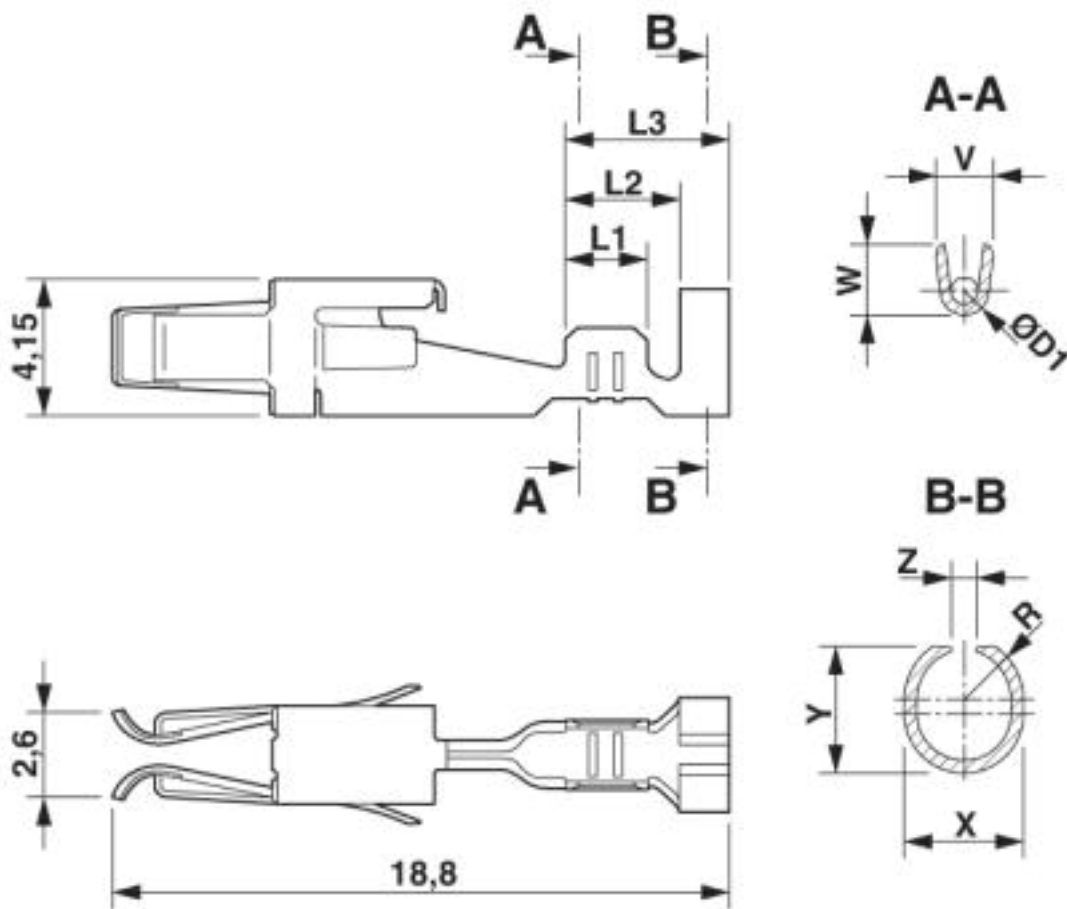

© Phoenix Contact 2013 - all rights reserved
<http://www.phoenixcontact.com>