


254/TS
254/TS-SN

254/TC
254/TC-SN

G13


2A-250V

T130
Tm110

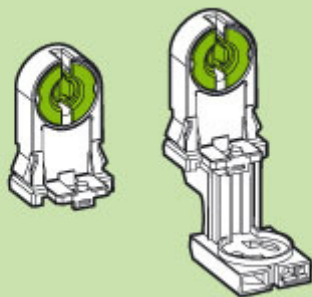


IP20 LAMPHOLDERS



- Polycarbonate body
- Copper alloy/brass contacts

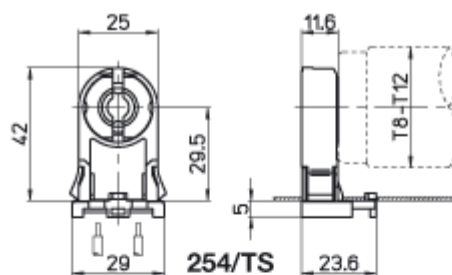

254/TS


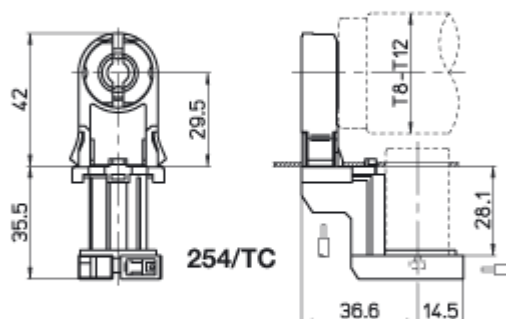


254/TC

 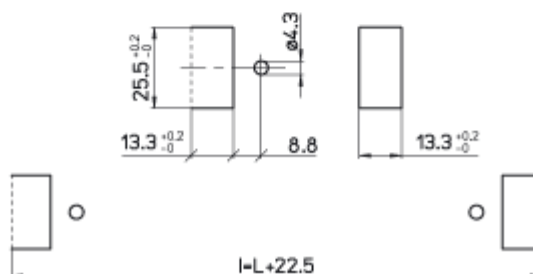


.../T

  ...-SN




Legend

AUTOMATIC FIXING

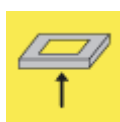


push-through fixing

 CHARACTERISTICS




metal plate thickness

 

lamp centre height (from the bottom of the metal plate)



 
suitable only for fixing into 13,3x25,5 mm holes




without stop nib



 PBT green rotor with position of...



rigid conductor section

 

rigid wires stripping

TERMINALS



push-wire terminals with 2 holes