

BLB Fluorescent Tubes


Application:

Disco-Lighting / Effect Lighting

F36T8/BLB

Fluorescent Tube T8 36W BLB

Wavelength 350nm

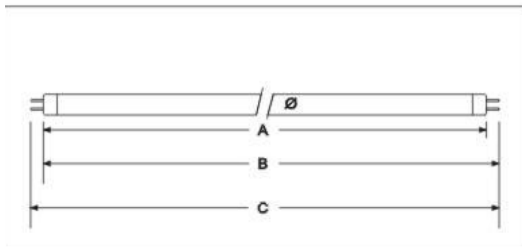

Type	A	B	B	C	Ø	Measurement of Carton(cm)	Pcs
	Max(mm)	Max(mm)	Min(mm)	Max(mm)			
10W	331.3	338.4	335.8	345.5	26	57.5X36.5X31	200
15W	437.4	444.5	442.1	451.6	26	47X30.5X31	100
18W	589.8	596.9	594.5	604.0	26	62.5X30.5X31	100
30W	894.6	901.7	899.3	908.8	26	93.5X15X15	25
36W	1199.4	1206.5	1204.1	1213.6	26	124X15X15	25
58W	1500.0	1507.1	1504.70	1514.20	26	153X16X16.5	25

Type	Watt (W)	Current (A)	Lamp Voltage			UV-Airradiance Be apart from one meter(μ w/cm ²)
			Min(v)	Rating	Max(v)	
10W/BLB	10	0.220	44	52	60	\geq 6.5
15W/BLB	15	0.310	46	55	64	\geq 9.5
18W/BLB	18	0.370	50	57	64	\geq 12.5
30W/BLB	30	0.365	86	96	106	\geq 13.5
36W/BLB	36	0.430	93	103	113	\geq 14.5
58W/BLB	58	0.670	100	110	120	\geq 15.3