


Technische Daten

Technical data

Betriebstemperatur	max. +150°C
Betriebsdruck	bis 60bar
Werkstoffe	Messing (Ms58) vernickelt und blank
Gewinde	DIN 3852 DIN 3858
Medium	Luft, Wasser, Öl, Dampf, etc.

Fittings

Operating temperature	Max +150°C
Operating pressure	Up to 60 bar
Materials	Brass (Ms58) nickel-plated and polished
Thread	DIN 3852 DIN 3858
Medium	Air, water, oil, steam, etc.

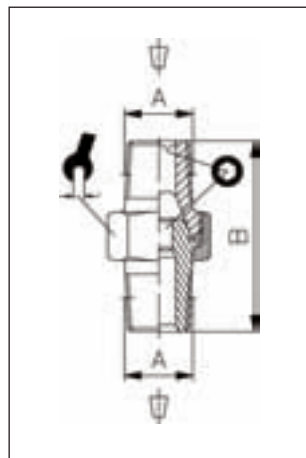

Doppelnippel lösbar - blank, kon.
Double nipple con. detachable

	A	B	Ø			
306002	R ^{1/8}	27	5,3	15	5	25
306004	R ^{1/4}	34	6,3	19	6	25
306006	R ^{3/8}	36	8,5	22	8	10
306008	R ^{1/2}	40	13	27	12	10
306010	R ^{3/4}	52	15	36	14	10
306012	R1	65	20	46	19	5
306014	R ^{1/8} -R ^{1/4}	30	5,3	15	5	5
306015	R ^{1/4} -R ^{3/8}	35	6,3	19	6	5