

Docking frames - HC-B 16-ANDOCK - 1586138

Please be informed that the data shown in this PDF Document is generated from our Online Catalog. Please find the complete data in the user's documentation. Our General Terms of Use for Downloads are valid (<http://download.phoenixcontact.com>)



Docking frame for racks, for contact inserts of B16 type, with four M5 flat headed screws, rack balance x/y axis +/- 1.5 mm

Key commercial data

package_quantity	1
GTIN	4046356345729

Technical data

General

Material	High-grade steel
----------	------------------

classifications

eCl@ss

eCl@ss 4.0	272607xx
eCl@ss 4.1	27260701
eCl@ss 5.0	27189207
eCl@ss 5.1	27189207
eCl@ss 6.0	27143424
eCl@ss 7.0	27440209
eCl@ss 8.0	27440209

ETIM

ETIM 3.0	EC002310
ETIM 4.0	EC002310
ETIM 5.0	EC002310

UNSPSC

UNSPSC 6.01	30211817
UNSPSC 7.0901	39121416
UNSPSC 11	43172601
UNSPSC 12.01	39121522
UNSPSC 13.2	39121522

Docking frames - HC-B 16-ANDOCK - 1586138

approvals


GOST /

Approval details

GOST 

Drawings


Dimensioned drawing

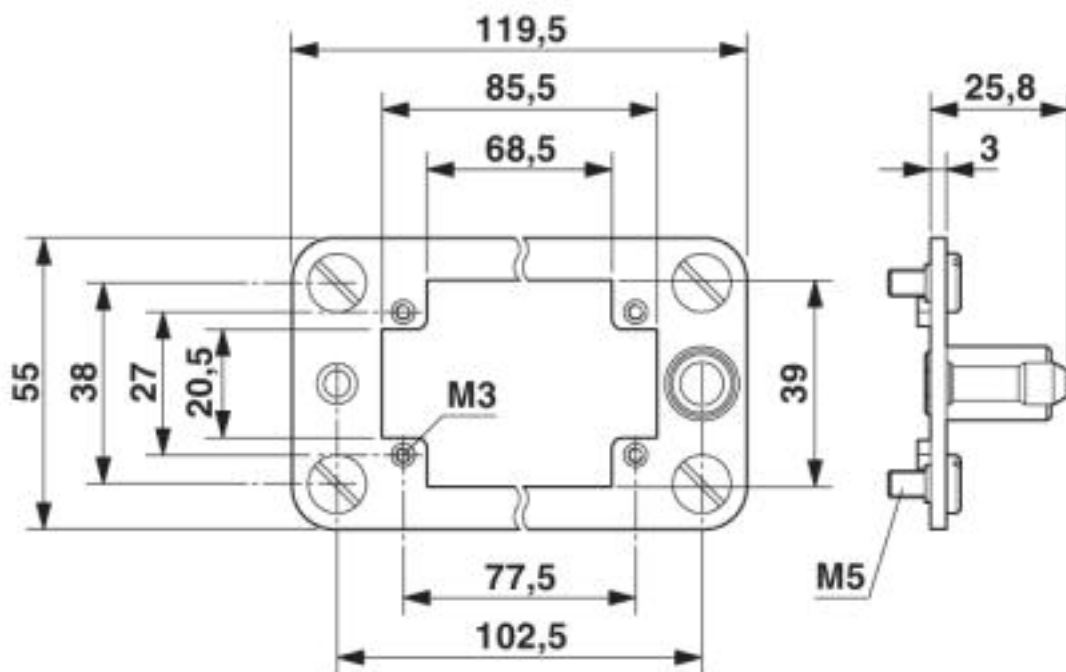

Dimensional drawing


Docking frames - HC-B 16-ANDOCK - 1586138

Dimensioned drawing

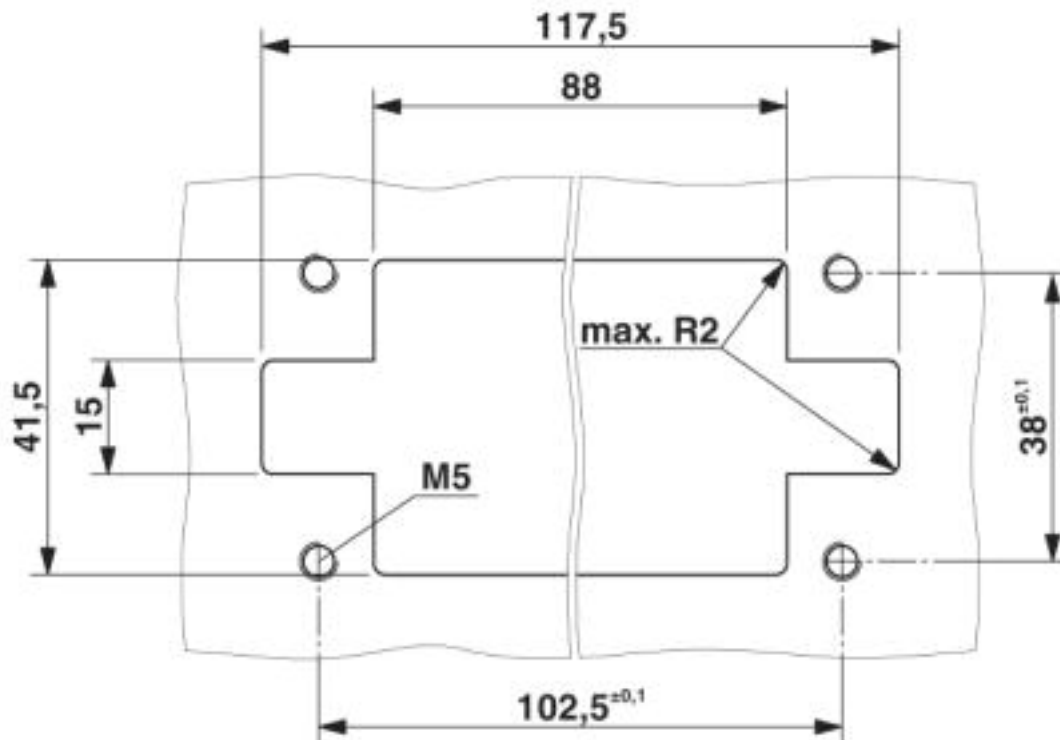

Panel cutout

Dimensioned drawing

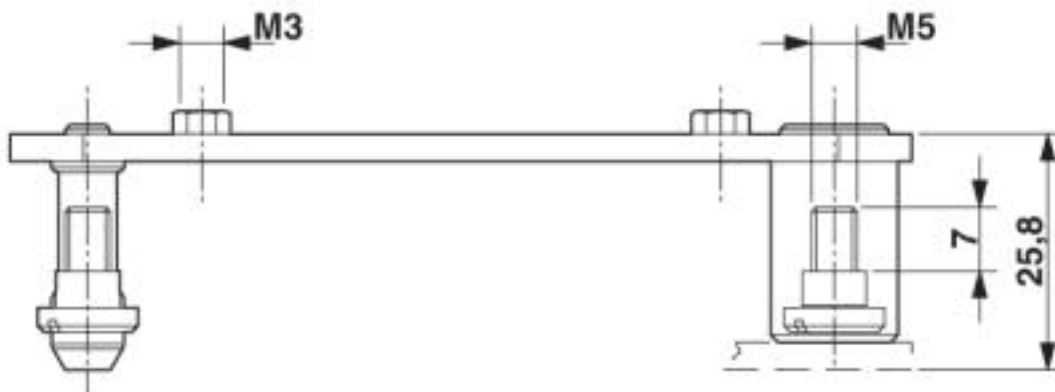

max. dimensions of both the docking frames (in case of standard contacts 25.8 mm; in case of fiber optics contacts 27 mm; in case of pneumatic contacts 26.5 mm)

© Phoenix Contact 2013 - all rights reserved
<http://www.phoenixcontact.com>