

## Flush-type connector - SACC-SQ-M12MSB-5CON-25F/0,5 - 1440999

Please be informed that the data shown in this PDF Document is generated from our Online Catalog. Please find the complete data in the user's documentation. Our General Terms of Use for Downloads are valid (<http://download.phoenixcontact.com>)



Sensor/actuator flush-type plug, 5-pos., M12, B-coded, front/square flange mounting, with 0.5 m TPE litz wire, 5 x 0.34 mm<sup>2</sup>

### Product Features

- ✓ 4 x fixing hole, 2.7 mm
- ✓ With form seal for M2.5 screws



### Key commercial data

|                  |               |
|------------------|---------------|
| package_quantity | 1             |
| GTIN             | 4046356533850 |

### Technical data

#### Dimensions

|                 |       |
|-----------------|-------|
| Length of cable | 0.5 m |
|-----------------|-------|

#### Ambient conditions

|                                 |                                  |
|---------------------------------|----------------------------------|
| Ambient temperature (operation) | -25 °C ... 85 °C (Plug / socket) |
| Degree of protection            | IP67                             |

#### General

|                        |                               |
|------------------------|-------------------------------|
| Rated current at 40 °C | 4 A                           |
| Rated voltage          | 60 V                          |
| Number of positions    | 5                             |
| Contact resistance     | ≤ 3 mΩ                        |
| Insulation resistance  | ≥ 100 MΩ                      |
| Coding                 | B - inverse                   |
| Standards/regulations  | M12 connector IEC 61076-2-101 |
| Status display         | No                            |
| Surge voltage category | II                            |
| Pollution degree       | 3                             |
| Connection method      | Individual wires              |
| Mounting type          | Front mounting Square flange  |

# Flush-type connector - SACC-SQ-M12MSB-5CON-25F/0,5 - 1440999

## Technical data

### Material

|                                         |                              |
|-----------------------------------------|------------------------------|
| Inflammability class according to UL 94 | V0                           |
| Contact material                        | CuZn                         |
| Contact surface material                | Ni/Au                        |
| Contact carrier material                | PA 66                        |
| Material, knurls                        | Zinc die-cast, nickel-plated |
| Sealing material                        | NBR                          |

### Cable

|                                 |                                              |
|---------------------------------|----------------------------------------------|
| Cable type                      | TPE litz wire                                |
| Conductor cross section         | 0.34 mm²                                     |
| AWG signal line                 | 22                                           |
| Wire colors                     | Brown, white, blue, black, gray              |
| Conductor material              | Tin-plated Cu litz wires                     |
| Ambient temperature (operation) | -25 °C ... 90 °C (cable, fixed installation) |

## classifications

### eCl@ss

|            |          |
|------------|----------|
| eCl@ss 4.0 | 27140815 |
| eCl@ss 4.1 | 27140815 |
| eCl@ss 5.0 | 27143423 |
| eCl@ss 5.1 | 27143423 |
| eCl@ss 6.0 | 27279220 |
| eCl@ss 7.0 | 27440103 |
| eCl@ss 8.0 | 27440103 |

### ETIM

|          |          |
|----------|----------|
| ETIM 2.0 | EC001297 |
| ETIM 3.0 | EC002061 |
| ETIM 4.0 | EC002061 |
| ETIM 5.0 | EC002061 |

### UNSPSC

|               |          |
|---------------|----------|
| UNSPSC 6.01   | 31251501 |
| UNSPSC 7.0901 | 31251501 |
| UNSPSC 11     | 31251501 |
| UNSPSC 12.01  | 31251501 |
| UNSPSC 13.2   | 39121413 |

## approvals

Flush-type connector - SACC-SQ-M12MSB-5CON-25F/0,5 - 1440999

approvals

Approval details


|                                                                                                 |       |
|-------------------------------------------------------------------------------------------------|-------|
| UL Recognized  |       |
| Nominal voltage UN                                                                              | 60 V  |
| Nominal current IN                                                                              | 4 A   |
| mm²/AWG/kcmil                                                                                   | 26-20 |

GOST 



Drawings


Dimensioned drawing

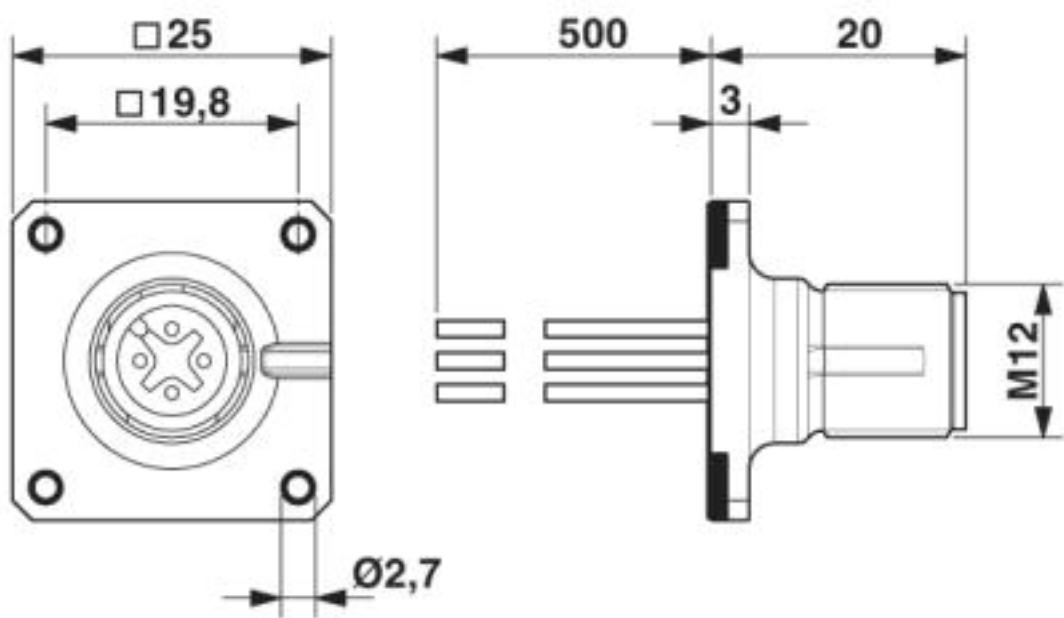

M12 flush-type plug

## Flush-type connector - SACC-SQ-M12MSB-5CON-25F/0,5 - 1440999


Circuit diagram

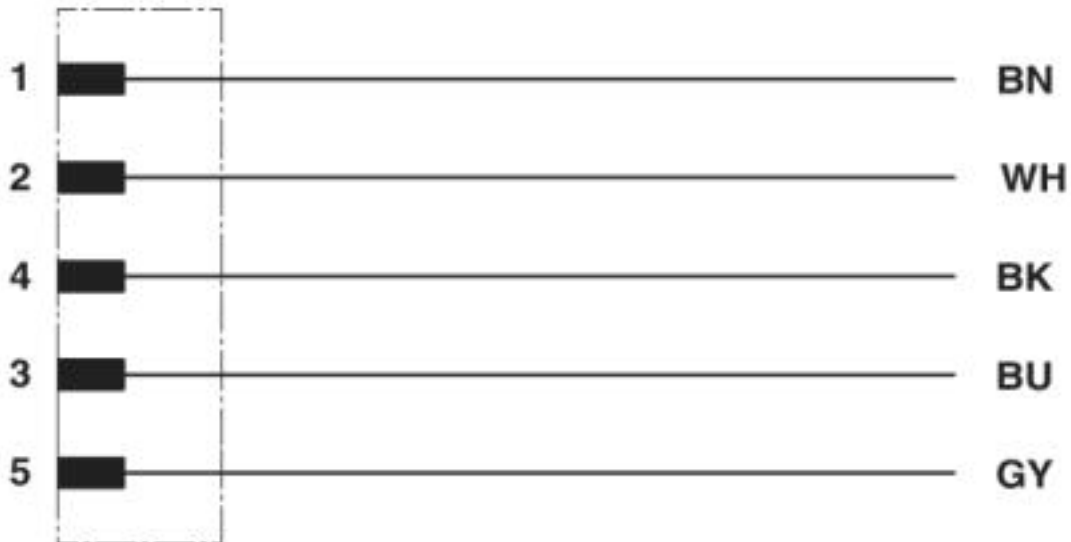

Contact assignment of the M12 plug and the M12 socket

## Flush-type connector - SACC-SQ-M12MSB-5CON-25F/0,5 - 1440999

Schematic diagram

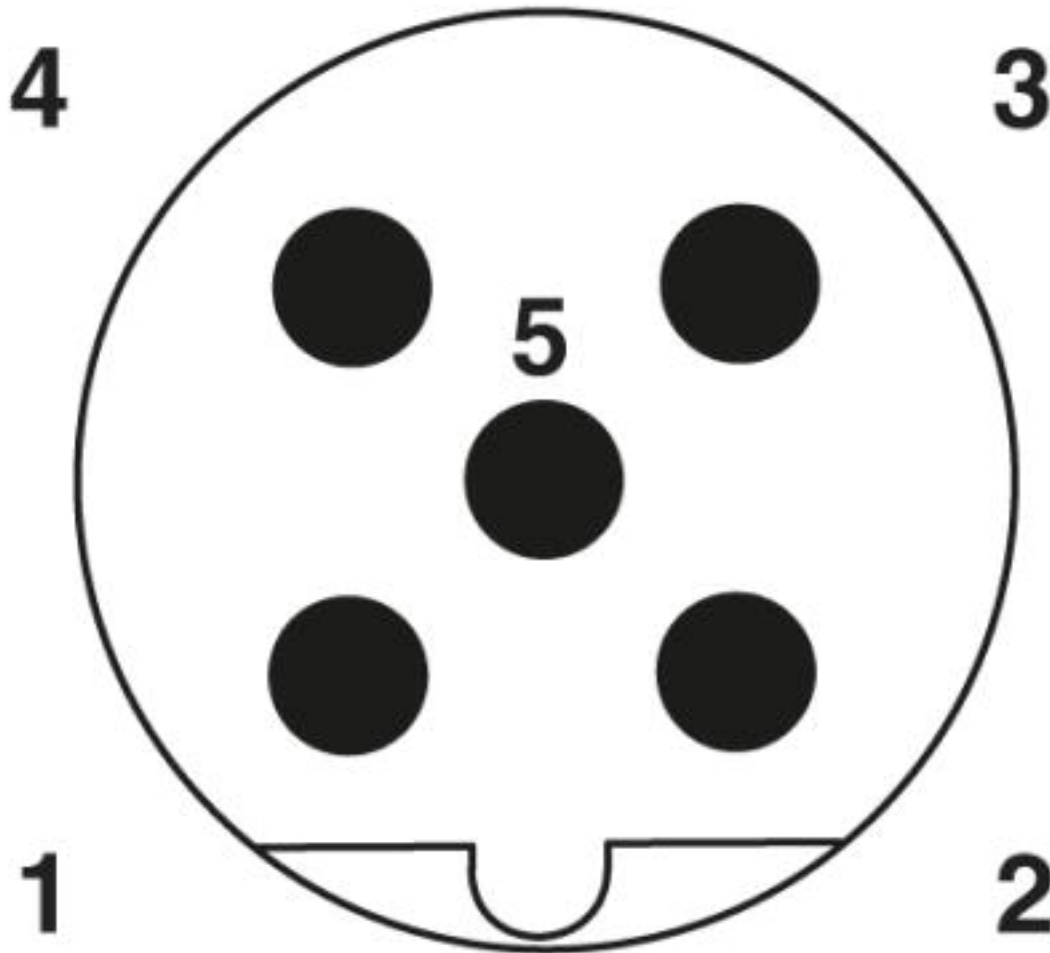

Pin assignment M12 male connector, 5-pos., B-coded, male side

© Phoenix Contact 2013 - all rights reserved  
<http://www.phoenixcontact.com>