

# Housing - HC-B 6-TMB-100/O1STM25G-EEE - 1460363

Please be informed that the data shown in this PDF Document is generated from our Online Catalog. Please find the complete data in the user's documentation. Our General Terms of Use for Downloads are valid (<http://download.phoenixcontact.com>)



HEAVYCON ADVANCE B6 sleeve housing, with bayonet locking (Allen screw), salt water resistant aluminum, height: 100 mm, with 1 x M25 thread, straight cable outlet, without surface; conductive seal (EMC properties)



## Key commercial data

<b>package_quantity</b>	10
<b>GTIN</b>	4046356592628

## Technical data

### Dimensions

<b>Height</b>	100 mm
---------------	--------

### Ambient conditions

<b>Degree of protection for housing</b>	IP65
<b>Degree of protection for housing</b>	IP67
<b>Ambient temperature (operation)</b>	-40 °C ... 125 °C

### General

<b>Note</b>	For contact inserts HC-B6, BB10, DD24, M
<b>Design</b>	B6
<b>Housing type</b>	Sleeve housings
<b>Locking type</b>	Bayonet locking
<b>Fixing screws</b>	M6
<b>No. of cable exits</b>	1
<b>Cable exit</b>	Straight
<b>Screw connection</b>	None
<b>Type of the screw connection</b>	1x M25
<b>Housing material</b>	Die-cast aluminum, salt water resistant
<b>Housing surface material</b>	Uncoated
<b>Seal material</b>	NBR, conductive
<b>Material lock</b>	High-grade steel

# Housing - HC-B 6-TMB-100/O1STM25G-EEE - 1460363

## Technical data

### General

<b>Connection</b>	If insulating powder coating is present on the control cabinet panel, it should be removed from the profile gasket area in order to ensure optimum shielding.
-------------------	---

## classifications

### eCl@ss

<b>eCl@ss 4.0</b>	27140816
<b>eCl@ss 4.1</b>	27140816
<b>eCl@ss 5.0</b>	27143424
<b>eCl@ss 5.1</b>	27143424
<b>eCl@ss 6.0</b>	27143424
<b>eCl@ss 7.0</b>	27440209
<b>eCl@ss 8.0</b>	27440209

### ETIM

<b>ETIM 4.0</b>	EC000437
<b>ETIM 5.0</b>	EC000437

### UNSPSC

<b>UNSPSC 6.01</b>	31261502
<b>UNSPSC 7.0901</b>	31261502
<b>UNSPSC 11</b>	31261502
<b>UNSPSC 12.01</b>	31261502
<b>UNSPSC 13.2</b>	31261502

## accessories

### Panel mounting flange

HC-B-BF - 1604641



HC-B-BF-SET - 1604654



# Housing - HC-B 6-TMB-100/O1STM25G-EEE - 1460363

accessories

## Protective cover

HC-B 6-TMB-SD-IP65 - 1690930



---

## Screwdriver tools

SF-BIT-HEXB 5-89 - 1208911



---

SF-M BH - 1212070



---

## Full screw connection

HC-K-KV-M25(11-17) - 1690639



---

HC-M-KV-M25(11-16) - 1690574



## Housing - HC-B 6-TMB-100/O1STM25G-EEE - 1460363

### accessories

HC-M-KV-M25(14-21) - 1646007



HC-EMV-KV-M25(9-16,5) - 1690516



HC-M-KV-M25(1ASI) - 1584020



### **Multiple screw connection**


HC-M-KV-M25(1X10/1X11) - 1580228



### Drawings


# Housing - HC-B 6-TMB-100/O1STM25G-EEE - 1460363

Diagram

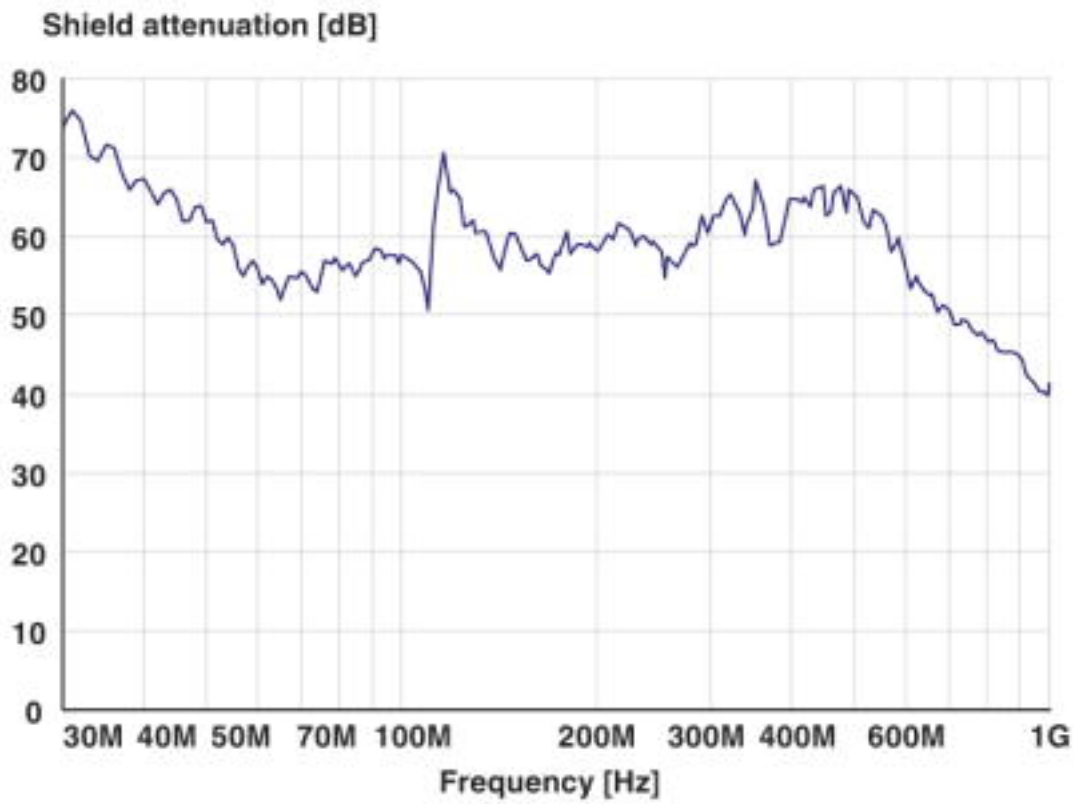

Shield attenuation


Dimensioned drawing

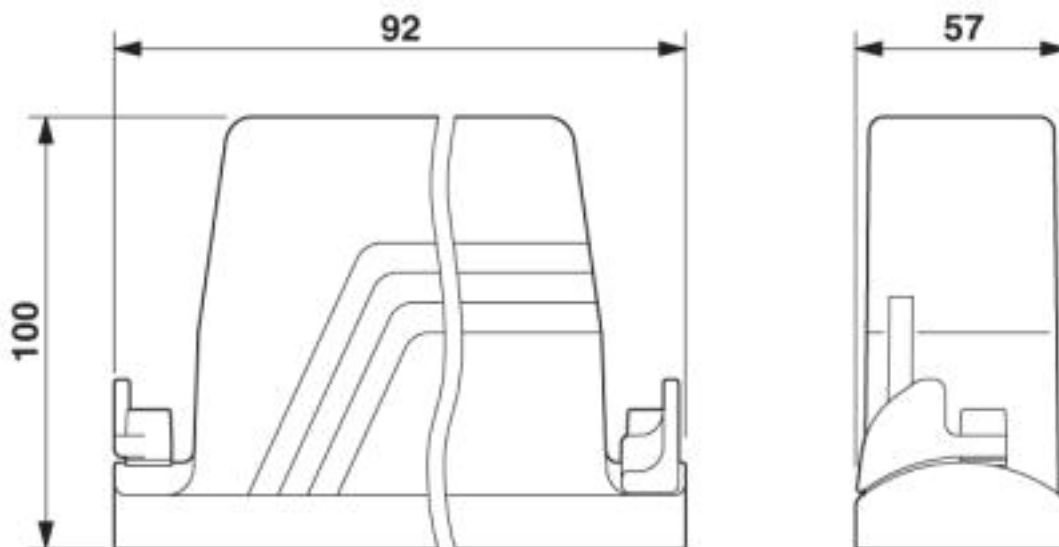

Dimensional drawing

# Housing - HC-B 6-TMB-100/O1STM25G-EEE - 1460363

Dimensioned drawing

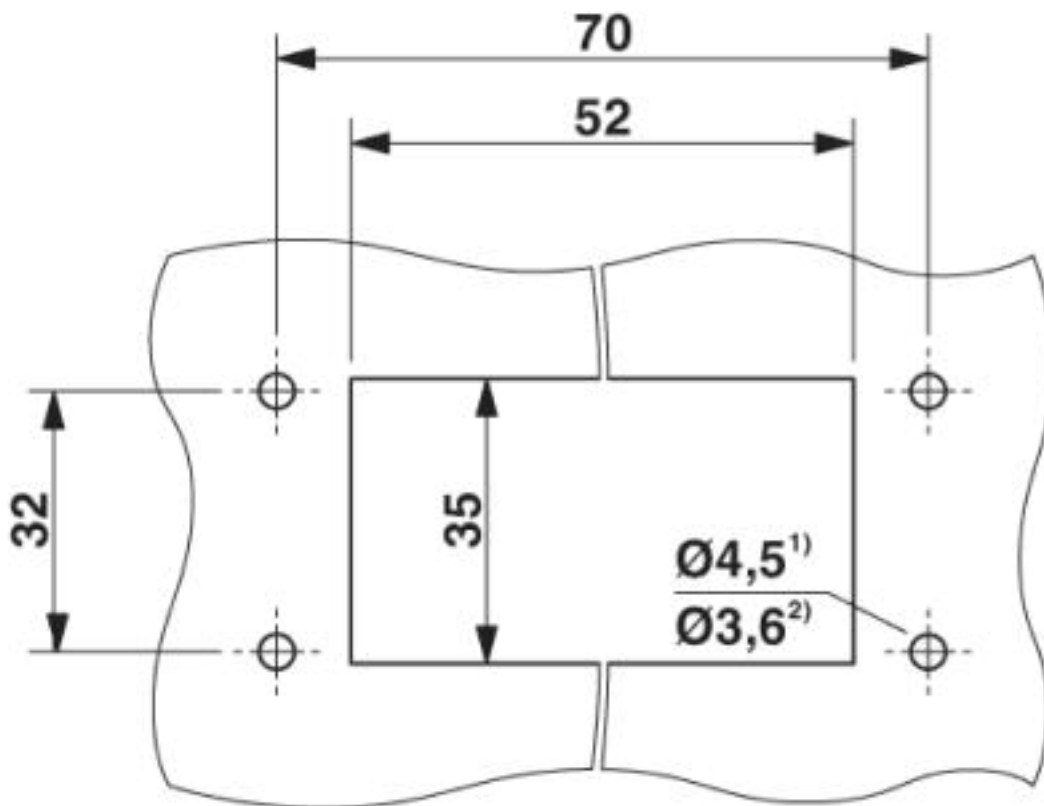

Mounting cutout<sup>1)</sup> when M4 screws are used<sup>2)</sup> when self-tapping Torx® screws are used (Torx® 20, M4)

© Phoenix Contact 2013 - all rights reserved  
<http://www.phoenixcontact.com>