


Cover profile - A/F 60 METER - 1004979

Please be informed that the data shown in this PDF Document is generated from our Online Catalog. Please find the complete data in the user's documentation. Our General Terms of Use for Downloads are valid (<http://download.phoenixcontact.com>)

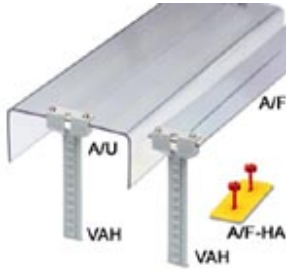

Flat-ribbon cover, for covering terminal strips, 2 mm thick, 6 cm wide, an additional requirement are 2 E/UK end brackets and 2 adjustable VAH cover holders. The max. supply length is 100 cm

The illustration shows a combination of versions A/F, A/U, VAH, A/F-HA

Key commercial data

package_quantity	1
GTIN	4017918012328

Technical data

Dimensions

Length (b)	1 m
Width (a)	60 mm

General

Color	transparent
Inflammability class according to UL 94	V2
Material	Polycarbonate PC

classifications

eCl@ss

eCl@ss 4.0	23150301
eCl@ss 4.1	23150301
eCl@ss 5.0	27141143
eCl@ss 5.1	27141143
eCl@ss 6.0	27379200
eCl@ss 7.0	27141143
eCl@ss 8.0	27141143

ETIM

ETIM 2.0	EC000761
ETIM 3.0	EC000761
ETIM 4.0	EC002498
ETIM 5.0	EC002498

Cover profile - A/F 60 METER - 1004979

classifications

UNSPSC

UNSPSC 6.01	30212109
UNSPSC 7.0901	39121708
UNSPSC 11	39121708
UNSPSC 12.01	39121708
UNSPSC 13.2	39121708

Drawings

© Phoenix Contact 2013 - all rights reserved
<http://www.phoenixcontact.com>