

Cover plate - HC-D 25-AP-GY - 1660355

Please be informed that the data shown in this PDF Document is generated from our Online Catalog. Please find the complete data in the user's documentation. Our General Terms of Use for Downloads are valid (<http://download.phoenixcontact.com>)



HEAVYCON cover plate, for wall cutouts of type D25, 3.5 mm thick, gray

The illustration shows a version of the product

Key commercial data

package_quantity	10
GTIN	4017918021993

Technical data

Dimensions

Length	103 mm
Height	3.5 mm
Hole diameter	4.5 mm
Width	45 mm
Drill hole distance, horizontal	86 mm
Drill hole distance, vertical	17.5 mm
Internal cutout dimension	24 x 74 mm

General

Note	For wall cutouts of type D25
Material	PA
Inflammability class according to UL 94	HB
Color	gray
Design	D25

classifications

eCl@ss

eCl@ss 4.0	27140816
eCl@ss 4.1	27140816
eCl@ss 5.0	27143424
eCl@ss 5.1	27143424
eCl@ss 6.0	27143424
eCl@ss 7.0	27440209

Cover plate - HC-D 25-AP-GY - 1660355

classifications

eCl@ss

eCl@ss 8.0	27440209
------------	----------

ETIM

ETIM 3.0	EC002310
ETIM 4.0	EC000886
ETIM 5.0	EC002314


UNSPSC

UNSPSC 6.01	30211817
UNSPSC 7.0901	39121416
UNSPSC 11	39121408
UNSPSC 12.01	39121408
UNSPSC 13.2	39121408

approvals

GOST /


Approval details



Drawings

Cover plate - HC-D 25-AP-GY - 1660355

Dimensioned drawing

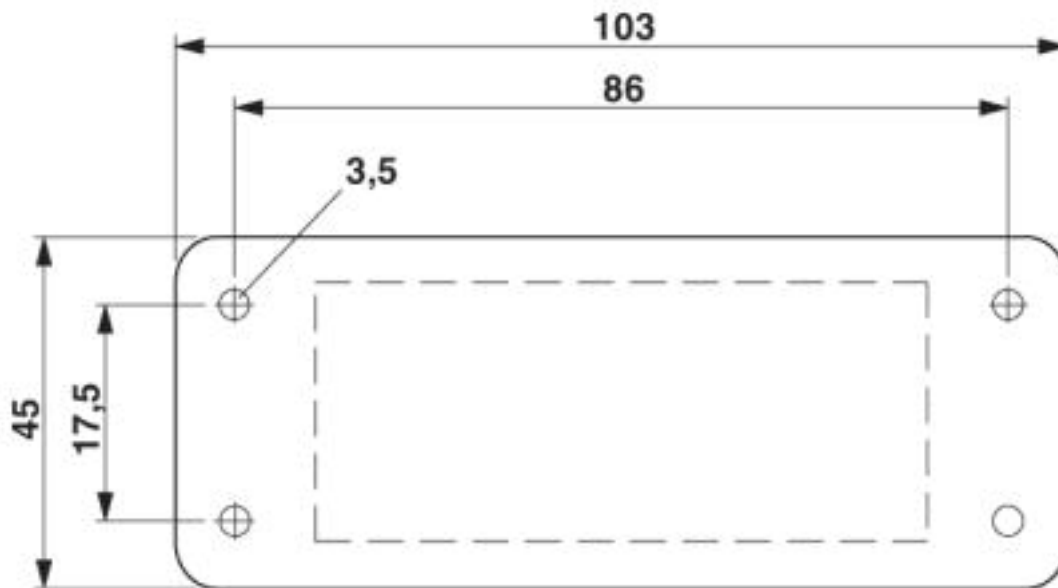

© Phoenix Contact 2013 - all rights reserved
<http://www.phoenixcontact.com>