

Flush-type connector - SACC-DSI-M 8MS-3CON-L180 - 1694334

Please be informed that the data shown in this PDF Document is generated from our Online Catalog. Please find the complete data in the user's documentation. Our General Terms of Use for Downloads are valid (<http://download.phoenixcontact.com>)



Sensor/actuator flush-type connector, male, 3-pos., M8, rear/screw mounting with M8 thread, with straight solder connection

Key commercial data

package_quantity	20
GTIN	4017918178697

Technical data

Ambient conditions

Ambient temperature (operation)	-25 °C ... 85 °C
Degree of protection	IP67

General

Rated current at 40°C	4 A
Rated voltage	60 V
Number of positions	3
Contact resistance	≤ 3 mΩ
Insulation resistance	≥ 100 MΩ
Coding	A - standard
Standards/regulations	M8 connector IEC 61076-2-104
Status display	No
Surge voltage category	II
Pollution degree	3
Connection method	Solder pins
Mounting type	Rear mounting M8 x 0.5 With locking nut

Material

Inflammability class according to UL 94	HB
Contact material	CuZn
Contact surface material	Au
Contact carrier material	PA 66
Material, knurls	Nickel-plated brass
Sealing material	NBR

Flush-type connector - SACC-DSI-M 8MS-3CON-L180 - 1694334

classifications

eCl@ss

eCl@ss 4.0	27140815
eCl@ss 4.1	27140815
eCl@ss 5.0	27143423
eCl@ss 5.1	27143423
eCl@ss 6.0	27143423
eCl@ss 7.0	27449001
eCl@ss 8.0	27449001

ETIM

ETIM 2.0	EC001297
ETIM 3.0	EC002061
ETIM 4.0	EC002062
ETIM 5.0	EC002062

UNSPSC

UNSPSC 6.01	31251501
UNSPSC 7.0901	31251501
UNSPSC 11	31251501
UNSPSC 12.01	31251501
UNSPSC 13.2	31251501

approvals

UL Recognized / cUL Recognized / GOST / cULus Recognized /

Approval details

UL Recognized 	
Nominal voltage UN	125 V
Nominal current IN	4 A
mm²/AWG/kcmil	

cUL Recognized 	
Nominal voltage UN	125 V
Nominal current IN	4 A
mm²/AWG/kcmil	

Flush-type connector - SACC-DSI-M 8MS-3CON-L180 - 1694334


approvals

GOST 

cULus Recognized  **UL** US

Drawings


Drilling diagram

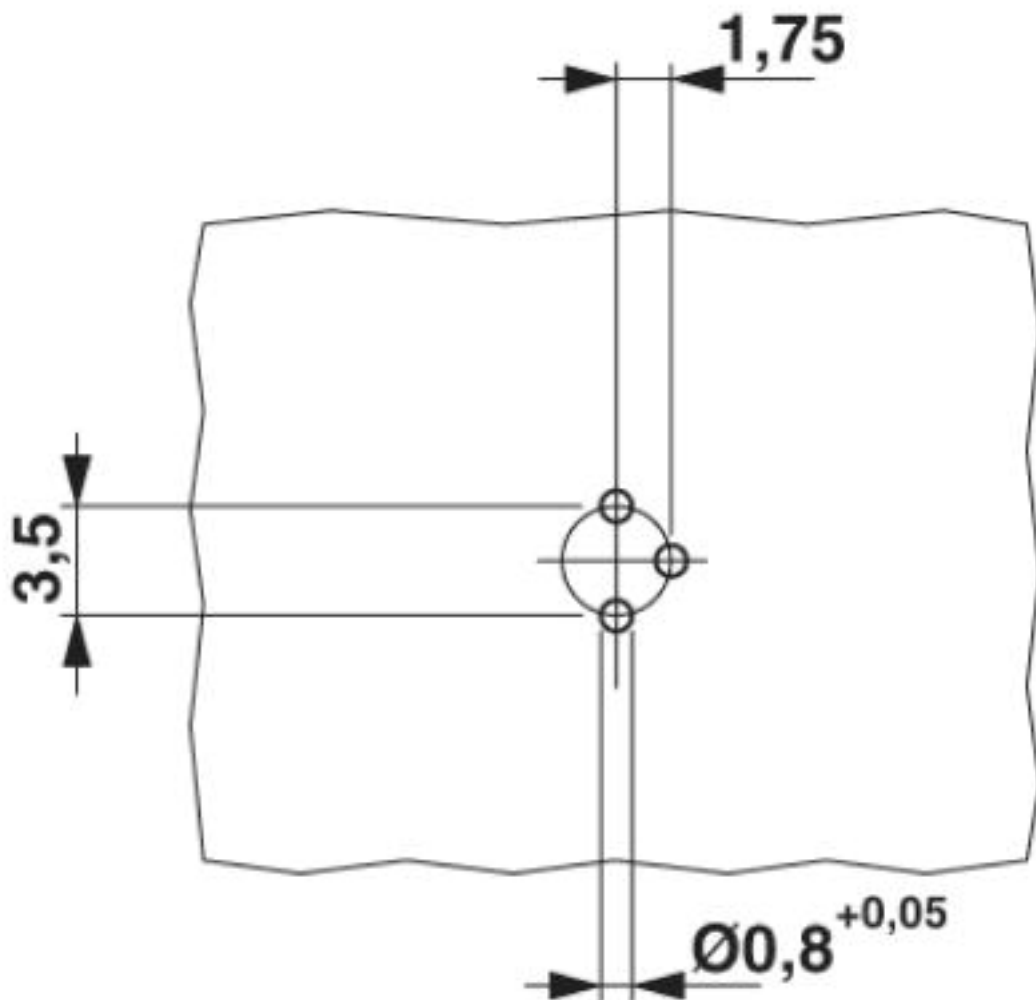

Drilling diagram

Flush-type connector - SACC-DSI-M 8MS-3CON-L180 - 1694334


Dimensioned drawing

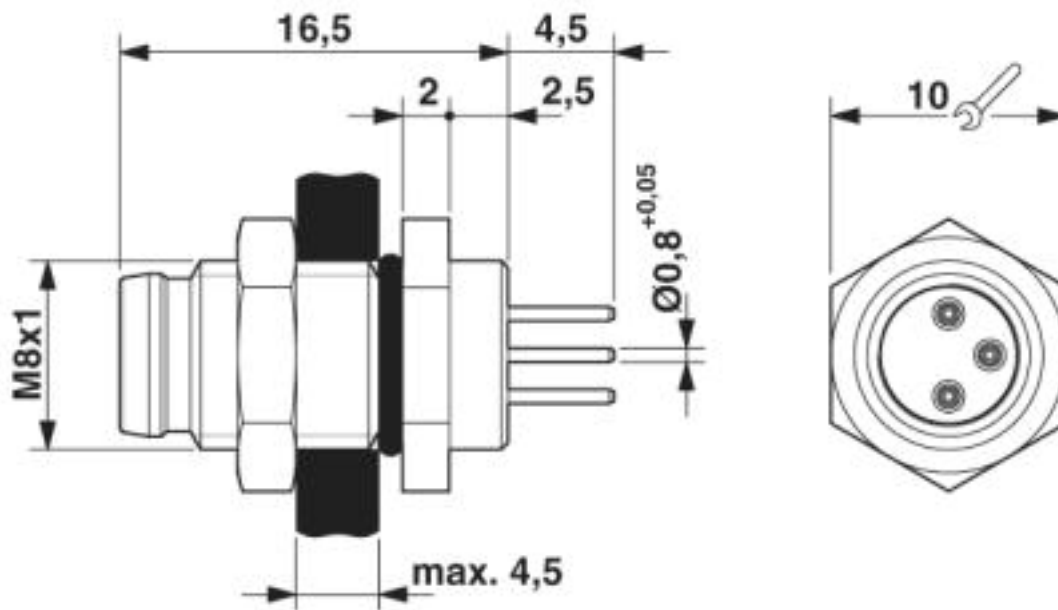

M8 flush-type plug

Flush-type connector - SACC-DSI-M 8MS-3CON-L180 - 1694334


Dimensioned drawing

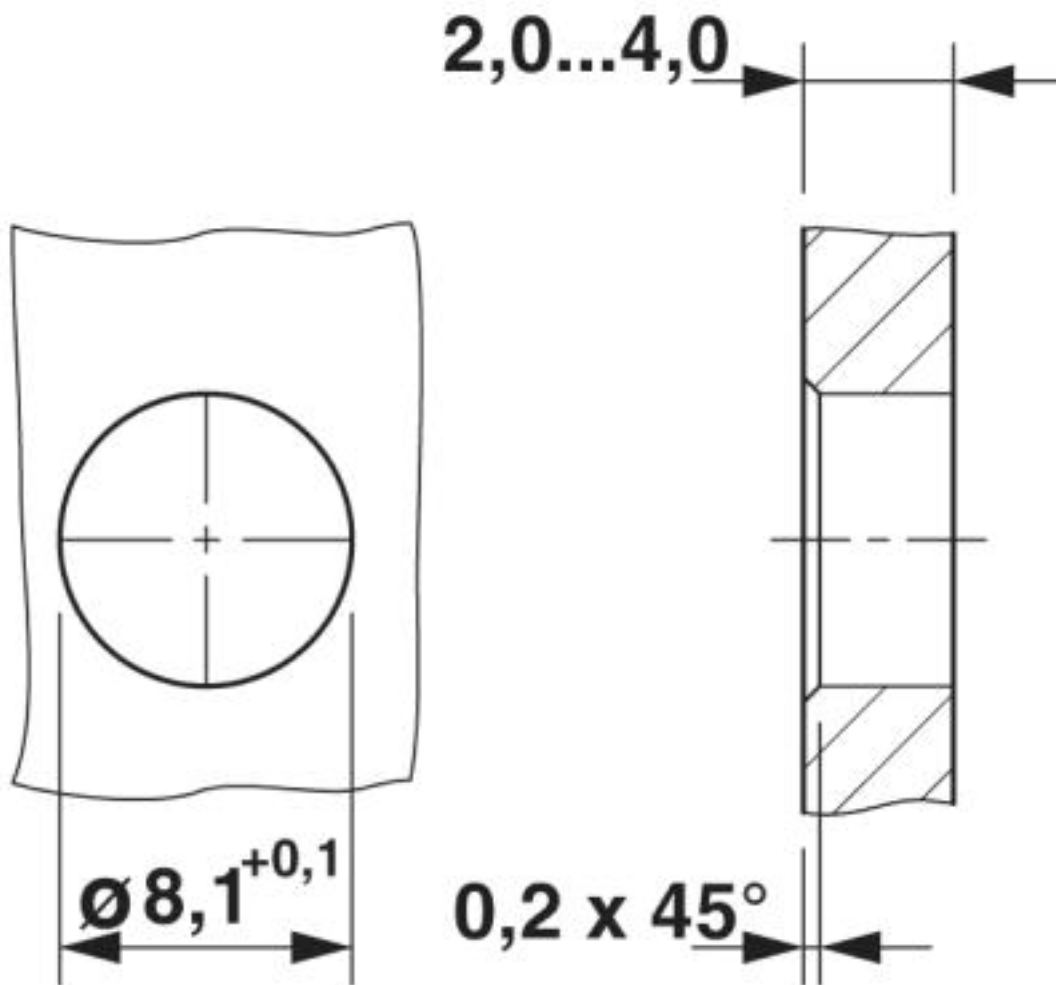

Housing cutout for M8 flush-type connector, connector, one-section

Flush-type connector - SACC-DSI-M 8MS-3CON-L180 - 1694334

Schematic diagram

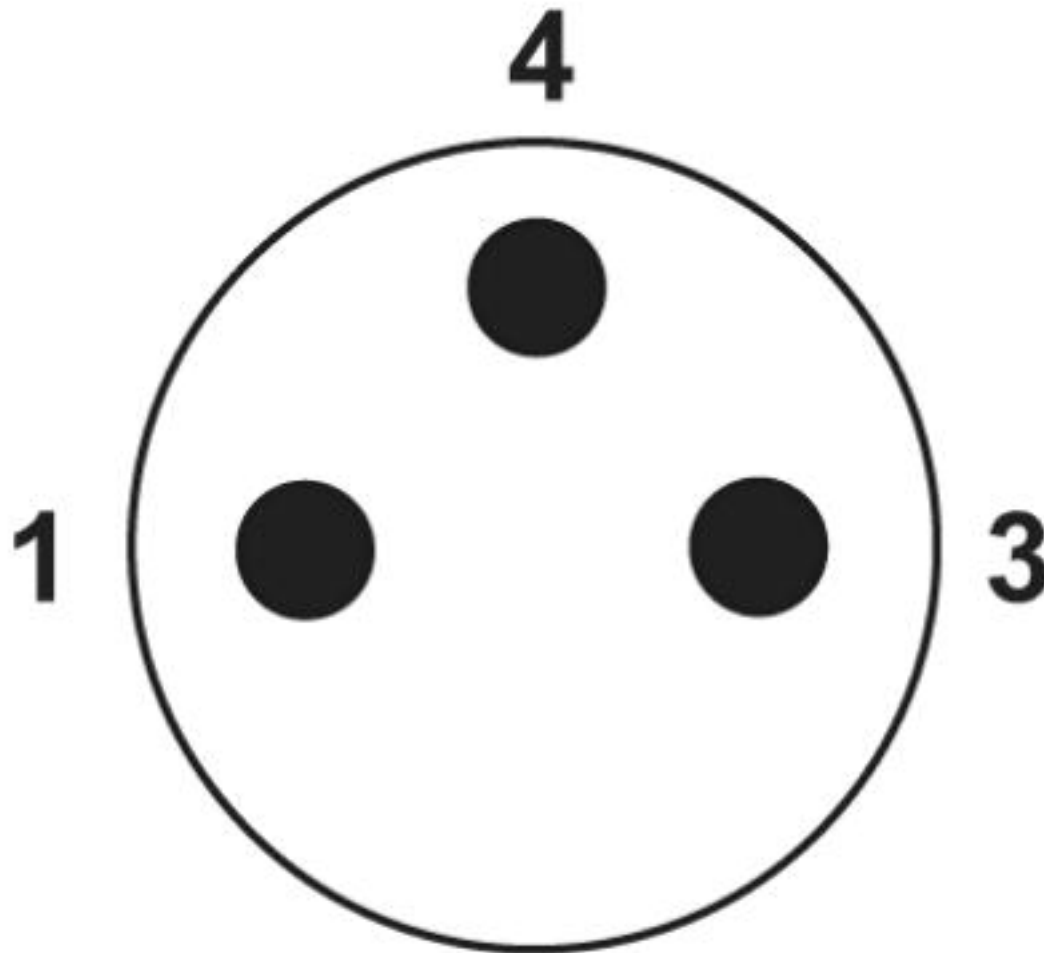

Pin assignment M8 plug, 3-pos., view male side

© Phoenix Contact 2013 - all rights reserved
<http://www.phoenixcontact.com>