

## Filler plugs - HC-BS-PG29 - 1674532

Please be informed that the data shown in this PDF Document is generated from our Online Catalog. Please find the complete data in the user's documentation. Our General Terms of Use for Downloads are valid (<http://download.phoenixcontact.com>)



Filler plugs, for Pg screw connections, type Pg29

The illustration shows version  
HC-BS-PG 21

### Key commercial data

|                  |               |
|------------------|---------------|
| package_quantity | 10            |
| GTIN             | 4017918135430 |

### Technical data

#### Ambient conditions

|                                 |                  |
|---------------------------------|------------------|
| Degree of protection            | IP68             |
| Degree of protection            | IP68             |
| Ambient temperature (operation) | -20 °C ... 80 °C |

#### General

|                                |                     |
|--------------------------------|---------------------|
| Material                       | Nickel-plated brass |
| Material, O-ring               | NBR                 |
| Thread type on connection side | Pg29                |

### classifications

#### eCl@ss

|            |          |
|------------|----------|
| eCl@ss 4.0 | 27140816 |
| eCl@ss 4.1 | 27140816 |
| eCl@ss 5.0 | 27143424 |
| eCl@ss 5.1 | 27143424 |
| eCl@ss 6.0 | 27143424 |
| eCl@ss 7.0 | 27440209 |
| eCl@ss 8.0 | 27440209 |

#### ETIM

|          |          |
|----------|----------|
| ETIM 2.0 | EC000437 |
| ETIM 3.0 | EC000437 |
| ETIM 4.0 | EC000032 |
| ETIM 5.0 | EC000032 |

# Filler plugs - HC-BS-PG29 - 1674532

## classifications

### UNSPSC

|               |          |
|---------------|----------|
| UNSPSC 6.01   | 30212113 |
| UNSPSC 7.0901 | 39121712 |
| UNSPSC 11     | 39121712 |
| UNSPSC 12.01  | 39121712 |
| UNSPSC 13.2   | 39121712 |

## approvals


GOST /

### Approval details



## Drawings

### Dimensioned drawing

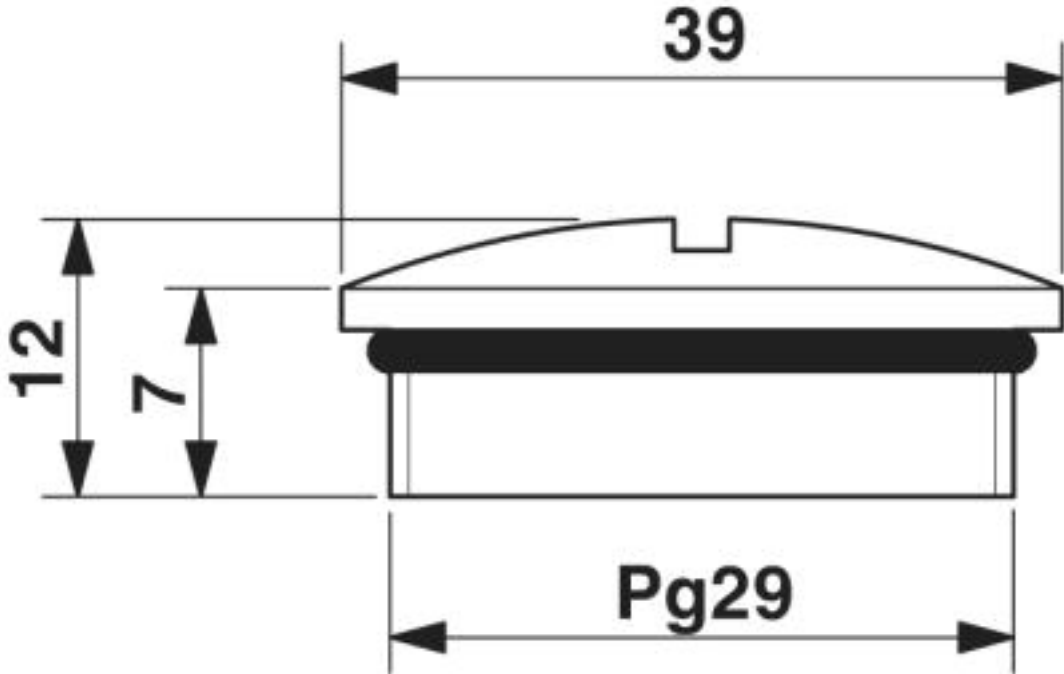

Filler plugs Pg29