

## Filler plugs - HC-BS-PG21 - 1674529

Please be informed that the data shown in this PDF Document is generated from our Online Catalog. Please find the complete data in the user's documentation. Our General Terms of Use for Downloads are valid (<http://download.phoenixcontact.com>)



Filler plugs, for Pg screw connections, type Pg21

### Key commercial data

<b>package_quantity</b>	10
<b>GTIN</b>	4017918135423

### Technical data

#### Ambient conditions

<b>Degree of protection</b>	IP68
<b>Degree of protection</b>	IP68
<b>Ambient temperature (operation)</b>	-20 °C ... 80 °C

#### General

<b>Material</b>	Nickel-plated brass
<b>Material, O-ring</b>	NBR
<b>Thread type on connection side</b>	Pg21

### classifications

#### eCl@ss

<b>eCl@ss 4.0</b>	27140816
<b>eCl@ss 4.1</b>	27140816
<b>eCl@ss 5.0</b>	27143424
<b>eCl@ss 5.1</b>	27143424
<b>eCl@ss 6.0</b>	27143424
<b>eCl@ss 7.0</b>	27440209
<b>eCl@ss 8.0</b>	27440209

#### ETIM

<b>ETIM 2.0</b>	EC000437
<b>ETIM 3.0</b>	EC000437
<b>ETIM 4.0</b>	EC000032
<b>ETIM 5.0</b>	EC000032

#### UNSPSC

# Filler plugs - HC-BS-PG21 - 1674529

## classifications

### UNSPSC

UNSPSC 6.01	30212113
UNSPSC 7.0901	39121712
UNSPSC 11	39121712
UNSPSC 12.01	39121712
UNSPSC 13.2	39121712

## approvals


GOST /

## Approval details



## Drawings

### Dimensioned drawing

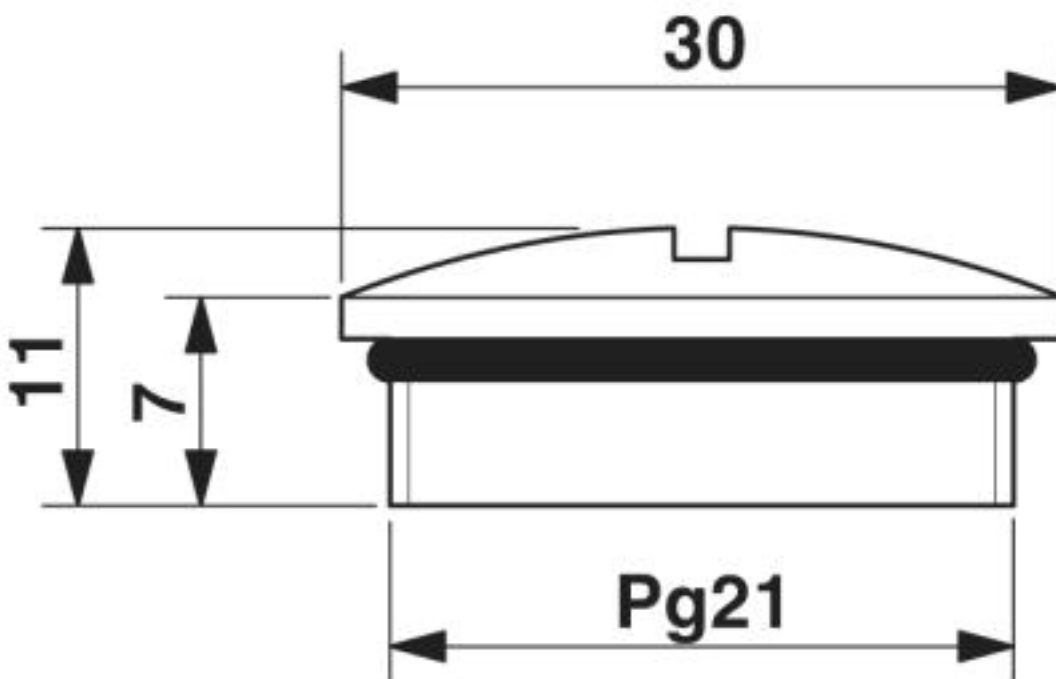

Filler plugs Pg21