

RGB

EUROLITE FIB LED fiber light

Fiber light

- For indoor use only
- For decoration
- Color changing effect
- Equipped with a 3 W RGB LED
- Length of the fibers: 1,5 m/ 2 m



No. 50520200..... 100, RGB
 No. 50520210..... 203, SC
 No. 50520240..... 206, SC/FC control

Technical specifications:

Product:	FIB-100	FIB-203	FIB-206
Power supply:	230 V AC, 50 Hz ~	230 V AC, 50 Hz ~ (via enclosed power unit)	230 V AC, 50 Hz ~ (via enclosed power unit)
Power consumption:	3 W	approx:4 W/10 VA	3 W
Fibre optic strand length:	1,5 m	2 m	2 m
Number of fibre optic strands:	100 pcs	200 pcs.	200 pcs.
Number of LEDs:	1 x 3 W RGB	1 x 3W white LED	1 x 3 W RGB LED
Illuminator dimensions (LxWxH):	26 x 80 mm	170 x 120 x 67 mm	180 x 75 x 57 mm
Weight:		approx: 0.75 kg	1.2 kg

DMX


TCL

RGB

EUROLITE FIB-450 LED fiber light RGB DMX

Fiber light

- Operable via DIP switches or DMX interface
- Sound-control via built-in microphone
- Color change effect due to 1 x 9W TCL RGB LED
- For indoor use only
- Length of the fibers: 2m

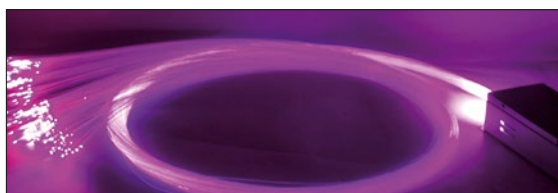

No. 50520260


Technical specifications:

Power supply (via enclosed 4V DC power unit):	230 V AC, 50 Hz ~
Power consumption:	mas. 12 W
Number of DMX channels:	4
DMX512 connection:	3-pin XLR
Sound-control:	via built-in microphone
Fibre optic strand length:	2 m
Number of fibre optic strands:	450 pcs.
Number of LEDs:	1
LED type:	TCL RGB, 9 W
Illuminator dimensions (LxWxH):	195 x 85 x 50 mm
Weight:	1 kg

EUROLITE EL wire 2mm, 2m

Flexible electroluminescent lighting wire

- For decoration
- No heat radiation
- Ready for use with supplied batteries

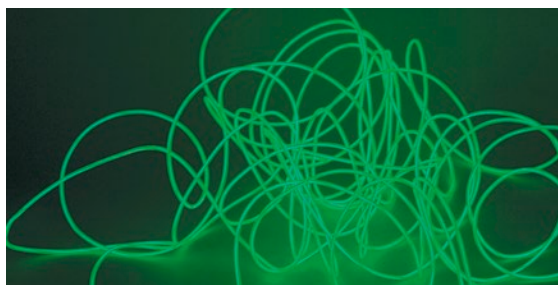

Technical specifications:

Power supply:	3 V DC via 2 x 1.5 V mignon batteries (type AA)
Power consumption:	max. 1 W
Lifetime:	3000 - 5000 h
Diameter x Length:	2 mm x 2 m
Weight:	120 g

No. 50520300..... 2 m, red
 No. 50520302..... 2 m, yellow
 No. 50520304..... 2 m, blue
 No. 50520305..... 2 m, light blue
 No. 50520306..... 2 m, green
 No. 50520308..... 2 m, orange
 No. 50520310..... 2 m, white