


## Product Description

Fast and easy assembly; Vibration protection; No extra parts necessary

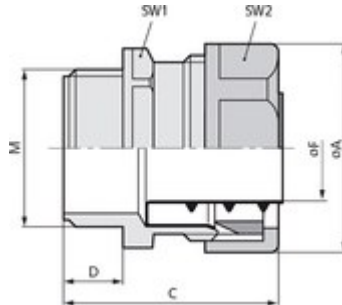

## Application range

- In combination with protective conduit
- SILVYN® FPS/ FD-PU
- SILVYN® SI/SP/SP-PU/BRAID
- Indoor applications
- Light mechanical stress

## Benefits

- Fast and easy assembly
- Vibration protection
- No extra parts necessary

## Design

- Metric connection thread
- Hexagonal collar
- Threaded sleeve
- Cap nut

## Note

- Included: SILVYN® EE-K inner sleeve



Product features

- Large wrench sizes

Technical Data

**Colour delivered**  
Silver grey (RAL 7001)  
**Material**  
PP

**Protection rating**  
IP 54  
**Temperature range**  
-10°C to +110°C

Article List

Part number	Connection thread M	Clear opening (mm)	Overall length/ C (mm)	Thread length/ D (mm)	SW 1/2 mm	Suitable for SILVYN® FD-PU/FPS	Suitable for SILVYN® SP	Suitable for SILVYN® SP-PU	Pieces / PU
SILVYN® USK-M									
55501300	10 x 1.0	6.0	40.0	10.0	18 / 16	7 x 10			50
55501310	12 x 1.5	9.0	43.0	12.0	23 / 21	10 x 14	10 x 14	10 x 14	50
55501320	16 x 1.5	13.0	43.0	12.0	27 / 24	13 x 17	12 x 16	12 x 16	50
55501330	20 x 1.5	14.5	44.0	13.0	32 / 29	16 x 21	16 x 20	16 x 20	50
55501340	25 x 1.5	19.5	50.0	13.0	40 / 36	22 x 27	22 x 27	22 x 27	25
55501350	32 x 1.5	27.0	51.0	15.0	49 / 45	29 x 36	30 x 36	30 x 36	25
55501360	40 x 1.5	36.0	51.0	15.0	58 / 53	38 x 45	38 x 44	38 x 44	25
55501370	50 x 1.5	46.0	58.0	16.0	70 / 65	48 x 56	50 x 56		10

Footnote:

Photographs are not to scale and do not represent detailed images of the respective products.