


Product Description

With incised sealing ring for adjustment to several cable diameters; Fewer sizes need to be kept in stock

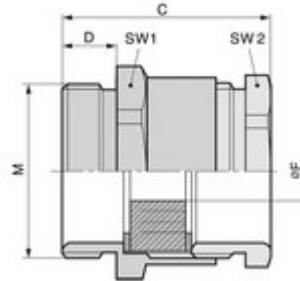

Application range

- Brass cable gland with hexagonal fitting and variable incised sealing ring.

Benefits

- With incised sealing ring for adjustment to several cable diameters
- Fewer sizes need to be kept in stock

Design

- Metric connection thread acc. to EN 50262

Note

- Refer to SKINDICHT® EV for additional accessories
- Counter nut to be used: SKINDICHT® SM-M
- Example description: SVRE-M 12/7/5 12 = metric connection thread 7 = PG function thread 5 = clear opening of F

**Technical Data****Caution**

The installation dimensions can be found in appendix T21

Upon request

Available with long connection thread Available with VITON® incised ring

Material

Body: nickel-plated brass Incised seal: CR/NBR

Protection rating

IP 54

Temperature range

-20°C to +80°C

Article List

Part number	Article designation / size	Incised sealing ring ØF (mm)	Max. internal Ø (mm)	Function thread PG	SW1/SW2 mm	Overall length/ C (mm)	Thread length/ D (mm)	Pieces / PU
SKINDICHT® SVRE-M								
52104980	16 x 1,5	5/8	12	9	18 / 15	21,6	5.0	100
52104990	20 x 1,5	7/10/12.5	15	11	22 / 18	22,6	6.0	50
52105000	20 x 1,5	7/10.5/13/16	15	13.5	22 / 20	25,6	6.0	50
52105010	20 x 1,5	8/10.5/13.5/16	15	16	24 / 22	26,6	6.0	50
52105002	25 x 1,5	11/15/18/20	20	21	30 / 28	29,6	7.0	50
52105003	32 x 1,5	19/23/27/31	27	29	40 / 37	32,6	8.0	50
52105004	40 x 1,5	25/28/31/35	34	36	50 / 47	37,6	8.0	20
52105005	50 x 1,5	35.5/39/42.5/46	44	42	57 / 54	42,6	9.0	5
52105006	63 x 1,5	40.5/44/47/50.5	54	48	66 / 60	45,1	10.0	5

Footnote:

Photographs are not to scale and do not represent detailed images of the respective products.