




<b>DATA SHEET</b>	55506485
<b>SILVYN® FPAG-90° metric</b>	valid from : 30.07.2010

**Specification:**

The SILVYN® FPAG.90° metric angle conduit gland gives a high tensile strength with it all round teeth a vibrations protection. The gland can be removed from the conduit using a tooling (small screwdriver).

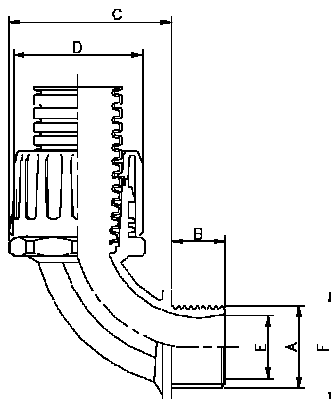

**Dimensions table:**

part number	measurement M	A mm	B mm	C mm	D mm	F mm	suitable for SILVYN FPAS
5550 6485	M 12x1,5	19,0	6,0	24,0	8,0	18,0	10
5550 6495	M 16x1,5/1	24,0	11,0	34,0	11,0	22,0	13
5550 6505	M 16x1,5/2	29,0	11,0	38,0	11,0	28,0	16
5550 6515	M 20x1,5/1	29,0	15,0	38,0	13,0	28,0	16
5550 7075	M 20x1,5/3	32,0	15,0	40,0	13,0	30,0	18
5550 6525	M 20x1,5/2	32,0	15,0	40,0	13,0	30,0	21
5550 6535	M 25x1,5	44,0	19,0	50,0	15,0	42,0	28
5550 6545	M 32x1,5	51,0	25,0	58,0	16,0	49,0	34
5550 7085	M 40x1,5	63,0	33,0	83,0	16,0	60,0	42
5550 6555	M 50x1,5/1	63,0	39,0	83,0	16,0	70,0	42
5550 6565	M 50x1,5/2	76,0	40,0	88,0	16,0	73,0	54
5550 6575	M 63x1,5/1	76,0	50,0	95,0	16,0	73,0	54
5550 7095	M 63x1,5/2	90,0	50,0	100,0	16,0	86,0	67



<b>DATA SHEET</b>	55506485
<b>SILVYN® FPAG-90° metric</b>	valid from : 30.07.2010

**Technical feature:** temperature range: -40°C up to +135°C  
colour: black RAL 9005, grey RAL 7011  
material: PA 66  
protections class: IP 66  
fire class: UL 94 V2

**Characteristics:** halogen free  
flame retardant  
low toxicity  
oil and solvent resistant  
UV resistant in black

**Approval:**



For more information please see our current catalogue.  
Please do not hesitate to contact our laboratory if there any questions regarding  
resistance against aggressive agents and special oil.