


Product Description

Easy assembly of cables and wires; Bendable; Crush-resistant; A fully insulated system when used in combination with SILVYN® MPC/MPC-M

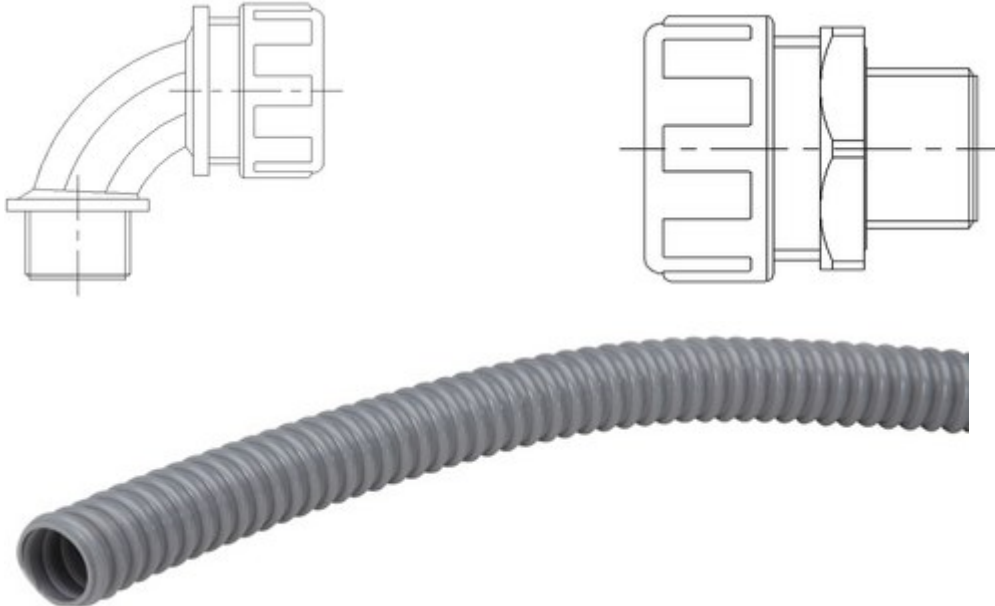

Application range

- Mechanical engineering
- Vehicle construction
- Vending machine construction
- Exporters

Benefits

- Easy assembly of cables and wires
- Bendable
- Crush-resistant
- A fully insulated system when used in combination with SILVYN® MPC/MPC-M

Design

- Integrated hard PVC spiral
- Soft PVC outer sheath



Approvals

- UL FILENUMBER E308201

Note

- On request

Product features

- Flexible
- Smooth inner wall
- Dimensionally stable

Technical Data

Colour delivered

Silver grey (RAL 7001)

Temperature range

-20 °C to +70 °C

Material

Special soft PVC sheath with hard PVC spiral

Article List

Part number	Internal Ø x external Ø (mm)	Bending radius (mm)	Inner Ø (mm)	Suitable for SILVYN® MPC-M/MPC 90°M	Suitable for SILVYN® MPC	Suitable for SILVYN® MPC 90°	PU ring (m)
SILVYN® EL							
61747360	10 x 14,7	20	10	16 x 1,5	9	9	30
61747370	12 x 16,6	25	12	16 x 1,5	11/13,5	11/13,5	30
61747380	16 x 20,7	30	16	20 x 1,5	13,5/16	13,5/16	30
61747390	22 x 27,7	40	22	25 x 1,5	21	21	30
61747400	25 x 30,6	45	25	32 x 1,5	29	29	30
61747410	28 x 33,5	50	28	32 x 1,5	29	29	30
61747420	35 x 41	60	35	40 x 1,5	36	36	30
61747430	40 x 46,4	70	40	50 x 1,5	48		30



61747440	50 x 57,2	85	50	63 x 1,5	48		30
----------	-----------	----	----	----------	----	--	----

Footnote:

Photographs are not to scale and do not represent detailed images of the respective products.