


Product Description

Watertight;Gentle cable clamping;Robust;High strain relief

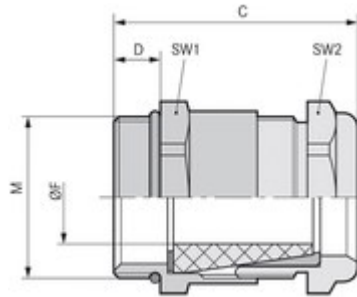

Application range

- Watertight cable gland with conical sealing element.
- Pumps
- Floater switches

Benefits

- Watertight
- Gentle cable clamping
- Robust
- High strain relief

Design

- Metric connection thread acc. to EN 50262

Note

- Counter nut to be used: SKINDICHT® SM-M
- Suitable accessory: SKINDICHT® SHV sealing cones
- Example description: SHV-M 20/11/7 20 = metric connection thread 11 = PG function thread 7 = clear opening of sealing cone

**Technical Data****Caution**

The installation dimensions can be found in appendix T21

Material

Body: nickel-plated brass Sealing cone: CR O-ring: NBR

Protection rating

IP 68 - 10 bar

Temperature range

-20°C to +80°C

Article List

Part number	Article designation / size	Clamping range ØF (mm)	Function thread PG	SW1/SW2 mm	Overall length/ C (mm)	Thread length/ D (mm)	Clear opening seal	Pieces / PU
SKINDICHT® SHV-M								
52105270	12 x 1,5	3 - 4,8	7	14 / 14	26.0	5.0	5	50
52105280	16 x 1,5	4,5 - 5,8	9	18 / 17	26,5	5.0	6	50
52105290	16 x 1,5	4,5 - 6,8	9	18 / 17	26,5	5.0	7	50
52105300	20 x 1,5	6 - 6,8	11	22 / 20	31.0	6.0	7	25
52105310	20 x 1,5	6,5 - 8,8	11	22 / 20	31.0	6.0	9	25
52105320	20 x 1,5	6,5 - 8,8	13.5	22 / 22	32,5	6.0	9	25
52105330	20 x 1,5	9 - 10,8	13.5	22 / 22	32,5	6.0	11	25
52105340	20 x 1,5	9 - 10,8	16	24 / 24	34,5	6.0	11	25
52105350	20 x 1,5	9,5 - 12,8	16	24 / 24	34,5	6.0	13	25
52105360	20 x 1,5	13 - 14,8	16	24 / 24	34,5	6.0	15	25
52105370	25 x 1,5	13,5 - 15,8	21	30 / 30	38,5	7.0	16	25
52105380	25 x 1,5	15 - 17,8	21	30 / 30	38,5	7.0	18	25
52105390	25 x 1,5	17,5 - 19,8	21	30 / 30	38,5	7.0	20	25
52105400	32 x 1,5	17,5 - 21,8	29	40 / 40	42,5	8.0	22	10
52105410	32 x 1,5	19 - 23,8	29	40 / 40	42,5	8.0	24	10
52105420	32 x 1,5	23 - 25,8	29	40 / 40	42,5	8.0	26	10

Footnote:

Photographs are not to scale and do not represent detailed images of the respective products.