


Housing design H-B. The industry standard.

## Product Description

The smallest housing out of the H-B series. For inserts with high electrical properties

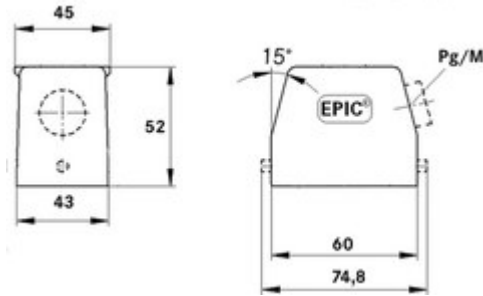

## Application range

- Plant engineering
- Control engineering
- Plastics industry

## Benefits

- The smallest housing out of the H-B series. For inserts with high electrical properties

## Product features

- Hood, low version
- Bolts for single lever
- Side cable entry
- Versions with neck



**Technical Data**

**Material**

Housing: powder-coated aluminium alloy, grey

Lever: zinc-plated steel Sealing: NBR

**Protection rating**

IP 65 (latched)

**Temperature range**

-40 °C to +100 °C, short-term up to +125 °C

**Article List**

Part number	Article	M	PG	Neck	Pieces / PU
H-B housing: hood (side cable entry, bolts for single lever)					
10012000	H-B 6 TS 13,5		13.5	yes	10
10022000	H-B 6 TS 16		16	yes	10
19012000	H-B 6 TS M20	20		yes	10
19022000	H-B 6 TS M25	25		yes	10

**Footnote:**

Photographs are not to scale and do not represent detailed images of the respective products.