


Housing design H-B. The industry standard.

### Product Description

Ideal for many applications due to a wide range of housings and inserts

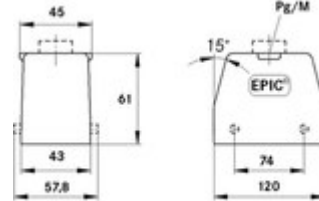

### Application range

- Plant engineering
- Light & sound technology
- Plastics industry

### Benefits

- Ideal for many applications due to a wide range of housings and inserts

### Product features

- Hood, low version
- Bolts for double lever
- Straight cable entry
- Versions with / without neck



**Technical Data**

**Material**

Housing: powder-coated aluminium alloy, grey

Lever: zinc-plated steel Sealing: NBR

**Protection rating**

IP 65 (latched)

**Temperature range**

-40 °C to +100 °C, short-term up to +125 °C

**Article List**

Part number	Article	M	PG	Neck	Pieces / PU
H-B housing: hood (straight cable entry, bolts for double lever)					
10121000	H-B 24 TG 21		21	yes	5
10111000	H-B 24 TG 29		29	yes	5
19121000	H-B 24 TG M25	25			5
19111000	H-B 24 TG M32	32			5

**Footnote:**

Photographs are not to scale and do not represent detailed images of the respective products.