


These connectors are attractive because of their compact housing.

### Product Description

Small and compact, for applications with high number of contacts

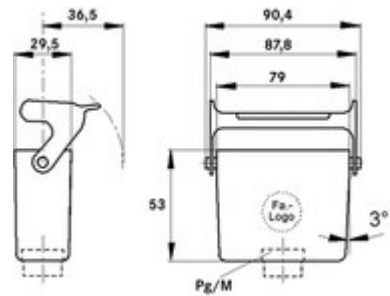

### Application range

- Machine and equipment manufacturing
- Control engineering
- Electronic laboratory

### Benefits

- Small and compact, for applications with high number of contacts

### Product features

- Cable coupler hood, low version
- Single lever
- Straight cable entry
- Versions with / without neck



**Technical Data**

**Material**

Housing: aluminium alloy, grey Lever: zinc-plated steel Sealing: NBR

**Protection rating**

IP 65 (latched)

**Temperature range**

-40 °C to +100 °C, short-term up to +125 °C

**Article List**

Part number	Article	M	PG	Neck	Pieces / PU
H-A housing: cable coupler hood (straight cable entry, single lever)					
10563000	H-A 16 TBF-LB 16		16	yes	5
19563000	H-A 16 TBF-LB M20	20			5
19563200	H-A 16 TBF-LB M25	25			5

**Footnote:**

Photographs are not to scale and do not represent detailed images of the respective products.