
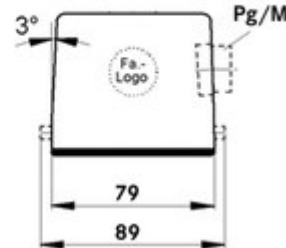


These connectors are attractive because of their compact housing.

Product Description

Small and compact, for applications with high number of contacts

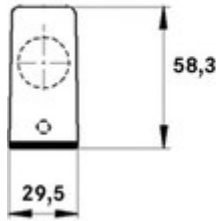

Application range

- Machine and equipment manufacturing
- Control engineering
- Electronic laboratory

Benefits

- Small and compact, for applications with high number of contacts

Product features

- Hood, low version
- Bolts for single lever
- Side cable entry
- Versions with neck



Technical Data

Material

Housing: powder-coated aluminium alloy, grey

Sealing: NBR

Protection rating

IP 65 (latched)

Temperature range

-40 °C to +100 °C, short-term up to +125 °C

Article List

Part number	Article	M	PG	Neck	Pieces / PU
H-A housing: hood (side cable entry, bolts for single lever)					
10564000	H-A 16 TS 16		16	yes	5
10564500	H-A 16 TS 21		21	yes	5
19564000	H-A 16 TS M20	20		yes	5
19564500	H-A 16 TS M25	25		yes	5

Footnote:

Photographs are not to scale and do not represent detailed images of the respective products.