


Housing design H-B. The industry standard.

### Product Description

The housing standard. Wide choice for all applications

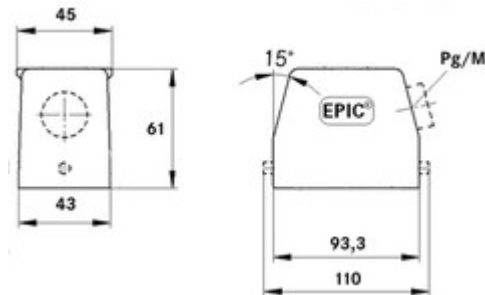

### Application range

- Plant engineering
- Light & sound technology
- Plastics industry

### Benefits

- The housing standard. Wide choice for all applications

### Product features

- Hood, low version
- Reels for single lever
- Side cable entry
- Versions with neck



Technical Data

Material

Housing: powder-coated aluminium alloy, grey

Lever: zinc-plated steel Sealing: NBR

Protection rating

IP 65 (latched)

Temperature range

-40 °C to +100 °C, short-term up to +125 °C

Article List

Part number	Article	M	PG	Neck	Pieces / PU
H-B housing: hood (side cable entry, bolts for single lever)					
10082900	H-B 16 TS-RO 21		21	yes	5
10092900	H-B 16 TS-RO 29		29	yes	5
19082900	H-B 16 TS-RO M25	25		yes	5
19092900	H-B 16 TS-RO M32	32		yes	5

Footnote:

Photographs are not to scale and do not represent detailed images of the respective products.