


Artikel-Nr.: 607826

Bez.: Koax-Kabel, 5-fach geschirmt, 135 dB

inner conductor ø mm, material	1,13	Cu
insulation ø mm, material	4,8	foamed PE 63%
1. screening foil	Al-foil	double faced
2. screening braid, material	128 x 0,12	Al
3. screening foil	Al-foil	double faced
4. screening braid, material	128 x 0,12	Al
5. screening foil	Al-foil	double faced
humidity blocker	gel	
jacket ø mm, material/colour	8,2	PVC/white

attenuation, at 20°C in dB/100 m	100 MHz	4,9 dB
	200 MHz	6,7 dB
	300 MHz	8,5 dB
	500 MHz	11,9 dB
	800 MHz	15,3 dB
	1000 MHz	17,4 dB
	1350 MHz	21,3 dB
	1750 MHz	23,9 dB
2050 MHz	27,3 dB	

impedance	75 Ω
screening immunity	> 135 dB
velocity factor v/c	0,8
min. bending radius mm	40

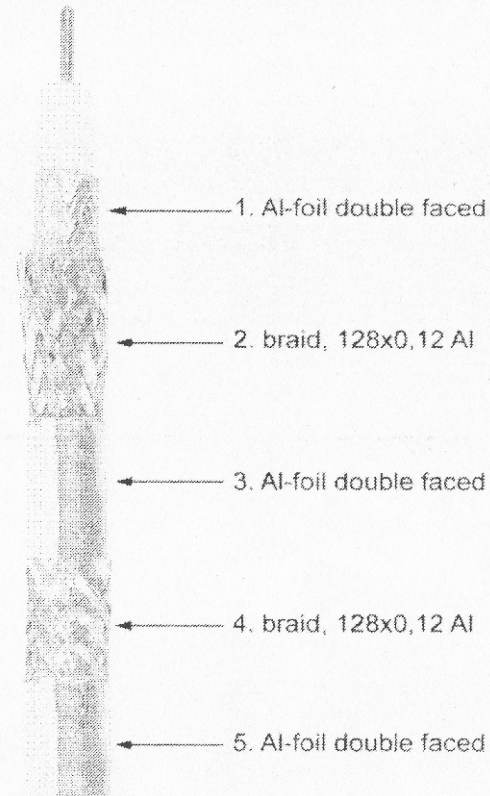

Class A

www.bkl-electronic.de

Technische Änderungen vorbehalten. Ausführungen können variieren. Sollten Sie ein Muster benötigen kontaktieren Sie uns bitte.

BKL-ELECTRONIC Kreimendahl GmbH • Märkenstück 14 • 58509 Lüdenscheid

Tel: +49 (0)2351-3621-0 • Fax: +49 (0)2351-3621-29 • info@bkl-electronic.de

