


USB2.0 DATA CABLE (5 meter/10 meter)

Datasheet

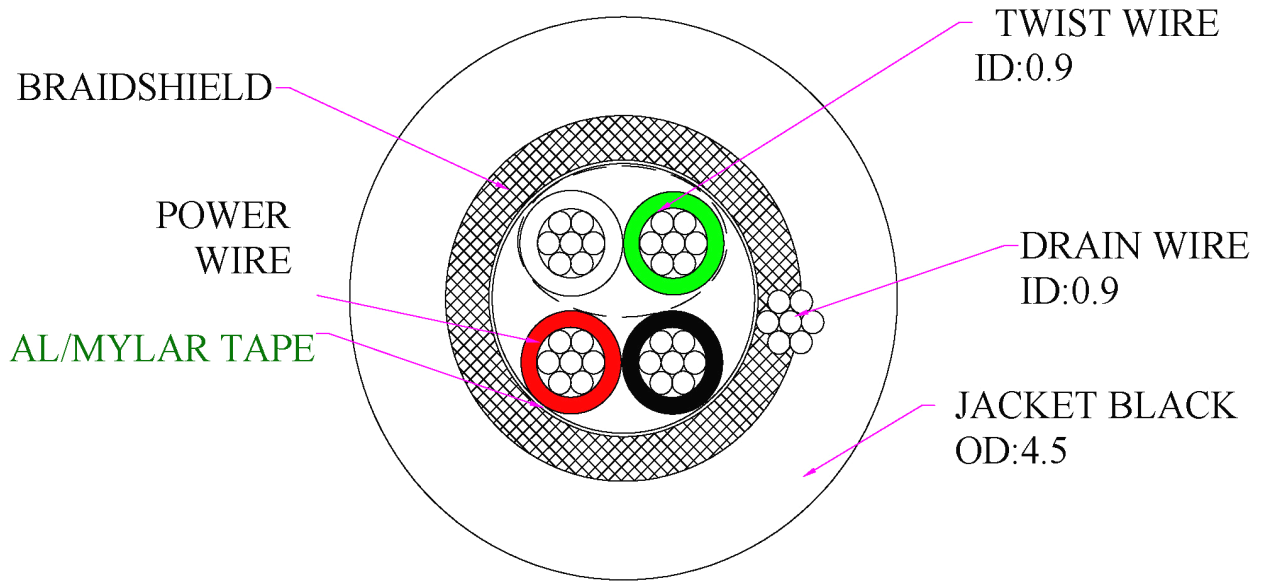

ITEM	SPECIFICATION	CONDUCTOR				
BRAID SHIELD	0.1*32	ALMG	DESCRIPTION	USB 2.0 CABLE		
DRAIN WIRE	28AWG*1C: 0.12*7	CCA	DRAWING	Archer Xu	APPROVED YOU	
POWER WIRE	28AWG*1C: 0.12*7	CCA	THIRD ANGLE PROJECT	SCALE	SHEET	UNIT
TWIST WIRE	28AWG*1C: 0.12*7	CCA		NONE	1/1	mm
					REV	A

Item No.	USB2.0 CABLE 5M	USB2.0 CABLE 10M
B/N	608513	608425
Jacker, outer dimension	PVC 4.5mm	PVC 4.5mm
Length	5 meter	10 meter
No. of conductors	7x 0.12 mm	7x 0.12 mm
strand per conductor	0.08 sqmm	0.08 sqmm
color	BLACK	BLACK
Material	CCA	CCA
Packaging	5 meter/blue spool	10 meter/blue spool

Technical Data

- Material of the jacket : PVC 4.5mm
- Conductor resistance (Ohm/km): Max 0.6 ohm/m
- Insulation resistance: Min 200M ohm x km
- Withstanding voltage: 5V / DC
- Operating temperature: -20 to +70 C