


HANDELSONDERNEMING KERAF BV

Datenblatt - Datasheet

Produkt / product	Caravan Einspeisungsstecker / Caravan Flush Inlet
Artikel / article	107153- 307W
Material / material	Polyamid PA6 / polyamide PA6
Farbe / color	Weiss / white
Schutzart / protection class	spritzwassergeschützt, IP44 / <i>splash proof, IP44</i>
Chemische Beständigkeit / chemical resistance	öl- sowie benzinbeständig <i>oil and gasoline</i> Komplette Beständigkeitsliste auf Anfrage verfügbar <i>Complete report on chemical resistance available on request</i>
Temperaturbeständigkeit / temperature resistance	-25°C bis 40°C <i>-25°C to 40°C</i>
Technische daten technical details	16A 250V~ 2-polig+E, nach IEC/EN 60309, VDE0623 <i>16A 250VAC 2 poles and earth contact according to IEC/EN 60309, VDE0623</i>
Gewicht / weight	230 Gr. / 230 gr.
Prüfzeichen / certification	KEMA geprüft / <i>KEMA certificated</i>
Abmessungen / Dimensions	 <p>The technical drawing shows two views of the Caravan Flush Inlet. The front view (left) shows a square-shaped device with a circular opening in the center. Dimensions are: total width 107, total height 107, inner width 90, inner height 78, and a small hole diameter of 5 (labeled as Ø5). The side view (right) shows the device's profile with a total width of 98 and a total height of 85.</p>

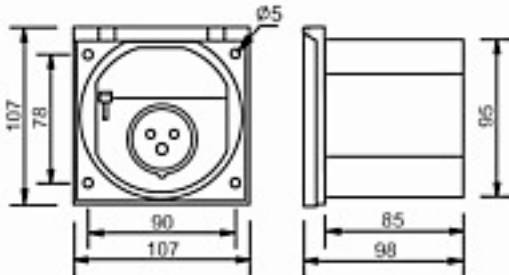