

DIGITUS® CAT 6, High Density Patch Panel, shielded



✓ High Density - only 0.5U

✓ Category 6

✓ Shielded, 24-port

✓ Available in grey and black

Abstract

DIGITUS® CAT 6, High Density Patch Panel, shielded, rack mount, 0.5U, 24-port

Features


- CAT 6
- 24x RJ45 jacks, 8P8C
- Height unit: Only 0.5U
- Shielded
- Dust protection caps
- Manufactured acc. to Link Performance Class E, for up to 250 MHz, EN 50173 and ISO/IEC 11801
- Cable installation via LSA strips, color coded acc. EIA/TIA 568 A & B
- Fixing option for cable ties, central ground connection
- Suitable for 483 mm (19") rack mount
- Available in color light grey (RAL 7035) and black (RAL 9005)

Product Overview


The DIGITUS® 24-port 0.5U Patch Panel offers a high density.

As the panel is only 0.5U in height, it allows to present 48 ports on 1U (2 panels with 24 ports each) which can be installed.

Product Images

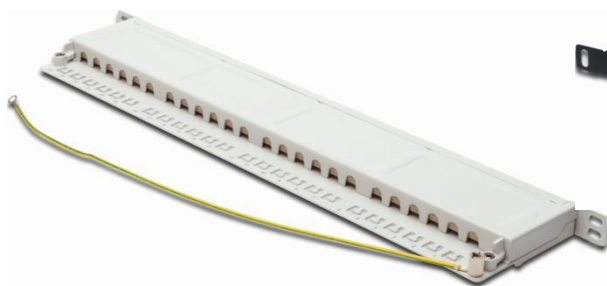

Technical Drawings

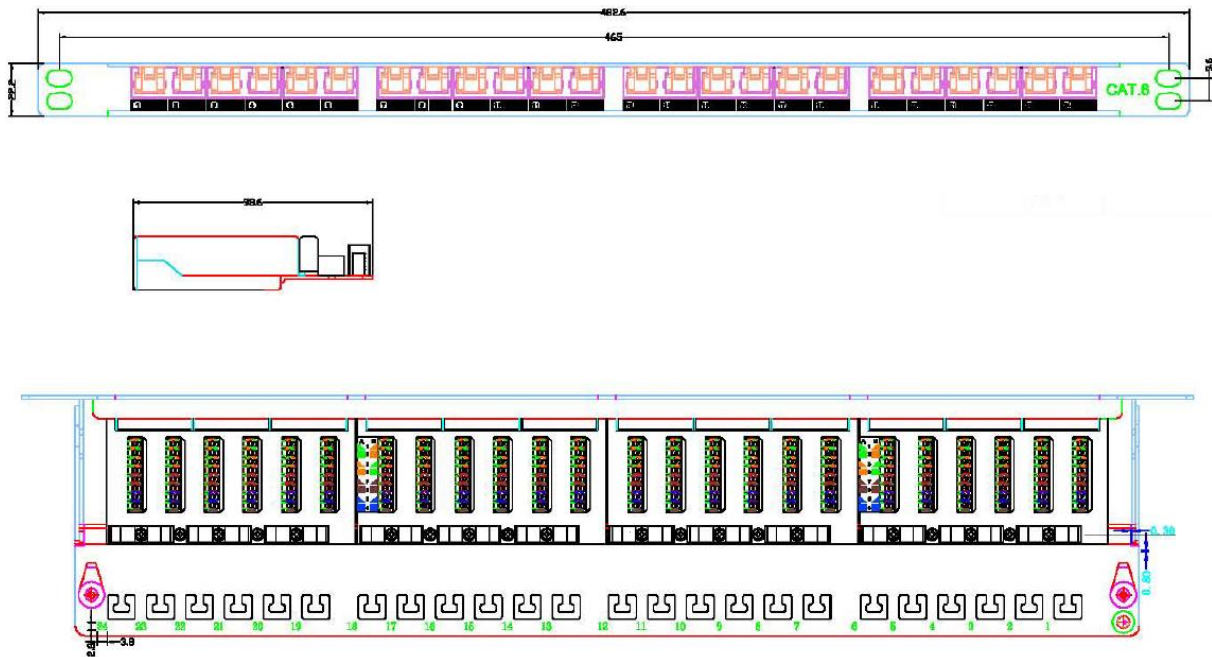

Product Number Information

| | |
|-------------------|--|
| DN-91624S-SL-SH | DIGITUS® CAT 6 Patch Panel, shielded, 24-port RJ45, incl. shutter, 8P8C, LSA, 0.5U, 19" rack mount, color black (RAL 9005) |
| DN-91624S-SL-SH-G | DIGITUS® CAT 6 Patch Panel, shielded, 24-port RJ45, incl. shutter, 8P8C, LSA, 0.5U, 19" rack mount, color grey (RAL 7035) |

More High Density Patch Panel DIGITUS®

| | |
|-----------------|---|
| DN-91624S-SL-EA | DIGITUS® CAT 6 _A , Class E _A High Density Patch Panel, shielded, 0.5U, 24-port, RJ45, incl. dust protection shutter, 8P8C, color black (RAL 9005) |
| DN-91624U-SL-SH | DIGITUS® CAT 6 Patch Panel, unshielded, 24-port RJ45, incl. shutter, 8P8C, LSA, 0.5U, 19" rack mount, color black (RAL 9005) |

Product Number Information - Accessories

| | |
|--------------|---|
| DN-LSA-PT | DIGITUS® LSA Punch Down Tool |
| DN-94014 | DIGITUS® Pliers, cutting area 0.7 mm hole, for precise and easy cutting, compact design, with ergonomic handle (yellow) |
| DN-94015 | DIGITUS® Cutter & Stripper, 5" electrical cutter & stripper for flush cutting, size 20-24 AWG |
| DN-CT-10M-20 | Velcro Tape, 20 mm wide, for structured cabling, 10 m roll, color black |