



## Data sheet | Item number: 857-552

Current signal conditioner; Input for Rogowski coils; Current and voltage output signal; Digital output; Configuration via software; Supply voltage: 24 VDC; 6 mm module width

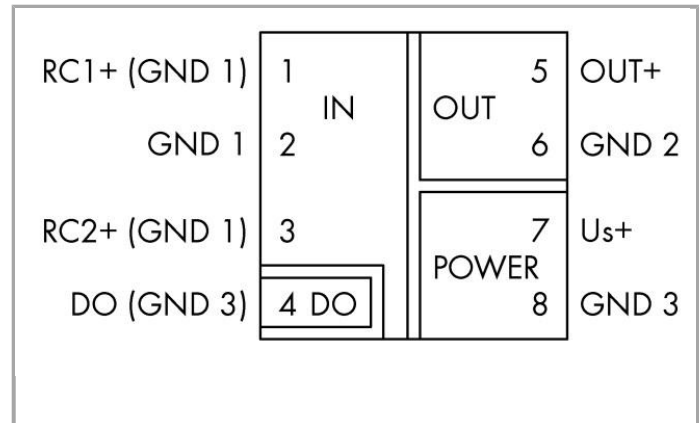

[www.wago.com/857-552](http://www.wago.com/857-552)

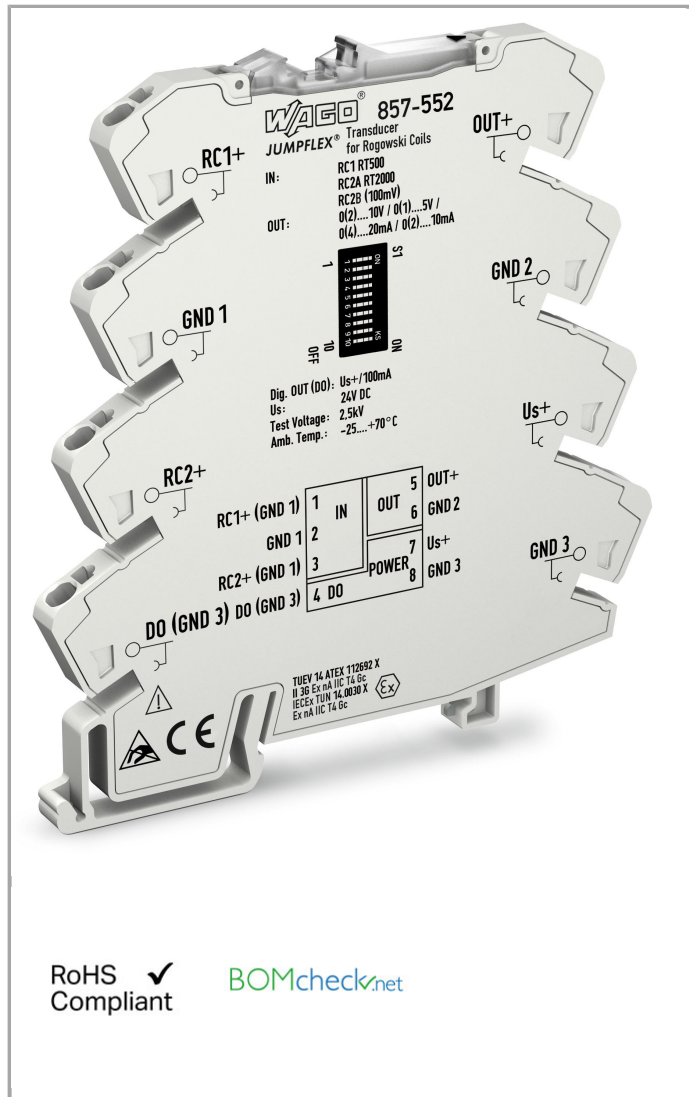

### Item description

#### Short description:

The Rogowski Signal Conditioner records RMS values from alternating currents via Rogowski coil and converts the input signal into a standard analog signal on the output side.

#### Features:

- PC configuration interface
- Supports different types of Rogowski coils
- Digital switching output (configurable switching thresholds)
- True RMS measurement (TRMS)

- Configurable output signal
- Configuration via DIP switch
- Safe 3-way isolation with 2.5 kV test voltage acc. to EN 61140
- No current bar interruption during installation
- Measuring range overflow indication

**Note:**

(\* Additional setting options via interface configuration software or interface configuration app)

**Data****Technical Data****Configuration**

Configuration options	DIP switches Interface configuration software Interface configuration app
-----------------------	---

**Input**

Input signal type	Voltage
Input signal voltage	50 Hz sinusoidal signals: 10.05 mV AC (RC1); 40.2 mV AC (RC2A); 90 mV AC (RC2B)
Sensitivity	RC2B: 22,5 mV/kA
Measurement range, current	500AAC (RC1); 2000AAC (RC2A); 4000AAC (RC2B)
Frequency range	50Hz (Sinussignale)
Response threshold	≤ 1 % (of measuring range nominal value)
Resolution	250 mA (RC1); 1 A (RC2A); 1.5 A (RC2B)

**Output**

Output signal type	Current Voltage
Output signal voltage	0 ... 5 V; 1 ... 5 V; 0 ... 10 V; 2 ... 10 V
Output signal current	0 ... 10 mA; 2 ... 10 mA; 0 ... 20 mA; 4 ... 20 mA
Load impedance (output/voltage)	≥ 1kΩ
Load impedance (output/current)	≤ 600Ω

**Output – Digital**

Max. switching voltage (DO)	Supply voltage applied
Max. continuous current (DO)	100mA (no internal restriction)
Number of switching thresholds (DO)	1 (adjustable)



## Signal processing

Measuring procedure	True RMS measurement (TRMS)
Max. operating frequency	2kHz
Software filter; adjustable	moving mean value (filtering level: 30)

## Measurement error

Transmission error max.	$\leq 1\%$ (of the full scale value)
Temperature coefficient	$\leq 0.01\%/K$

## Power supply

Type of power supply	24 VDC
Nominal supply voltage $U_S$	24 VDC
Supply voltage range	$\pm 30\%$
Current consumption at supply voltage	40 mA (+ $I_{D0}$ )

## Safety and protection:

Test voltage (input/output/supply)	2.5 kV AC; 50Hz; 1 min
Degree of protection	IP20

## Connection data

Connection technology	Push-in CAGE CLAMP®
Solid conductor	0.08 ... 2.5 mm <sup>2</sup> / 28 ... 14 AWG
Fine-stranded conductor	0.34 ... 2.5 mm <sup>2</sup> / 22 ... 14 AWG
Strip length	9 ... 10 mm / 0.35 ... 0.39 Inch

## Geometrical Data

Width	6 mm / 0.236 inch
Height from upper-edge of DIN-35 rail	97.8 mm / 3.85 inch
Depth	94 mm / 3.701 inch

## Mechanical data

Type of mounting	DIN-35 rail
------------------	-------------

## Material Data

Color	light gray
Weight	35.113 g

## Environmental Requirements

Surrounding air (operating) temperature	-25 ... 70 °C
Surrounding air (storage) temperature	-40 ... 85 °C

## Standards and specifications





Conformity marking	CE
--------------------	----

## Commercial data

Packaging type	bag
Country of origin	DE
GTIN	4050821476917
Customs Tariff No.	85437090300
Product Group	6 (Interface Electronics)

## Compatible products

### current transformer

	<b>Item no.: 855-9100/2000-000</b> Rogowski coil; Primary rated current: 2000 A; Output signal: 40.2 mV; Cable length: 1.5 m	<a href="http://www.wago.com/855-9100/2000-000">www.wago.com/855-9100/2000-000</a>
	<b>Item no.: 855-9100/500-000</b> Rogowski coil; Primary rated current: 500 A; Output signal: 10.05 mV; Cable length: 1.5 m	<a href="http://www.wago.com/855-9100/500-000">www.wago.com/855-9100/500-000</a>
	<b>Item no.: 855-9150/2000-1251</b> Rogowski coil; Primary rated current 4000 A; Output signal 22.5 mV per kA; Cable length: 1.5 m; Accuracy class: 1; Feedthrough for measurement conductor 125 mm	<a href="http://www.wago.com/855-9150/2000-1251">www.wago.com/855-9150/2000-1251</a>
	<b>Item no.: 855-9150/2000-1751</b> Rogowski coil; Primary rated current 4000 A; Output signal 22.5 mV per kA; Cable length: 1.5 m; Accuracy class: 1; Feedthrough for measurement conductor 175 mm	<a href="http://www.wago.com/855-9150/2000-1751">www.wago.com/855-9150/2000-1751</a>
	<b>Item no.: 855-9150/2000-701</b> Rogowski coil; Primary rated current 4000 A; Output signal 22.5 mV per kA; Cable length: 1.5 m; Accuracy class: 1; Feedthrough for measurement conductor 70 mm	<a href="http://www.wago.com/855-9150/2000-701">www.wago.com/855-9150/2000-701</a>
	<b>Item no.: 855-9300/2000-000</b> Rogowski coil; Primary rated current: 2000 A; Output signal: 40.2 mV; Cable length: 3 m	<a href="http://www.wago.com/855-9300/2000-000">www.wago.com/855-9300/2000-000</a>
	<b>Item no.: 855-9300/500-000</b> Rogowski coil; Primary rated current: 500 A; Output signal: 10.05 mV; Cable length: 3 m	<a href="http://www.wago.com/855-9300/500-000">www.wago.com/855-9300/500-000</a>
	<b>Item no.: 855-9450/2000-1251</b> Rogowski coil; Primary rated current 4000 A; Output signal 22.5 mV per kA; Cable length 4.5 m; Accuracy class: 1; Feedthrough for measurement conductor 125 mm	<a href="http://www.wago.com/855-9450/2000-1251">www.wago.com/855-9450/2000-1251</a>

**Item no.: 855-9450/2000-1751**

Rogowski coil; Primary rated current 4000 A; Output signal 22.5 mV per kA; Cable length 4.5 m; Accuracy class: 1; Feedthrough for measurement conductor 175 mm

[www.wago.com/855-9450/2000-1751](http://www.wago.com/855-9450/2000-1751)

**Item no.: 855-9450/2000-701**

Rogowski coil; Primary rated current 4000 A; Output signal 22.5 mV per kA; Cable length 4.5 m; Accuracy class: 1; Feedthrough for measurement conductor 70 mm

[www.wago.com/855-9450/2000-701](http://www.wago.com/855-9450/2000-701)

**tools****Item no.: 210-720**

Operating tool with partially insulated shaft; Type 2, blade (3.5 x 0.5) mm

[www.wago.com/210-720](http://www.wago.com/210-720)

**assembling****Item no.: 249-116**

Screwless end stop; 6 mm wide

[www.wago.com/249-116](http://www.wago.com/249-116)

**Item no.: 249-117**

Screwless end stop; 10 mm wide

[www.wago.com/249-117](http://www.wago.com/249-117)

**Item no.: 249-197**

Screwless end stop; 14 mm wide

[www.wago.com/249-197](http://www.wago.com/249-197)

**power supply****Item no.: 787-2852**

Switched-mode power supply; for JUMPFLEX® Signal Conditioners; 1-phase; 24 VDC output voltage; 1 A output current

[www.wago.com/787-2852](http://www.wago.com/787-2852)

**Jumper****Item no.: 281-482**

Comb-style jumper bar; insulated; 2-way; IN = IN terminal block

[www.wago.com/281-482](http://www.wago.com/281-482)

**Item no.: 859-402**

Push-in type jumper bar; 2-way; Nominal current 18 A; insulated

[www.wago.com/859-402](http://www.wago.com/859-402)

**Item no.: 859-402/000-005**

Push-in type jumper bar; 2-way; Nominal current 18 A; insulated

[www.wago.com/859-402/000-005](http://www.wago.com/859-402/000-005)

**Item no.: 859-402/000-006**

Push-in type jumper bar; 2-way; Nominal current 18 A; insulated

[www.wago.com/859-402/000-006](http://www.wago.com/859-402/000-006)

**Item no.: 859-402/000-029**

Push-in type jumper bar; 2-way; Nominal current 18 A; insulated

[www.wago.com/859-402/000-029](http://www.wago.com/859-402/000-029)

**Item no.: 859-403**

















Push-in type jumper bar; 3-way; Nominal current 18 A; insulated














 
[www.wago.com/859-403](http://www.wago.com/859-403)

**Item no.: 859-403/000-005**

Push-in type jumper bar; 3-way; Nominal current 18 A; insulated

[www.wago.com/859-403/000-005](http://www.wago.com/859-403/000-005)

	<p><b>Item no.: 859-403/000-006</b>                      Push-in type jumper bar; 3-way; Nominal current 18 A; insulated</p>	<a href="http://www.wago.com/859-403/000-006">www.wago.com/859-403/000-006</a>
	<p><b>Item no.: 859-403/000-029</b>                      Push-in type jumper bar; 3-way; Nominal current 18 A; insulated</p>	<a href="http://www.wago.com/859-403/000-029">www.wago.com/859-403/000-029</a>
	<p><b>Item no.: 859-404</b>                      Push-in type jumper bar; 4-way; Nominal current 18 A; insulated</p>	<a href="http://www.wago.com/859-404">www.wago.com/859-404</a>
	<p><b>Item no.: 859-404/000-005</b>                      Push-in type jumper bar; 4-way; Nominal current 18 A; insulated</p>	<a href="http://www.wago.com/859-404/000-005">www.wago.com/859-404/000-005</a>
	<p><b>Item no.: 859-404/000-006</b>                      Push-in type jumper bar; 4-way; Nominal current 18 A; insulated</p>	<a href="http://www.wago.com/859-404/000-006">www.wago.com/859-404/000-006</a>
	<p><b>Item no.: 859-404/000-029</b>                      Push-in type jumper bar; 4-way; Nominal current 18 A; insulated</p>	<a href="http://www.wago.com/859-404/000-029">www.wago.com/859-404/000-029</a>
	<p><b>Item no.: 859-405</b>                      Push-in type jumper bar; 5-way; Nominal current 18 A; insulated</p>	<a href="http://www.wago.com/859-405">www.wago.com/859-405</a>
	<p><b>Item no.: 859-405/000-005</b>                      Push-in type jumper bar; 5-way; Nominal current 18 A; insulated</p>	<a href="http://www.wago.com/859-405/000-005">www.wago.com/859-405/000-005</a>
	<p><b>Item no.: 859-405/000-006</b>                      Push-in type jumper bar; 5-way; Nominal current 18 A; insulated</p>	<a href="http://www.wago.com/859-405/000-006">www.wago.com/859-405/000-006</a>
	<p><b>Item no.: 859-405/000-029</b>                      Push-in type jumper bar; 5-way; Nominal current 18 A; insulated</p>	<a href="http://www.wago.com/859-405/000-029">www.wago.com/859-405/000-029</a>
	<p><b>Item no.: 859-406</b>                      Push-in type jumper bar; 6-way; Nominal current 18 A; insulated</p>	<a href="http://www.wago.com/859-406">www.wago.com/859-406</a>
	<p><b>Item no.: 859-406/000-005</b>                      Push-in type jumper bar; 6-way; Nominal current 18 A; insulated</p>	<a href="http://www.wago.com/859-406/000-005">www.wago.com/859-406/000-005</a>
	<p><b>Item no.: 859-406/000-006</b>                      Push-in type jumper bar; 6-way; Nominal current 18 A; insulated</p>	<a href="http://www.wago.com/859-406/000-006">www.wago.com/859-406/000-006</a>
	<p><b>Item no.: 859-406/000-029</b>                      Push-in type jumper bar; 6-way; Nominal current 18 A; insulated</p>	<a href="http://www.wago.com/859-406/000-029">www.wago.com/859-406/000-029</a>
	<p><b>Item no.: 859-407</b>                      Push-in type jumper bar; 7-way; Nominal current 18 A; insulated</p>	<a href="http://www.wago.com/859-407">www.wago.com/859-407</a>
	<p><b>Item no.: 859-407/000-005</b>                      Push-in type jumper bar; 7-way; Nominal current 18 A; insulated</p>	<a href="http://www.wago.com/859-407/000-005">www.wago.com/859-407/000-005</a>

	<b>Item no.: 859-407/000-006</b> Push-in type jumper bar; 7-way; Nominal current 18 A; insulated	<a href="http://www.wago.com/859-407/000-006">www.wago.com/859-407/000-006</a>
	<b>Item no.: 859-407/000-029</b> Push-in type jumper bar; 7-way; Nominal current 18 A; insulated	<a href="http://www.wago.com/859-407/000-029">www.wago.com/859-407/000-029</a>
	<b>Item no.: 859-408</b> Push-in type jumper bar; 8-way; Nominal current 18 A; insulated	<a href="http://www.wago.com/859-408">www.wago.com/859-408</a>
	<b>Item no.: 859-408/000-005</b> Push-in type jumper bar; 8-way; Nominal current 18 A; insulated	<a href="http://www.wago.com/859-408/000-005">www.wago.com/859-408/000-005</a>
	<b>Item no.: 859-408/000-006</b> Push-in type jumper bar; 8-way; Nominal current 18 A; insulated	<a href="http://www.wago.com/859-408/000-006">www.wago.com/859-408/000-006</a>
	<b>Item no.: 859-408/000-029</b> Push-in type jumper bar; 8-way; Nominal current 18 A; insulated	<a href="http://www.wago.com/859-408/000-029">www.wago.com/859-408/000-029</a>
	<b>Item no.: 859-409</b> Push-in type jumper bar; 9-way; Nominal current 18 A; insulated	<a href="http://www.wago.com/859-409">www.wago.com/859-409</a>
	<b>Item no.: 859-409/000-005</b> Push-in type jumper bar; 9-way; Nominal current 18 A; insulated	<a href="http://www.wago.com/859-409/000-005">www.wago.com/859-409/000-005</a>
	<b>Item no.: 859-409/000-006</b> Push-in type jumper bar; 9-way; Nominal current 18 A; insulated	<a href="http://www.wago.com/859-409/000-006">www.wago.com/859-409/000-006</a>
	<b>Item no.: 859-409/000-029</b> Push-in type jumper bar; 9-way; Nominal current 18 A; insulated	<a href="http://www.wago.com/859-409/000-029">www.wago.com/859-409/000-029</a>
	<b>Item no.: 859-410</b> Push-in type jumper bar; 10-way; Nominal current 18 A; insulated	<a href="http://www.wago.com/859-410">www.wago.com/859-410</a>
	<b>Item no.: 859-410/000-005</b> Push-in type jumper bar; 10-way; Nominal current 18 A; insulated	<a href="http://www.wago.com/859-410/000-005">www.wago.com/859-410/000-005</a>
	<b>Item no.: 859-410/000-006</b> Push-in type jumper bar; 10-way; Nominal current 18 A; insulated	<a href="http://www.wago.com/859-410/000-006">www.wago.com/859-410/000-006</a>
	<b>Item no.: 859-410/000-029</b> Push-in type jumper bar; 10-way; Nominal current 18 A; insulated	<a href="http://www.wago.com/859-410/000-029">www.wago.com/859-410/000-029</a>

#### General accessories

	<b>Item no.: 750-921</b> Bluetooth® Adapter	<a href="http://www.wago.com/750-921">www.wago.com/750-921</a>
--	--	--



**Item no.: 750-923**  
Configuration cable; USB connector

[www.wago.com/750-923](http://www.wago.com/750-923)



**Item no.: 750-923/000-001**  
Configuration cable; USB connector

[www.wago.com/750-923/000-001](http://www.wago.com/750-923/000-001)



**Item no.: 857-304**  
Relay module; Nominal input voltage: 24 VDC; 1 changeover contact; Limiting continuous current: 6 A; Yellow status indicator; Module width: 6 mm

[www.wago.com/857-304](http://www.wago.com/857-304)



**Item no.: 857-979**  
Supply and through module

[www.wago.com/857-979](http://www.wago.com/857-979)

### Marking accessories



**Item no.: 2009-110**  
Marking strips; on reel; not stretchable; plain; snap-on type

[www.wago.com/2009-110](http://www.wago.com/2009-110)



**Item no.: 2009-115**  
WMB-Inline; for smartPRINTER; on reel; stretchable 5 - 5.2 mm; plain; snap-on type

[www.wago.com/2009-115](http://www.wago.com/2009-115)



**Item no.: 2009-115/000-002**  
WMB-Inline; for smartPRINTER; on reel; stretchable 5 - 5.2 mm; plain; snap-on type

[www.wago.com/2009-115/000-002](http://www.wago.com/2009-115/000-002)



**Item no.: 2009-115/000-006**  
WMB-Inline; for smartPRINTER; on reel; stretchable 5 - 5.2 mm; plain; snap-on type

[www.wago.com/2009-115/000-006](http://www.wago.com/2009-115/000-006)



**Item no.: 2009-115/000-007**  
WMB-Inline; for smartPRINTER; on reel; stretchable 5 - 5.2 mm; plain; snap-on type

[www.wago.com/2009-115/000-007](http://www.wago.com/2009-115/000-007)



**Item no.: 2009-115/000-012**  
WMB-Inline; for smartPRINTER; on reel; stretchable 5 - 5.2 mm; plain; snap-on type

[www.wago.com/2009-115/000-012](http://www.wago.com/2009-115/000-012)



**Item no.: 2009-115/000-017**  
WMB-Inline; for smartPRINTER; on reel; stretchable 5 - 5.2 mm; plain; snap-on type

[www.wago.com/2009-115/000-017](http://www.wago.com/2009-115/000-017)



**Item no.: 2009-115/000-023**  
WMB-Inline; for smartPRINTER; on reel; stretchable 5 - 5.2 mm; plain; snap-on type

[www.wago.com/2009-115/000-023](http://www.wago.com/2009-115/000-023)



**Item no.: 2009-115/000-024**  
WMB-Inline; for smartPRINTER; on reel; stretchable 5 - 5.2 mm; plain; snap-on type

[www.wago.com/2009-115/000-024](http://www.wago.com/2009-115/000-024)



**Item no.: 793-501**  
WMB marking card; as card; not stretchable; plain; snap-on type

[www.wago.com/793-501](http://www.wago.com/793-501)



**Item no.: 793-501/000-002**  
WMB marking card; as card; not stretchable; plain; snap-on type

[www.wago.com/793-501/000-002](http://www.wago.com/793-501/000-002)





**Item no.: 793-501/000-005**  
WMB marking card; as card; not stretchable; plain; snap-on type

[www.wago.com/793-501/000-005](http://www.wago.com/793-501/000-005)



**Item no.: 793-501/000-006**  
WMB marking card; as card; not stretchable; plain; snap-on type

[www.wago.com/793-501/000-006](http://www.wago.com/793-501/000-006)



**Item no.: 793-501/000-007**  
WMB marking card; as card; not stretchable; plain; snap-on type

[www.wago.com/793-501/000-007](http://www.wago.com/793-501/000-007)



**Item no.: 793-501/000-012**  
WMB marking card; as card; not stretchable; plain; snap-on type

[www.wago.com/793-501/000-012](http://www.wago.com/793-501/000-012)



**Item no.: 793-501/000-017**  
WMB marking card; as card; not stretchable; plain; snap-on type

[www.wago.com/793-501/000-017](http://www.wago.com/793-501/000-017)



**Item no.: 793-501/000-023**  
WMB marking card; as card; not stretchable; plain; snap-on type

[www.wago.com/793-501/000-023](http://www.wago.com/793-501/000-023)



**Item no.: 793-501/000-024**  
WMB marking card; as card; not stretchable; plain; snap-on type

[www.wago.com/793-501/000-024](http://www.wago.com/793-501/000-024)



**Item no.: 793-502**  
WMB marking card; as card; MARKED; 1 ... 10 (10x); not stretchable; Horizontal marking; snap-on type

[www.wago.com/793-502](http://www.wago.com/793-502)



**Item no.: 793-502/000-002**  
WMB marking card; as card; MARKED; 1 ... 10 (10x); not stretchable; Horizontal marking; snap-on type

[www.wago.com/793-502/000-002](http://www.wago.com/793-502/000-002)



**Item no.: 793-502/000-005**  
WMB marking card; as card; MARKED; 1 ... 10 (10x); not stretchable; Horizontal marking; snap-on type

[www.wago.com/793-502/000-005](http://www.wago.com/793-502/000-005)



**Item no.: 793-502/000-006**  
WMB marking card; as card; MARKED; 1 ... 10 (10x); not stretchable; Horizontal marking; snap-on type

[www.wago.com/793-502/000-006](http://www.wago.com/793-502/000-006)



**Item no.: 793-502/000-007**  
WMB marking card; as card; MARKED; 1 ... 10 (10x); not stretchable; Horizontal marking; snap-on type

[www.wago.com/793-502/000-007](http://www.wago.com/793-502/000-007)



**Item no.: 793-502/000-012**  
WMB marking card; as card; MARKED; 1 ... 10 (10x); not stretchable; Horizontal marking; snap-on type

[www.wago.com/793-502/000-012](http://www.wago.com/793-502/000-012)



**Item no.: 793-502/000-017**  
WMB marking card; as card; MARKED; 1 ... 10 (10x); not stretchable; Horizontal marking; snap-on type

[www.wago.com/793-502/000-017](http://www.wago.com/793-502/000-017)



**Item no.: 793-502/000-023**  
WMB marking card; as card; MARKED; 1 ... 10 (10x); not stretchable; Horizontal marking; snap-on type

[www.wago.com/793-502/000-023](http://www.wago.com/793-502/000-023)

**Item no.: 793-502/000-024**

WMB marking card; as card; MARKED; 1 ... 10 (10x); not stretchable; Horizontal marking; snap-on type

[www.wago.com/793-502](http://www.wago.com/793-502)

/000-024

**Item no.: 793-503**

WMB marking card; as card; MARKED; 11 ... 20 (10x); not stretchable; Horizontal marking; snap-on type

[www.wago.com/793-503](http://www.wago.com/793-503)**Item no.: 793-503/000-002**

WMB marking card; as card; MARKED; 11 ... 20 (10x); not stretchable; Horizontal marking; snap-on type

[www.wago.com/793-503](http://www.wago.com/793-503)

/000-002

**Item no.: 793-503/000-005**

WMB marking card; as card; MARKED; 11 ... 20 (10x); not stretchable; Horizontal marking; snap-on type

[www.wago.com/793-503](http://www.wago.com/793-503)

/000-005

**Item no.: 793-503/000-006**

WMB marking card; as card; MARKED; 11 ... 20 (10x); not stretchable; Horizontal marking; snap-on type

[www.wago.com/793-503](http://www.wago.com/793-503)

/000-006

**Item no.: 793-503/000-007**

WMB marking card; as card; MARKED; 11 ... 20 (10x); not stretchable; Horizontal marking; snap-on type

[www.wago.com/793-503](http://www.wago.com/793-503)

/000-007

**Item no.: 793-503/000-012**

WMB marking card; as card; MARKED; 11 ... 20 (10x); not stretchable; Horizontal marking; snap-on type

[www.wago.com/793-503](http://www.wago.com/793-503)

/000-012

**Item no.: 793-503/000-017**

WMB marking card; as card; MARKED; 11 ... 20 (10x); not stretchable; Horizontal marking; snap-on type

[www.wago.com/793-503](http://www.wago.com/793-503)

/000-017

**Item no.: 793-503/000-023**

WMB marking card; as card; MARKED; 11 ... 20 (10x); not stretchable; Horizontal marking; snap-on type

[www.wago.com/793-503](http://www.wago.com/793-503)

/000-023

**Item no.: 793-503/000-024**

WMB marking card; as card; MARKED; 11 ... 20 (10x); not stretchable; Horizontal marking; snap-on type

[www.wago.com/793-503](http://www.wago.com/793-503)

/000-024

**Item no.: 793-504**

WMB marking card; as card; MARKED; 21 ... 30 (10x); not stretchable; Horizontal marking; snap-on type

[www.wago.com/793-504](http://www.wago.com/793-504)**Item no.: 793-504/000-002**

WMB marking card; as card; MARKED; 21 ... 30 (10x); not stretchable; Horizontal marking; snap-on type

[www.wago.com/793-504](http://www.wago.com/793-504)

/000-002

**Item no.: 793-504/000-005**

WMB marking card; as card; MARKED; 21 ... 30 (10x); not stretchable; Horizontal marking; snap-on type

[www.wago.com/793-504](http://www.wago.com/793-504)

/000-005

**Item no.: 793-504/000-006**

WMB marking card; as card; MARKED; 21 ... 30 (10x); not stretchable; Horizontal marking; snap-on type

[www.wago.com/793-504](http://www.wago.com/793-504)

/000-006

**Item no.: 793-504/000-012**

WMB marking card; as card; MARKED; 21 ... 30 (10x); not stretchable; Horizontal marking; snap-on type

[www.wago.com/793-504](http://www.wago.com/793-504)

/000-012

**Item no.: 793-504/000-017**

WMB marking card; as card; MARKED; 21 ... 30 (10x); not stretchable; Horizontal marking; snap-on type

[www.wago.com/793-504](http://www.wago.com/793-504)

/000-017

**Item no.: 793-504/000-023**

WMB marking card; as card; MARKED; 21 ... 30 (10x); not stretchable; Horizontal marking; snap-on type

[www.wago.com/793-504](http://www.wago.com/793-504)

/000-023

**Item no.: 793-505**

WMB marking card; as card; MARKED; 31 ... 40 (10x); not stretchable; Horizontal marking; snap-on type

[www.wago.com/793-505](http://www.wago.com/793-505)**Item no.: 793-505/000-005**

WMB marking card; as card; MARKED; 31 ... 40 (10x); not stretchable; Horizontal marking; snap-on type

[www.wago.com/793-505](http://www.wago.com/793-505)

/000-005

**Item no.: 793-505/000-006**

WMB marking card; as card; MARKED; 31 ... 40 (10x); not stretchable; Horizontal marking; snap-on type

[www.wago.com/793-505](http://www.wago.com/793-505)

/000-006

**Item no.: 793-505/000-007**

WMB marking card; as card; MARKED; 31 ... 40 (10x); not stretchable; Horizontal marking; snap-on type

[www.wago.com/793-505](http://www.wago.com/793-505)

/000-007

**Item no.: 793-505/000-012**

WMB marking card; as card; MARKED; 31 ... 40 (10x); not stretchable; Horizontal marking; snap-on type

[www.wago.com/793-505](http://www.wago.com/793-505)

/000-012

**Item no.: 793-506**

WMB marking card; as card; MARKED; 41 ... 50 (10x); not stretchable; Horizontal marking; snap-on type

[www.wago.com/793-506](http://www.wago.com/793-506)**Item no.: 793-506/000-005**

WMB marking card; as card; MARKED; 41 ... 50 (10x); not stretchable; Horizontal marking; snap-on type

[www.wago.com/793-506](http://www.wago.com/793-506)

/000-005

**Item no.: 793-506/000-006**

WMB marking card; as card; MARKED; 41 ... 50 (10x); not stretchable; Horizontal marking; snap-on type

[www.wago.com/793-506](http://www.wago.com/793-506)

/000-006

**Item no.: 793-506/000-012**

WMB marking card; as card; MARKED; 41 ... 50 (10x); not stretchable; Horizontal marking; snap-on type

[www.wago.com/793-506](http://www.wago.com/793-506)

/000-012

**Item no.: 793-506/000-017**

WMB marking card; as card; MARKED; 41 ... 50 (10x); not stretchable; Horizontal marking; snap-on type

[www.wago.com/793-506](http://www.wago.com/793-506)

/000-017

**Item no.: 793-5501**

WMB marking card; as card; for terminal block width 5 - 17.5 mm; stretchable 5 - 5.2 mm; plain; snap-on type

[www.wago.com/793-5501](http://www.wago.com/793-5501)**Item no.: 793-5501/000-002**

WMB marking card; as card; for terminal block width 5 - 17.5 mm; stretchable 5 - 5.2 mm; plain; snap-on type

[www.wago.com/793-5501](http://www.wago.com/793-5501)

/000-002

**Item no.: 793-5501/000-005**

WMB marking card; as card; stretchable 5 - 5.2 mm; plain; snap-on type

[www.wago.com/793-5501](http://www.wago.com/793-5501)

/000-005



**Item no.: 793-5501/000-006**  
WMB marking card; as card; stretchable 5 - 5.2 mm; plain; snap-on type

[www.wago.com/793-5501/000-006](http://www.wago.com/793-5501/000-006)



**Item no.: 793-5501/000-007**  
WMB marking card; as card; stretchable 5 - 5.2 mm; plain; snap-on type

[www.wago.com/793-5501/000-007](http://www.wago.com/793-5501/000-007)



**Item no.: 793-5501/000-012**  
WMB marking card; as card; stretchable 5 - 5.2 mm; plain; snap-on type

[www.wago.com/793-5501/000-012](http://www.wago.com/793-5501/000-012)



**Item no.: 793-5501/000-014**  
WMB marking card; as card; stretchable 5 - 5.2 mm; plain; snap-on type

[www.wago.com/793-5501/000-014](http://www.wago.com/793-5501/000-014)



**Item no.: 793-5501/000-017**  
WMB marking card; as card; stretchable 5 - 5.2 mm; plain; snap-on type

[www.wago.com/793-5501/000-017](http://www.wago.com/793-5501/000-017)



**Item no.: 793-5501/000-023**  
WMB marking card; as card; stretchable 5 - 5.2 mm; plain; snap-on type

[www.wago.com/793-5501/000-023](http://www.wago.com/793-5501/000-023)



**Item no.: 793-5501/000-024**  
WMB marking card; as card; stretchable 5 - 5.2 mm; plain; snap-on type

[www.wago.com/793-5501/000-024](http://www.wago.com/793-5501/000-024)



**Item no.: 793-566**  
WMB marking card; as card; MARKED; 1 ... 50 (2x); not stretchable; Horizontal marking; snap-on type

[www.wago.com/793-566](http://www.wago.com/793-566)



**Item no.: 793-566/000-002**  
WMB marking card; as card; MARKED; 1 ... 50 (2x); not stretchable; Horizontal marking; snap-on type

[www.wago.com/793-566/000-002](http://www.wago.com/793-566/000-002)



**Item no.: 793-566/000-005**  
WMB marking card; as card; MARKED; 1 ... 50 (2x); not stretchable; Horizontal marking; snap-on type

[www.wago.com/793-566/000-005](http://www.wago.com/793-566/000-005)



**Item no.: 793-566/000-006**  
WMB marking card; as card; MARKED; 1 ... 50 (2x); not stretchable; Horizontal marking; snap-on type

[www.wago.com/793-566/000-006](http://www.wago.com/793-566/000-006)



**Item no.: 793-566/000-007**  
WMB marking card; as card; MARKED; 1 ... 50 (2x); not stretchable; Horizontal marking; snap-on type

[www.wago.com/793-566/000-007](http://www.wago.com/793-566/000-007)



**Item no.: 793-566/000-012**  
WMB marking card; as card; MARKED; 1 ... 50 (2x); not stretchable; Horizontal marking; snap-on type

[www.wago.com/793-566/000-012](http://www.wago.com/793-566/000-012)



**Item no.: 793-566/000-017**  
WMB marking card; as card; MARKED; 1 ... 50 (2x); not stretchable; Horizontal marking; snap-on type

[www.wago.com/793-566/000-017](http://www.wago.com/793-566/000-017)



**Item no.: 793-566/000-023**  
WMB marking card; as card; MARKED; 1 ... 50 (2x); not stretchable; Horizontal marking; snap-on type

[www.wago.com/793-566/000-023](http://www.wago.com/793-566/000-023)



Item no.: 793-566/000-024

WMB marking card; as card; MARKED; 1 ... 50 (2x); not stretchable; Horizontal marking; snap-on type

[www.wago.com/793-566](http://www.wago.com/793-566)

/000-024

**Downloads****Documentation****Bid Text**

857-552	Mar 9, 2016	DOC	Download
Rogowski-Messumformer		33.3 kB	

**Instruction Leaflet**

Rogowski Transducer	Jun 9, 2016	PDF	Download
		2.4 MB	

**Additional Information**

Disposal; Electrical and electronic equipment, Packaging	Oct 15, 2018		Download
		265.8 kB	

**Engineering-Software****Software for Interface-Products**

Interface Configuration Software FULL	1.5.4.6	EXE	Download
The full setup, in addition to the WAGO Interface Configuration Software, includes the installation for the Microsoft .NET Framework.	Jan 8, 2018	96.5 MB	

Interface Configuration Software SMALL	1.5.4.6	EXE	Download
The full setup only includes the WAGO Interface Configuration Software.	Jan 8, 2018	46.0 MB	

**smartDATA****CAD data**

3D Download 857-552		URL	Download
---------------------	--	-----	----------

Subject to changes.