
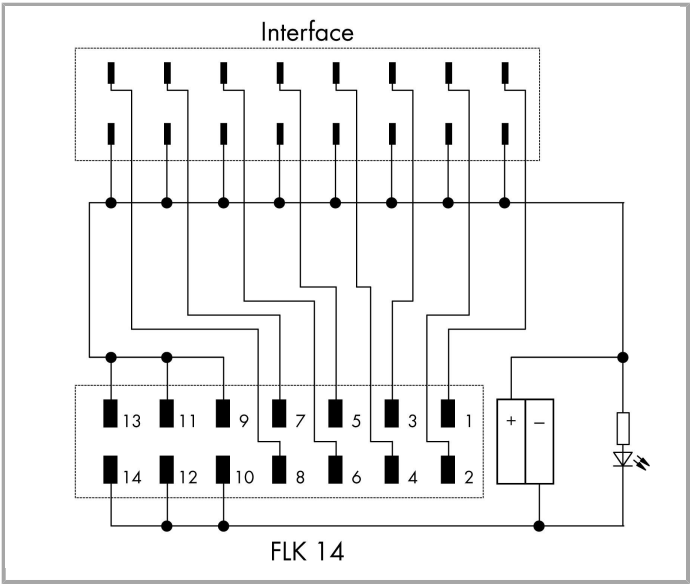


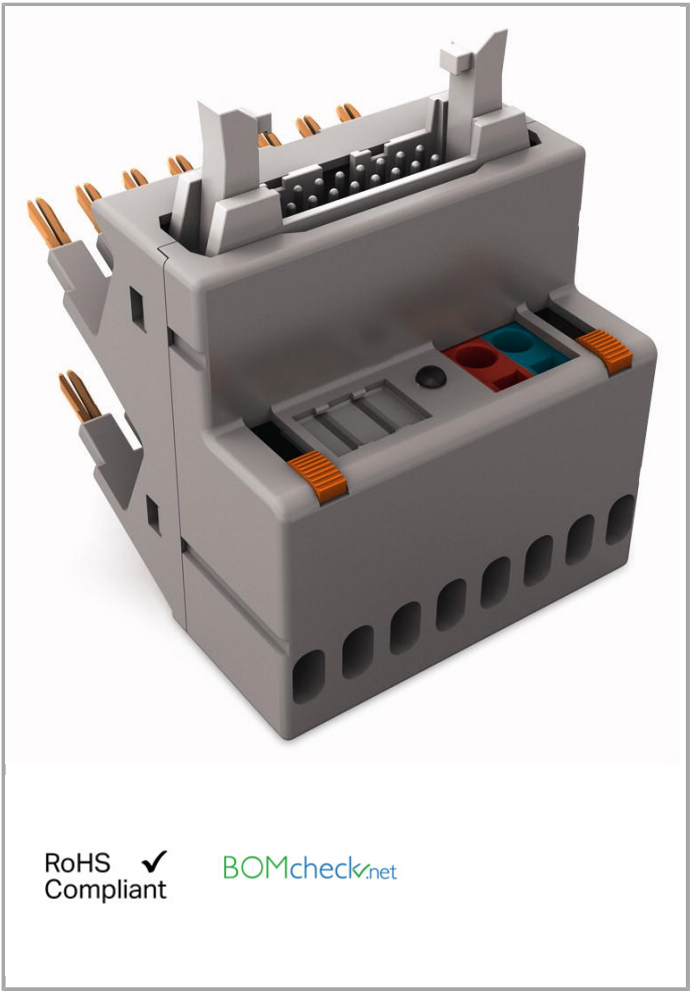

RoHS
Compliant

✓

BOMcheck.net

Data

Electrical data

Nominal operating voltage	24 VDC
Operating voltage range	±30 %
Nominal current	1 A
Total current	3 A
Contact resistance	≤ 20 mΩ
Status indication	LED green

Safety and protection:

Test voltage	500VAC; 50Hz; 1min
--------------	--------------------

Connection data

No. of poles	14
Connection technology 2	CAGE CLAMP®
Solid conductor (2)	0.08 ... 2.5 mm² / 28 ... 14 AWG
Fine-stranded conductor (2)	0.08 ... 2.5 mm² / 28 ... 14 AWG
Strip length (2)	5 ... 6 mm / 0.2 ... 0.24 Inch
Connector	pluggable connector per DIN 41651; male connector
Performance level	3

Mechanical data

Type of mounting	Pluggable module
------------------	------------------

Material Data

Weight	44.477 g
--------	----------

Environmental Requirements

Surrounding air (operating) temperature	-25 ... 70 °C
Surrounding air (storage) temperature	-40 ... 85 °C

Commercial data

Country of origin	DE
GTIN	4045454995188
Customs Tariff No.	85369010000
Product Group	6 (Interface Electronics)

Approvals / Certificates

Ship Approvals

Logo	Approval	Certificate name
	BV Bureau Veritas S.A.	40179_A0
	DNV GL Det Norske Veritas, Germanischer Lloyd	TAA00001D1
	PRS Polski Rejestr Statkow	TE/1989/880590/13

UL-Approvals

Logo	Approval	Certificate name
	Underwriters Laboratories Inc. (ORDINARY LOCATIONS)	E175199 Vol.2 Sec.1

Compatible products

wiring and connectors

	Item no.: 706-100/1303-200 Connection cable; 14-pole; Pluggable connector per DIN 41651; open-ended; Length: 2 m; Conductor cross-section: 0.14 mm ² ; UR components, 857 Series	www.wago.com/706-100/1303-200
	Item no.: 706-753/300-100 Connection cable; 14-pole; Pluggable connector per DIN 41651; 14-pole; Pluggable connector per DIN 41651; Length: 1 m (1 MOhm); Conductor cross-section: 0.14 mm ²	www.wago.com/706-753/300-100
	Item no.: 706-753/300-200 Connection cable; 14-pole; Pluggable connector per DIN 41651; 14-pole; Pluggable connector per DIN 41651; Length: 2 m; Conductor cross-section: 0.14 mm ²	www.wago.com/706-753/300-200
	Item no.: 706-753/300-300 Connection cable; 14-pole; Pluggable connector per DIN 41651; 14-pole; Pluggable connector per DIN 41651; Length: 3 m; Conductor cross-section: 0.14 mm ²	www.wago.com/706-753/300-300
	Item no.: 706-7753/304-100 System cable; for WAGO-I/O-SYSTEM, 750 Series; 2 x 8 analog inputs or outputs; Length: 1 m (1 MOhm); Conductor cross-section: 0.14 mm ²	www.wago.com/706-7753/304-100
	Item no.: 706-7753/304-200 System cable; for WAGO-I/O-SYSTEM, 750 Series; 2 x 8 analog inputs or outputs; Length: 2 m; Conductor cross-section: 0.14 mm ²	www.wago.com/706-7753/304-200
	Item no.: 706-7753/304-300 System cable; for WAGO-I/O-SYSTEM, 750 Series; 2 x 8 analog inputs or outputs; Length: 3 m; Conductor cross-section: 0.14 mm ²	www.wago.com/706-7753/304-300

tools

	Item no.: 210-720 Operating tool with partially insulated shaft; Type 2, blade (3.5 x 0.5) mm	www.wago.com/210-720
--	---	--

Downloads

Documentation

Bid Text

857-982	Mar 9, 2016	DOC	Download
Interface-Adapter		24.6 kB	

Additional Information



Disposal; Electrical and electronic equipment, Packaging

Oct 15, 2018

Download

265.8 kB

Device Files

Device Driver

WAGO Service Interface DTM / 767 and 857 Series (for communication with 857 + 767 Series)	3.2.2.26 Jul 30, 2013	EXE 1.5 MB	Download
WAGO USB Service Cable Driver / 750 and 857 Series	6.5.3.0 Sep 10, 2014	ZIP 4.8 MB	Download
WAGO 857 Series Device DTM	1.02.0007 Feb 29, 2012	ZIP 4.6 MB	Download

Subject to changes.