


## PVC MALE BULLET DISCONNECTOR - STANDARD

### PHOTO / TECHNICAL DRAWING

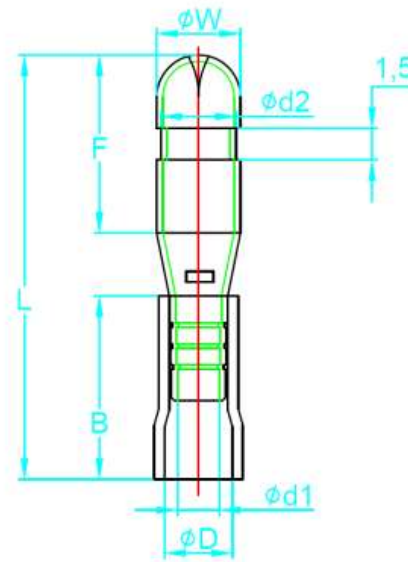

### DIMENSIONS

Wire range	Part nr.	ØW	F	L	B	ØD	Ød1	Ød2	UL
22~16 AWG 0,5~1,5 mm <sup>2</sup>	3282081	4,0	9,0	21,5	10,0	3,3	1,7	3,7	
16~14 AWG		4,0	9,0	21,5	10,0	4,1	2,3	3,7	
1,5~2,5 mm <sup>2</sup>		5,0	9,0	22,5	10,0	4,1	2,3	4,7	
12~10 AWG 4~6 mm <sup>2</sup>		5,0	9,0	25,0	13,0	5,6	3,4	4,7	

### TECHNICAL SPECIFICATIONS

Terminal:	Brass, tin plated
Insulation:	Vinyl (PVC)
Operating temperature:	-10~75 °C
Max. electrical current:	300V
Max. electrical rating:	red 10A blue 15A yellow 24A