


TECHNICAL SPECIFICATION

LR1154

- Chemical System** : Alkaline manganese button batteries
Model No. : LR1154 (LR44 AG13 A76)
Nominal Dimensions: $\Phi 11.60 \times 5.40 \text{mm}$
Nominal Voltage : 1.50V
Average Weight : 1.92g
Applications : Watch, Calculator,
 Electronic toy, etc.
Shelf Life : Not less than 90% of the
 service capacity, following
 1st year storage at 20°C.
Loading : 1000Ω(20°C)
Cut Off Voltage : 0.90V
Capacity : 145mAh

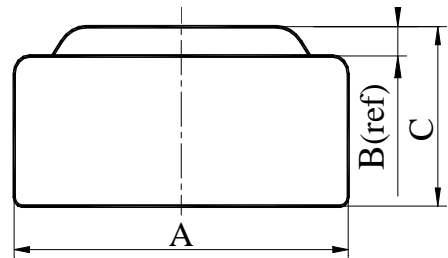

Dimensions	Unit: mm
A	11.40----11.60
B	0.50(ref)
C	5.10----5.40

Typical Discharge Characteristics at 20

