



CR 2

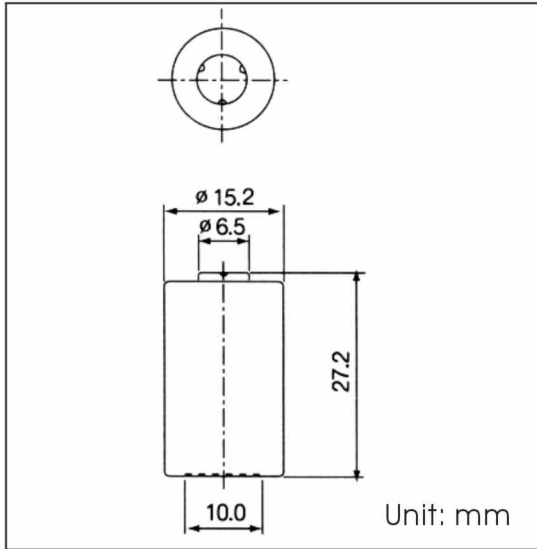

Chemical System : Lithium/Manganese Dioxide
IEC Name: CR2
Camelion No. : CR2
Average Weight : 11.0g
Dimension (O x H) : 15.2 x27.2 mm
Terminals: Flat, Recessed Negative
Nominal Voltage : 3.0Volts
Capacity : 750mAh
(20±2°C 10.0mA constantly discharge to 2.0V)
Standard discharge current: 10.0mA
Max. Continuous Discharge Current: 1000mA
Max. Pulse Discharge Current: 2500mA
Operating Temperature: -20°C~60°C
Storage conditions
Temperature: -20°C~45°C
Relative Humidity: 60±15%
Jacket : Aluminium Foil Label

Typical Temperature Characteristics

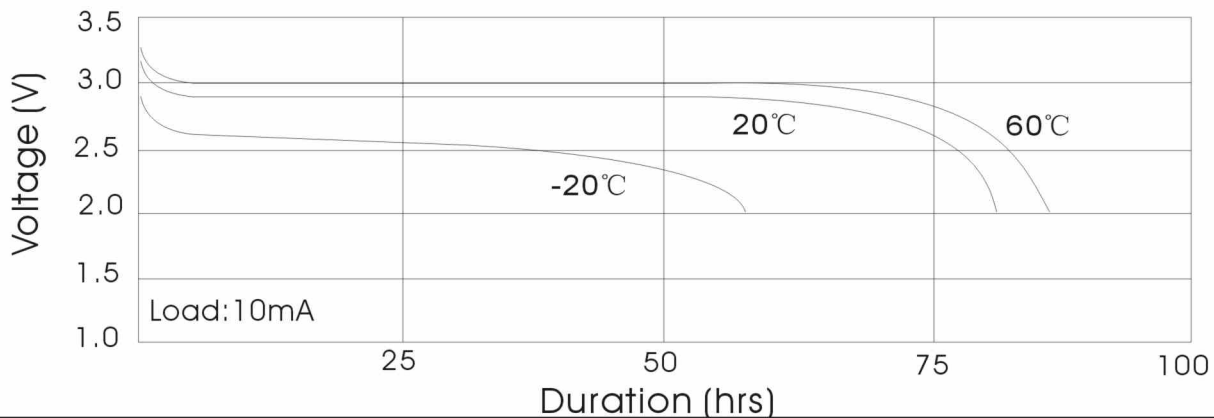

Typical Load Characteristics

