


MPD Series	Flange Recess	Clearance Hole	Recommended Flange Diameter	Typical Stimpson P/N
	0.180" wide x 0.040" deep	0.093"	0.150"	GS-3 Series, 0.089 O.D.

Date	SYM	REVISION RECORD	AUTH	DR.	CK.
4/29/06	A	Added dimensions Updated notes	T.B.	B.S.	
4/26/08	B	Added dimension 0.51	T.B.	B.S.	
8/01/14	C	Updated to ROHS 2 Compliant	T.B.	B.S.	

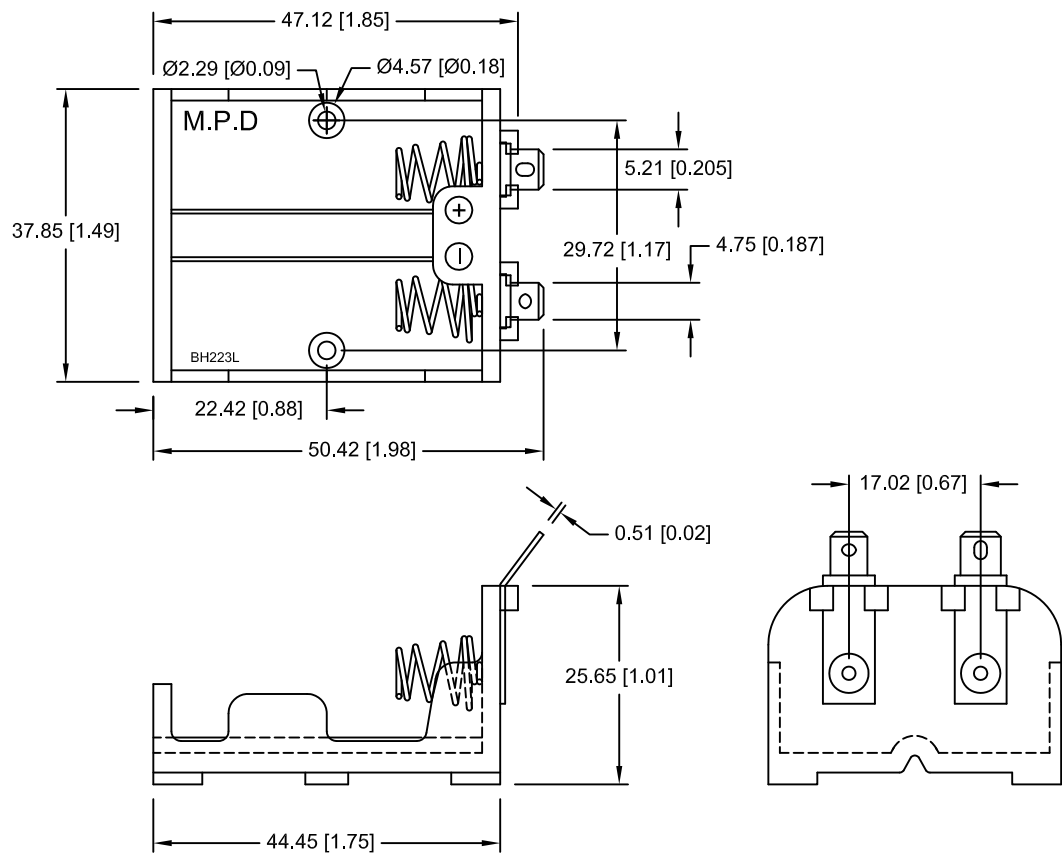

**NOTES:**

**1. MATERIAL:**

HOUSING : BLACK POLYPROPYLENE, PP4410  
 FLAMMABILITY RATING -UL94V-0, UL FILE NO. E107536  
 TEMPERATURE RANGE: -20°C TO +110°C  
 SPRING: STAINLESS STEEL, NICKEL PLATED  
 TERMINAL: BRASS, NICKEL PLATED, FAST ON TABS OR SOLDER LUGS

**2. ROHS 2 COMPLIANT**

<b>Tolerance</b> (Except as noted)			
<b>decimal</b> ±.5 (.020)		<b>Scale</b>	<b>Drawn By</b> B.S.
<b>Fractional</b> ± .8 (.030)	<b>Title</b> 6V BATTERY HOLDER		
<b>Angular</b> ± 3°	<b>Date</b> 8/01/14	<b>Drawing Number</b> BH223-L	
			<b>Approved By</b> T.B.