


Data sheet | Item number: 2001-438

Push-in type jumper bar; insulated; from 1 to 8; Nominal current 18 A

www.wago.com/2001-438

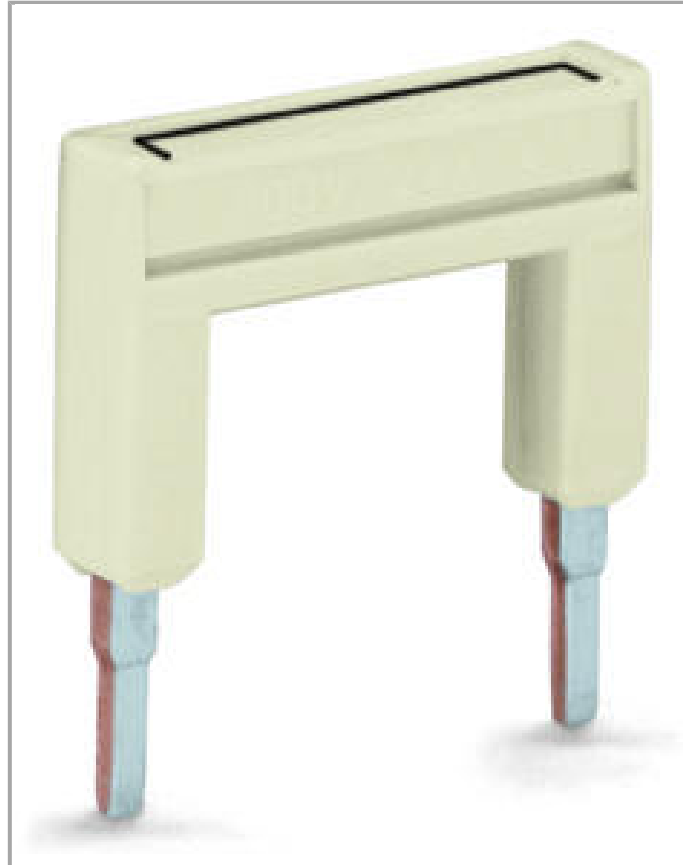

RoHS Compliant

[BOMcheck.net](https://www.bomcheck.net)

Color:

Data

Electrical data

Rated current (Ex e II)	16 A
-------------------------	------

Ratings per IEC/EN 60664-1

Rated voltage (III / 3)	800 V
-------------------------	-------

Rated current	18 A
---------------	------

Geometrical Data

Width	32.3 mm / 1.272 inch
-------	----------------------



Height	19 mm / 0.748 inch
Depth	4.1 mm / 0.161 inch

Material Data

Color	light gray
Fire load	0.016 MJ
Weight	1.829 g

Commercial data

Country of origin	DE
GTIN	4017332998925
Customs Tariff No.	85366990990
Product Group	22 (TOPJOB S)

Downloads**Documentation****Bid Text**

2001-438	Oct 20, 2017	DOC 24.1 kB	Download
----------	--------------	----------------	----------

smartDATA**CAD data**

3D Download 2001-438	URL	Download
----------------------	-----	----------

Product family**TOPJOB® S**

TOPJOB® S: In various industrial applications and modern building installations, WAGO's wide and versatile range of rail-mount terminal blocks provides more than just reliable electrical connections.

[Learn more about the product family.](#)

[Show all products from the family](#)

Subject to changes.