


Data sheet | Item number: 885-110

Stud terminal block; lateral marker slots; for DIN-rail 35 x 15 and 35 x 7.5; 1 stud, M10

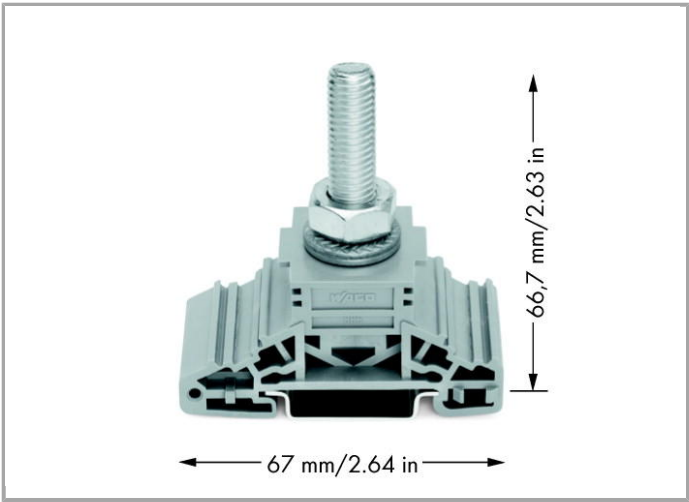

www.wago.com/885-110



Data
Electrical data

Ratings per IEC/EN 60664-1

Rated voltage (III / 3)	1000 V
Rated impulse voltage (III / 3)	8 kV
Rated current	269 A
Legend (ratings)	(III / 3) ≙ Overvoltage category III / Pollution degree 3

Connection data

Connection technology	Screw-clamp connection/Studs
Actuation type	Operating tool
Connectable conductor materials	Copper
Solid conductor	6 ... 120 mm² / 10 AWG ... 250 kcmil
Total number of connection points	1
Total number of potentials	1
Type of wiring	Front-entry wiring

Geometrical Data

Width	33.8 mm / 1.331 inch
Height from upper-edge of DIN-35 rail	66.7 mm / 2.626 inch
Depth	67 mm / 2.638 inch

Mechanical data

Tightening torque	10 ... 20 Nm
Type of mounting	DIN-35 rail
Marking level	Side marking

Material Data

Color	gray
Fire load	0.831 MJ
Weight	88.216 g

Commercial data

Country of origin	CN
GTIN	4050821049241
Customs Tariff No.	85369095990
Product Group	1 (Rail Mounted Terminal Blocks)

Approvals / Certificates

Country specific Approvals

Logo	Approval	Certificate name
	CCA DEKRA Certification B.V.	NTR NL 6882
	CCA DEKRA Certification B.V.	2145295.01
	CSA DEKRA Certification B.V.	70038960

UL-Approvals

Logo	Approval	Certificate name
	UL UL International Germany GmbH	E45172



Compatible products

Marking accessories

	Item no.: 2009-110 Marking strips; on reel; not stretchable; plain; snap-on type	www.wago.com/2009-110
	Item no.: 2009-115 WMB-Inline; for smartPRINTER; on reel; stretchable 5 - 5.2 mm; plain; snap-on type	www.wago.com/2009-115
	Item no.: 2009-115/000-002 WMB-Inline; for smartPRINTER; on reel; stretchable 5 - 5.2 mm; plain; snap-on type	www.wago.com/2009-115/000-002
	Item no.: 2009-115/000-006 WMB-Inline; for smartPRINTER; on reel; stretchable 5 - 5.2 mm; plain; snap-on type	www.wago.com/2009-115/000-006
	Item no.: 2009-115/000-007 WMB-Inline; for smartPRINTER; on reel; stretchable 5 - 5.2 mm; plain; snap-on type	www.wago.com/2009-115/000-007
	Item no.: 2009-115/000-012 WMB-Inline; for smartPRINTER; on reel; stretchable 5 - 5.2 mm; plain; snap-on type	www.wago.com/2009-115/000-012
	Item no.: 2009-115/000-017 WMB-Inline; for smartPRINTER; on reel; stretchable 5 - 5.2 mm; plain; snap-on type	www.wago.com/2009-115/000-017
	Item no.: 2009-115/000-023 WMB-Inline; for smartPRINTER; on reel; stretchable 5 - 5.2 mm; plain; snap-on type	www.wago.com/2009-115/000-023
	Item no.: 2009-115/000-024 WMB-Inline; for smartPRINTER; on reel; stretchable 5 - 5.2 mm; plain; snap-on type	www.wago.com/2009-115/000-024
	Item no.: 2009-135 WMB-Inline; for smartPRINTER; on reel; stretchable 5 - 5.2 mm; plain; snap-on type	www.wago.com/2009-135
	Item no.: 2009-198 Adaptor	www.wago.com/2009-198

End plate

	Item no.: 885-530 Separator plate; 2 mm thick; 157 mm wide	www.wago.com/885-530
	Item no.: 885-550 Separator plate with jumper bar recess; 2 mm thick; 157 mm wide	www.wago.com/885-550

N-busbar



Item no.: 885-570

Cover; 1 m long

www.wago.com/885-570

Jumper



Item no.: 885-410

Assembled jumper bar; 2-way

www.wago.com/885-410

Item no.: 885-430

Assembled jumper bar; 3-way

www.wago.com/885-430

Item no.: 885-470

Step-down adjacent jumper bar; 2 levels; from M10 to M6

www.wago.com/885-470

General accessories



Item no.: 885-580

Clip; secures cover against slipping

www.wago.com/885-580

Downloads

smartDATA

CAD data

3D Download 885-110

URL

Download

Subject to changes.

WAGO Kontakttechnik GmbH & Co. KG

Hansastr. 27

32423 Minden

Phone: +49571 887-0 | Fax: +49571 887-169

Email: info.de@wago.com | Web: www.wago.com

Do you have any questions about our products?

We are always happy to take your call at +49 (571) 887-44222.