



Data sheet | Item number: 885-306

Stud terminal block; lateral marker slots; for DIN-rail 35 x 15 and 35 x 7.5; 3 studs, M6

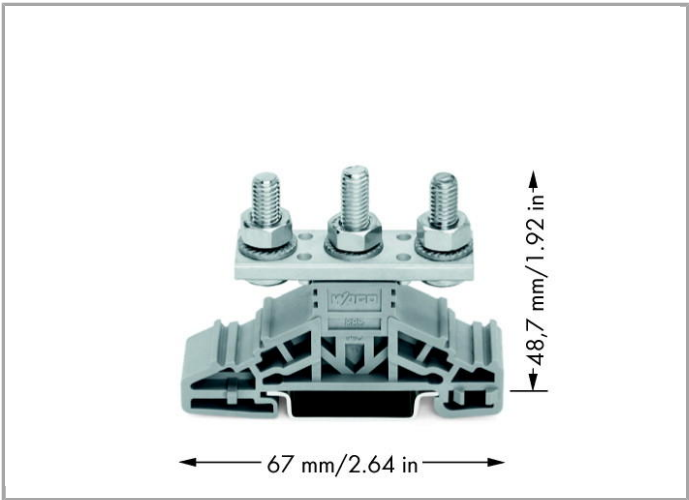

www.wago.com/885-306

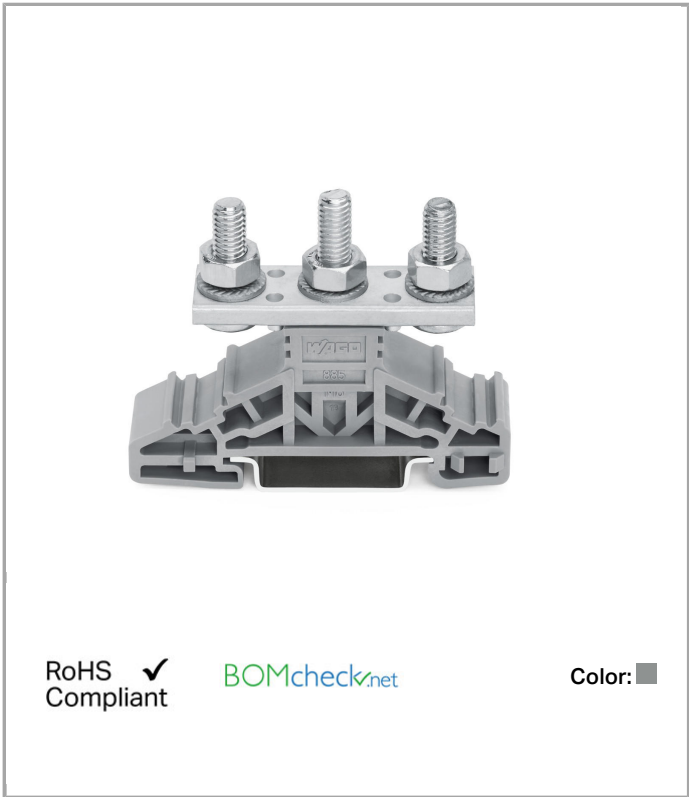

RoHS
Compliant

BOMcheck.net

Color: ■

Data
Electrical data

Ratings per IEC/EN 60664-1

Rated voltage (III / 3)	1000 V
Rated impulse voltage (III / 3)	8 kV
Rated current	125 A
Legend (ratings)	(III / 3) ≙ Overvoltage category III / Pollution degree 3

Connection data

Connection technology	Screw-clamp connection/Studs
Actuation type	Operating tool
Connectable conductor materials	Copper
Solid conductor	2.5 ... 35 mm² / 14 ... 2 AWG
Total number of connection points	3
Total number of potentials	1
Type of wiring	Front-entry wiring

Geometrical Data

Width	17.8 mm / 0.701 inch
Height from upper-edge of DIN-35 rail	48.7 mm / 1.917 inch
Depth	67 mm / 2.638 inch

Mechanical data

Tightening torque	3 ... 6 Nm
Type of mounting	DIN-35 rail
Marking level	Side marking

Material Data

Color	gray
Fire load	0.39 MJ
Weight	66.606 g

Commercial data

Country of origin	CN
GTIN	4050821049258
Customs Tariff No.	85369095990
Product Group	1 (Rail Mounted Terminal Blocks)

Approvals / Certificates

Country specific Approvals

Logo	Approval	Certificate name
	CCA DEKRA Certification B.V.	NTR NL 6882
	CCA DEKRA Certification B.V.	2145295.01
	CSA DEKRA Certification B.V.	70038960

UL-Approvals

Logo	Approval	Certificate name
	UL UL International Germany GmbH	E45172



Compatible products

End plate



Item no.: 885-526
Separator plate; 2 mm thick; 102.3 mm wide

www.wago.com/885-526



Item no.: 885-546
Separator plate with jumper bar recess; 2 mm thick; 102.3 mm wide

www.wago.com/885-546

Jumper



Item no.: 885-406
Assembled jumper bar; 2-way

www.wago.com/885-406



Item no.: 885-426
Assembled jumper bar; 3-way

www.wago.com/885-426



Item no.: 885-448
Step-down adjacent jumper bar; 1 level; from M8 to M6

 
www.wago.com/885-448



Item no.: 885-470
Step-down adjacent jumper bar; 2 levels; from M10 to M6

www.wago.com/885-470

N-busbar



Item no.: 885-566
Cover; 1 m long

www.wago.com/885-566

General accessories



Item no.: 885-580
Clip; secures cover against slipping

www.wago.com/885-580

Marking accessories



Item no.: 2009-110
Marking strips; on reel; not stretchable; plain; snap-on type

www.wago.com/2009-110



Item no.: 2009-115
WMB-Inline; for smartPRINTER; on reel; stretchable 5 - 5.2 mm; plain; snap-on type

www.wago.com/2009-115



Item no.: 2009-115/000-002
WMB-Inline; for smartPRINTER; on reel; stretchable 5 - 5.2 mm; plain; snap-on type

www.wago.com/2009-115/000-002



Item no.: 2009-115/000-006
WMB-Inline; for smartPRINTER; on reel; stretchable 5 - 5.2 mm; plain; snap-on type

www.wago.com/2009-115/000-006

	Item no.: 2009-115/000-007 WMB-Inline; for smartPRINTER; on reel; stretchable 5 - 5.2 mm; plain; snap-on type	www.wago.com/2009-115/000-007
	Item no.: 2009-115/000-012 WMB-Inline; for smartPRINTER; on reel; stretchable 5 - 5.2 mm; plain; snap-on type	www.wago.com/2009-115/000-012
	Item no.: 2009-115/000-017 WMB-Inline; for smartPRINTER; on reel; stretchable 5 - 5.2 mm; plain; snap-on type	www.wago.com/2009-115/000-017
	Item no.: 2009-115/000-023 WMB-Inline; for smartPRINTER; on reel; stretchable 5 - 5.2 mm; plain; snap-on type	www.wago.com/2009-115/000-023
	Item no.: 2009-115/000-024 WMB-Inline; for smartPRINTER; on reel; stretchable 5 - 5.2 mm; plain; snap-on type	www.wago.com/2009-115/000-024
	Item no.: 2009-135 WMB-Inline; for smartPRINTER; on reel; stretchable 5 - 5.2 mm; plain; snap-on type	www.wago.com/2009-135
	Item no.: 2009-198 Adaptor	www.wago.com/2009-198

Downloads

smartDATA

CAD data

3D Download 885-306	URL	Download
---------------------	-----	----------

Subject to changes.

WAGO Kontakttechnik GmbH & Co. KG
Hansastr. 27
32423 Minden
Phone: +49571 887-0 | Fax: +49571 887-169
Email: info.de@wago.com | Web: www.wago.com

Do you have any questions about our products?
We are always happy to take your call at +49 (571) 887-44222.