
 


Data sheet | Item number: 896-232

Tap-off module; with screw-type connection; for flat cable 3 x 2.5 mm²; tightening torque 0.7 nm; Phillips no. 1 screwdriver

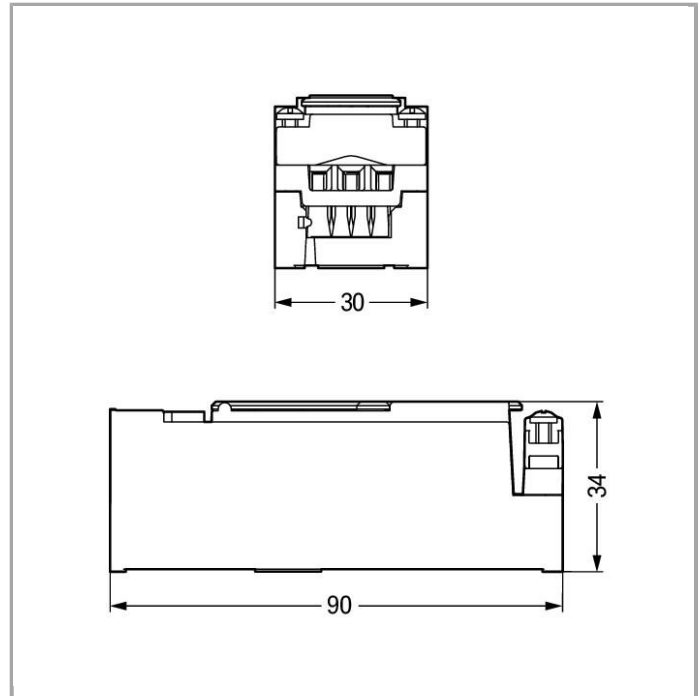

www.wago.com/896-232



Data

Electrical data

Ratings per IEC/EN 60664-1

Rated voltage (III / 3)	250 V
Rated impulse voltage (III / 3)	4 kV
Rated current	24 A
Legend (ratings)	(III / 3) ≙ Overvoltage category III / Pollution degree 3

Connection data

Connection technology	Screw clamp connection
Actuation type	Operating tool
Connection technology 2	IDC connection
Total number of connection points	3



Total number of potentials	3
Cross section of single conductor	2.5 mm ²

Geometrical Data

Width	30 mm / 1.181 inch
Height	34 mm / 1.339 inch
Depth	90 mm / 3.543 inch

Mechanical data

Mating force of a plug-in connection	approx. 30–70N (depending on number of poles)
Unmating force of a plug-in connection	when unlocked: approx. 15–20N
Degree of protection	IP20

Plug connection

Mismating protection	Yes
----------------------	-----

Material Data

Color	gray
Insulating material	Polyamide 66 (PA 66)
Flammability class per UL94	V0
Contact material	Copper or copper alloy, surface-treated
Fire load	1.5 MJ
Weight	90 g

Environmental Requirements

Surrounding air (operating) temperature	-35 ... 85 °C
---	---------------

Commercial data

Country of origin	CH
GTIN	4045454004217
Customs Tariff No.	85369010000
Product Group	20 (WINSTA)

Compatible products

wiring and connectors

Item no.: 897-231 Flat cable; PVC insulated; 3 x 2.5 mm ² ; 3L + N + PE	www.wago.com/897-231
Item no.: 897-232 Flat cable; halogen-free; 3 x 2.5 mm ² ; 3L + N + PE	www.wago.com/897-232



Downloads

Documentation

Bid Text

896-232	Sep 22, 2016	DOC	Download
WINSTA® IDC		23.0 kB	

Subject to changes.