


Data sheet | Item number: 2002-433

Push-in type jumper bar; insulated; from 1 to 3; Nominal current 25 A

www.wago.com/2002-433

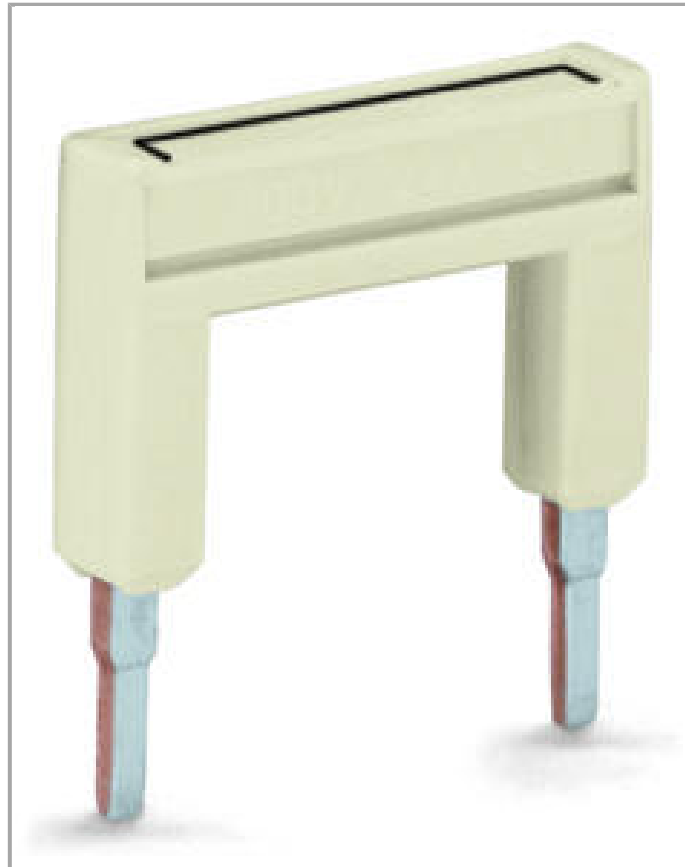

RoHS Compliant

[BOMcheck.net](https://www.bomcheck.net)

Color:

Data

Electrical data

Rated current (Ex e II)	20 A
-------------------------	------

Ratings per IEC/EN 60664-1

Rated voltage (III / 3)	800 V
-------------------------	-------

Rated current	25 A
---------------	------

Geometrical Data

Width	13.8 mm / 0.543 inch
-------	----------------------



Height	19 mm / 0.748 inch
Depth	4.1 mm / 0.161 inch

Material Data

Color	light gray
Fire load	0.009 MJ
Weight	1.144 g

Commercial data

Packaging type	bag
Country of origin	DE
GTIN	4055143690973
Customs Tariff No.	85366990990
Product Group	22 (TOPJOB S)

Downloads

Documentation

Bid Text

2002-433	Oct 25, 2017	DOC 24.6 kB	Download
----------	--------------	----------------	----------

smartDATA

CAD data

3D Download 2002-433	URL	Download
----------------------	-----	----------



Product family

TOPJOB® S

TOPJOB® S: In various industrial applications and modern building installations, WAGO's wide and versatile range of rail-mount terminal blocks provides more than just reliable electrical connections.

[Learn more about the product family.](#)

[Show all products from the family](#)

Subject to changes.

WAGO Kontakttechnik GmbH & Co. KG
Hansastr. 27
32423 Minden
Phone: +49571 887-0 | Fax: +49571 887-169
Email: info.de@wago.com | Web: www.wago.com

Do you have any questions about our products?
We are always happy to take your call at +49 (571) 887-44222.